


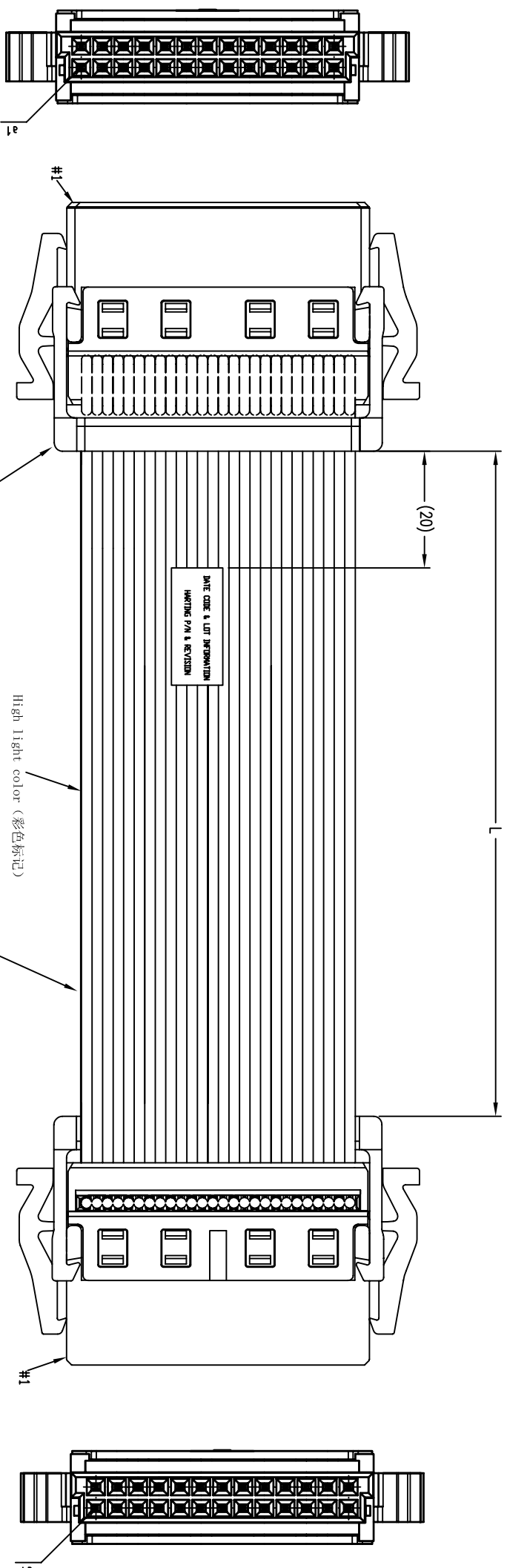

Har-Flex female 26pole, with Strain relief, L2 Flat cable, pitch 0.635mm, AWG30, 26 conductors

12

Har-flex 26P female connector

13

Har-flex 26P female connector

Part-No./产品号码	Length/长度
33 15 243 050 0009 .00	500±5
33 15 243 020 0008 .00	200±3
33 15 243 010 0007 .00	100±3

NOTES/要求:

- 1.) CABLE MUST BE PERFORMED 100% CONTINUITY TEST AND HI-POT (300VDC) TEST.
- 2.) CABLE OPERATION TEMPERATURE= -30 ° C TO +105 ° C .
- 3.) WHITE LABEL CONTENT :

DATE CODE & LOT INFORMATION

HARTING P/N & REVISION

00	Prototype	Andrew.H	24/05/11
Rev.	Description	Appr.	Date

				All Dimensions in mm Original Size DIN A4		Ref. MB
Free size tol.						Mat.
$V =$		cm^3		$A =$		
	Name	Date	Scale		Title	
Detail			/		Har-Flex female 26pole, double ender	
Insp.			Sheet		Flat cable assembly, L=xM	
Approved			1 of 1			

Ref. MB	
Mat.	
	SEE BILL OF MATERIAL
Title	
	Har-Flex female 26pole, double ended Flat cable assembly, L=xM
DWG. No.	TB_33 15 0003 .00