

PART NAME

VISIONCAB (STYLE B)


PART No.

VC-9930-B to VC-9934-B

REV. DATE

2-21-12

QTY. ("C")
110 VAC, 65 CFM FAN(S)

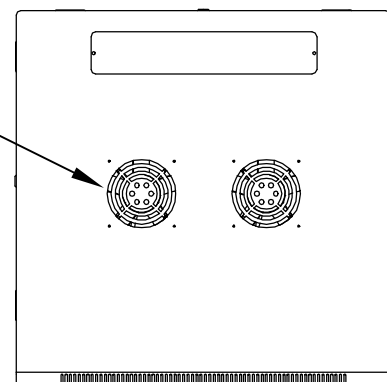

TOP VIEW


MATERIAL:
PANEL MOUNTING RAILS - 14 GA. [2.0mm] STEEL
SHELF - 18 GA. [1.2mm] STEEL
ALL OTHER PARTS - 18 GA. [1.2mm] STEEL

FINISH:
FINE TEXTURED BLACK POWDER COATING

PANEL MOUNTING RAILS HAVE 0.350 [8.89] SQUARE HOLES ON E.I.A. UNIVERSAL HOLE SPACING


SUPPLIED HARDWARE KIT TO INCLUDE:
QTY. (25) M6x1.0 PITCH CAGE NUT
QTY. (25) M6x1.0 PITCH PAN HEAD SCREW
QTY. (25) NYLON FLAT WASHER
QTY. (4) RUBBER FEET
QTY. (6) KEYS

17.72 [450.0] MIN.
CLEAR OPENING

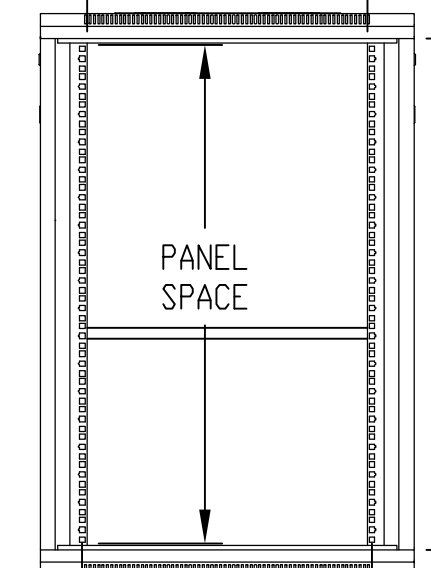

18.31±0.8 [465.0±2.0]
HOLE CENTERS
FRONT VIEW
(DOOR REMOVED)

23.62 [600.0]
A

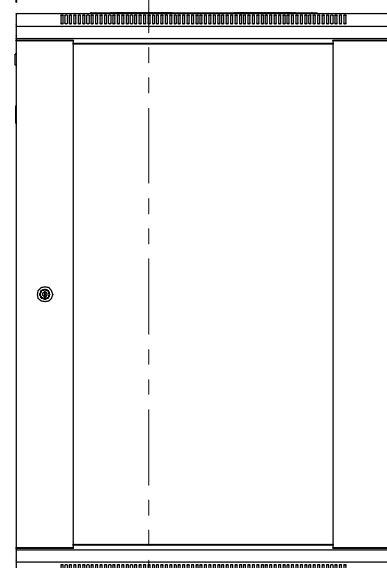


FRONT VIEW


DIM. "B"

DIM. "A"

23.62 [600.0]

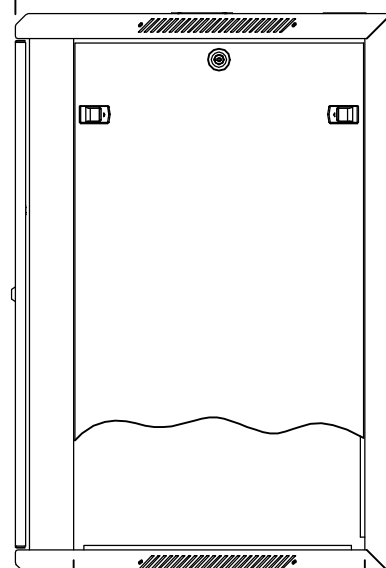


RIGHT SIDE VIEW

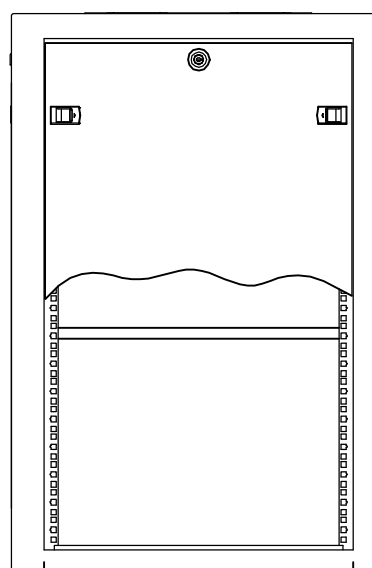

BACK VIEW

QTY. (4) L-SHAPE
PANEL MTG. RAILS

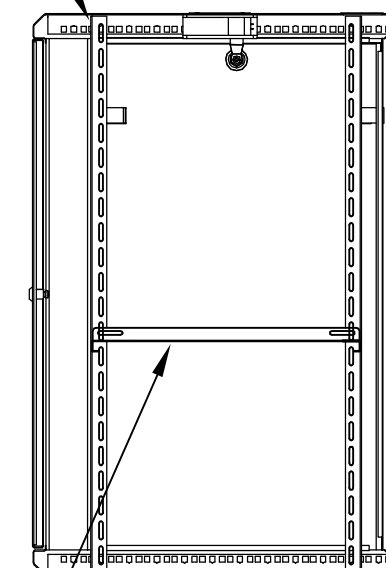


17.12 [434.8]

SECTION A-A

QTY. (1) VENTILATED
FIXED SHELF INCLUDED
(FOR ADDITIONAL SHELVES,
ORDER PART No. SH-12705)

19.63 [498.5]

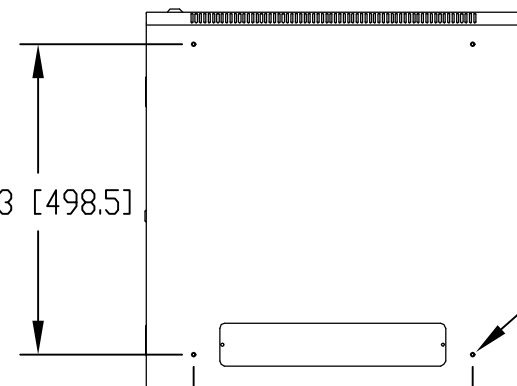

BOTTOM VIEW

∅0.25 [6.3]
MOUNTING HOLE
FOR RUBBER FOOT

17.63 [447.7]

TOLERANCE: ±0.8 [±2.0]

PART NO.	UNIT	PANEL SPACE	DIM. "A"	DIM. "B"	QTY. "C"
VC-9930-B	6U	10.50 [266.7]	14.49 [368.0]	11.35 [288.2]	(1)
VC-9931-B	9U	15.75 [400.1]	19.69 [500.0]	16.54 [420.2]	(1)
VC-9932-B	12U	21.00 [533.4]	25.00 [635.0]	21.86 [555.2]	(2)
VC-9933-B	15U	26.25 [666.8]	30.28 [769.0]	27.13 [689.2]	(2)
VC-9934-B	18U	31.50 [800.1]	35.43 [900.0]	32.29 [820.2]	(2)