



EPG.00.304.HLN

MECHANICAL DETAILS

Shell Style Model EP* : Elbow receptacle for printed circuit


Keying 1 key (alpha=0, plug: male contacts, receptacle: female contacts)

Housing Material PPS (Polyphenylene) shell, other pieces nickel plated brass

Cable Fixing 0 - 0 mm

Variant 2 :

	A	D	H	I	K	L	N
Mm.	6.8	11.5	3.5	7	8.7	19	7.1
In.	0.27	0.45	0.14	0.28	0.34	0.75	0.28

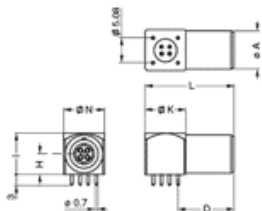


PERFORMANCE DETAIL

Insert 00.304/EPG : 4 Low Voltage

Insulator L: PEEK

Specifications

 Contact Type: Print (straight)



OTHER CHARACTERISTICS

Shell Style/Model Libellé







IP Rating 50



Available Download

 [unipole_multipole.pdf](#)

Related links

-  [Contact](#)
-  [Quote Request](#)
-  [Catalogs Downloads](#)
-  [Catalogs Requests](#)
-  [Sample Request](#)
-  [3D drawings](#)