



Datenblatt - Fiche technique - Data sheet


11.99.8944




VALUE USB 2.0 Kabel, Typ A-A, 4,5m

VALUE Câble USB 2.0 Type A-A, 4.5m

VALUE USB 2.0 Cable, Type A-A, 4.5 m

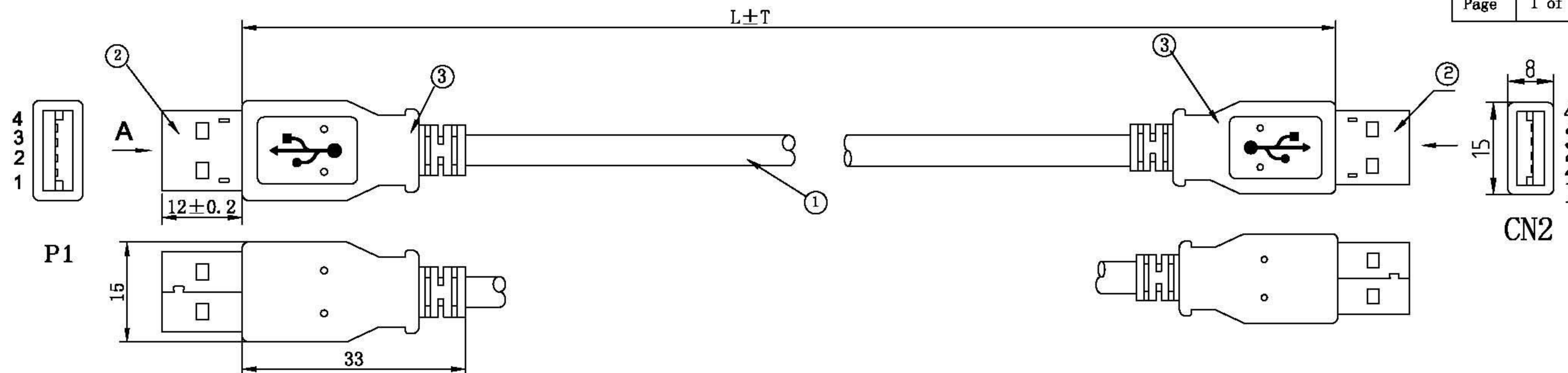

PIN OUT

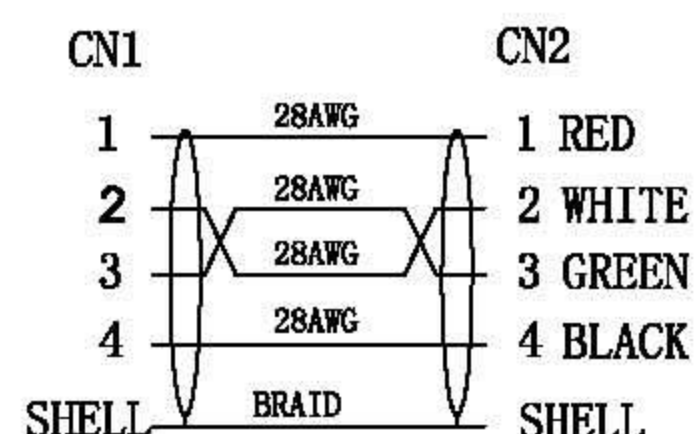

NOTE 1:

ITEM NO.	LENGTH
11. 99. 8909R	800±20mm
11. 99. 8919R	1800±30mm
11. 99. 8931R	3000±50mm
11. 99. 8944R	4500±100mm

NOTE:

- Electrical test:
 - 100% open short & miss wire test;
 - Insulation resistance:DC 300V 10M Ω;
 - Contact resistance:3Ω Max;
 - Dielectric strength:100V AC/Minute, 1mA.
- RoHS compliant
- PRINTING:USB 2.0 CABLE, 28AWG×1P+28AWG×2C
- Packing: 1PCS/PE BAG + LABEL 100PCS/CARTON
11. 99. 8909 50PCS/CARTON

MATERIAL LIST:

③	OUTER MOLD	Shore 88A PVC(UL94V-2) Color: White	2	
②	USB A TYPE	USB A /M Type, The Pin Gold Plating 30U", the shell for Nickel Plating	2	
①	CABLE	USB 2.0 28AWG(7/0.12BC*1P)+28AWG(7/0.12BC*2C)+AB B=0.12/3*16 AL-MG JACKET:PVC/WHITE (WH11) OD: 3.8±0.2mm	1	
NO.	PARTS NAME	SPECIFICATION STANDARD	QT' Y	REMARK
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.

Rotronic Co., Ltd									
CUSTOMER		REF.		ITEM NO.	11. 99. 8909	11. 99. 8919	11. 99. 8931	11. 99. 8944	
PRODUCT NAME	USB 2.0 AM/AM		DRAW NO.		UNTT	MM			
DRAWNBY	CHECKBY		APPOBY	DATE					
chenhuan	chenhuan			2009-11-20					