



M12 A-coded 3-poles, male straight connector


M12 A-coded 3-poles, female straight connector

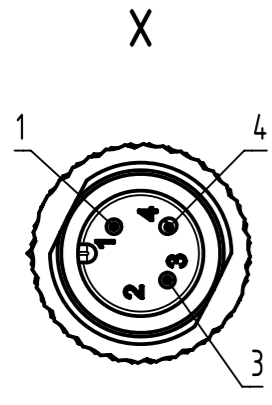

Loading-Plan:
 1 brown 1
 3 blue 3
 4 black 4

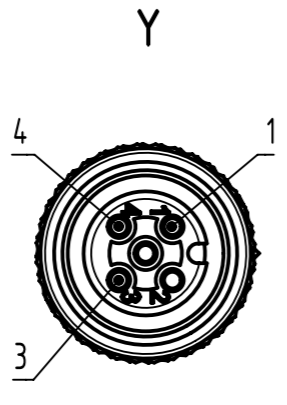

*For Information Only
 -won't be replaced when changed-*

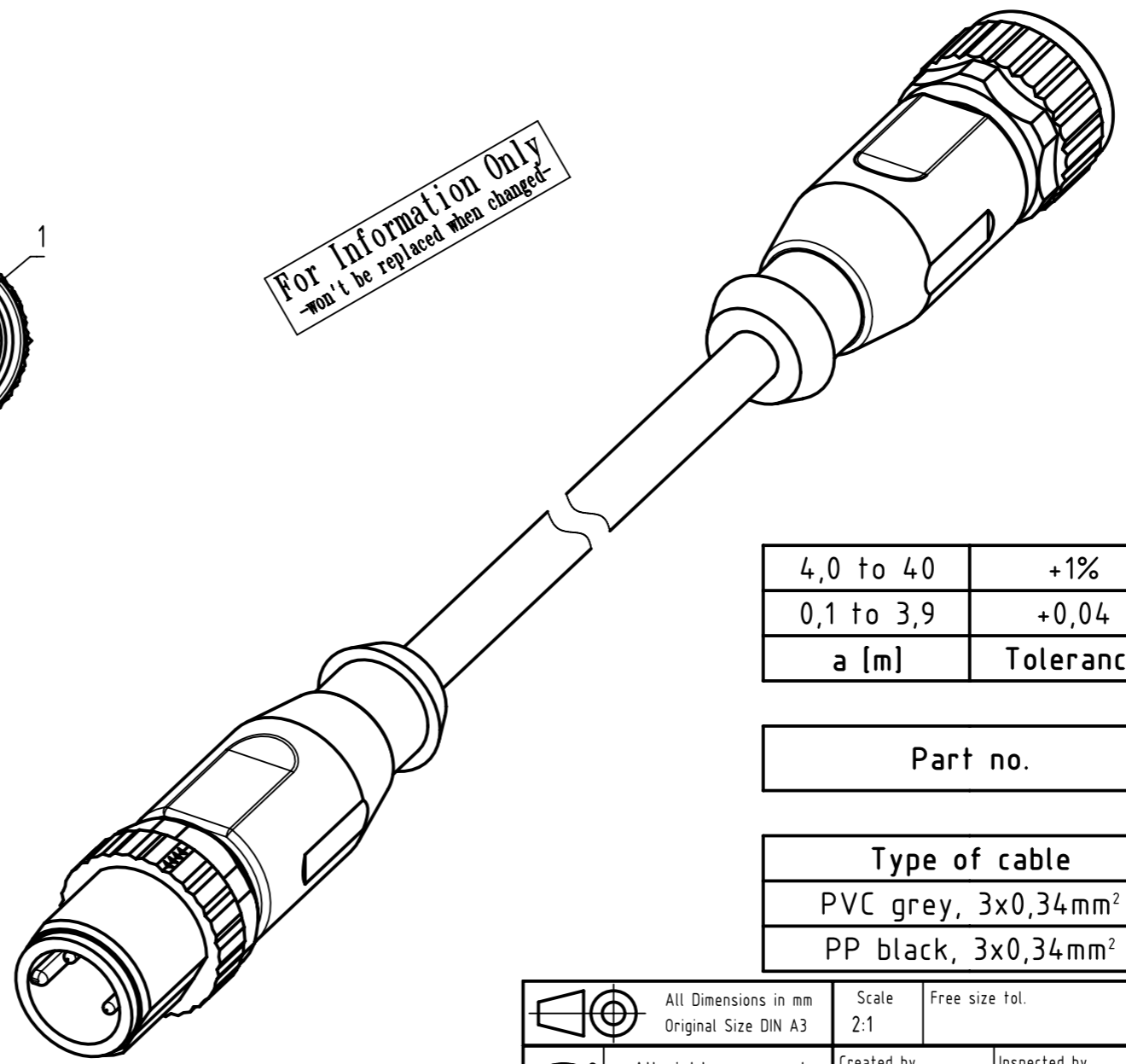

length in "1m" step	40	XXX=400
	39	XXX=390
	.	.
	12	XXX=120
length in "0,1m" step	11	XXX=110
	10	XXX=100
	9,9	XXX=099
	9,8	XXX=098
	.	.
	0,4	XXX=004
	0,3	XXX=003
	0,2	XXX=002
	0,1	XXX=001
Step	a [m]	XXX

4,0 to 40	+1%
0,1 to 3,9	+0,04
a [m]	Tolerance

Part no.	213484853XXXXX
----------	----------------

Type of cable	XX
PVC grey, 3x0,34mm ²	XX=83
PP black, 3x0,34mm ²	XX=90

- Protection level: IP67
 - Temperature range: -25°C ... +80°C

All rights reserved Department EC PD - RO HARTING Electronics GmbH D-32339 Espelkamp	All Dimensions in mm Original Size DIN A3	Scale 2:1 Free size tol.	Ref. Sub.
	Created by TOMUTA Title M12 A-coded Cable Assembly Type TB	Inspected by Standardisation Number 213484853XXXXX	Date 2014-05-23 State Checked Out