


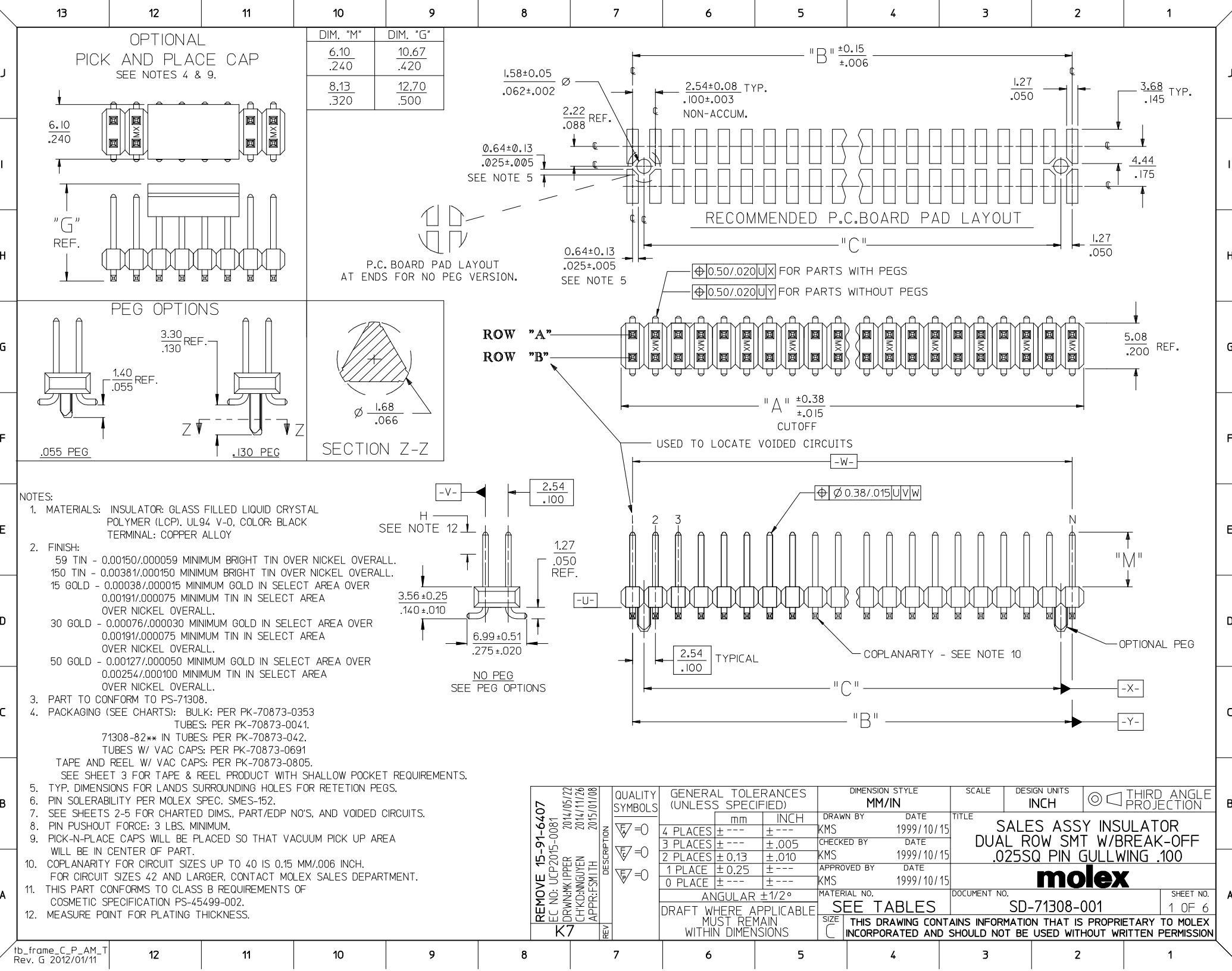

13			12		11		10		9		8		7		6		5		4		3		2		1															
J	PACKAGING SEE NOTE 4 SHT 1		4-6 CKT		BULK		TAPE-N-REEL W/ VAC CAPS		N/A		BULK		TAPE-N-REEL W/ VAC CAPS		N/A		BULK		TAPE-N-REEL W/ VAC CAPS		N/A		BULK		BULK															
			8-100 CKT		TUBES		TAPE-N-REEL W/ VAC CAPS		TUBES W/ VAC CAPS		TUBES		TAPE-N-REEL W/ VAC CAPS		TUBES W/ VAC CAPS		TUBES		TAPE-N-REEL W/ VAC CAPS		TUBES W/ VAC CAPS		TUBES		TUBES															
	DIM. M±0.25 MM				6.10 (.240)				6.10 (.240)				6.10 (.240)				6.10 (.240)								8.13 (.320)		8.13 (.320)													
	PLATING				150 TIN				15 GOLD				30 GOLD												15 GOLD		30 GOLD													
	DIM. H				2.54 (.100)				2.54 (.100)				2.54 (.100)												4.57 (.180)		4.57 (.180)													
I	CKTS	DIM. A		DIM. B		EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	CKTS													
		MM	IN	MM	IN																																			
H	04	5.08	.200	2.54	.100	015-91-2040	015-91-6040	N/A	015-91-0040	015-91-6042	N/A	015-91-3040	015-91-6043	N/A		015-91-0048	015-91-5049	04	H																					
	06	7.62	.300	5.08	.200	015-91-2060	015-91-6060	N/A	015-91-0060	015-91-6062	N/A	015-91-3060	015-91-6063	N/A		015-91-0068	015-91-5069	06																						
	08	10.16	.400	7.62	.300	015-91-2080	015-91-6080	015-91-3087	015-91-0080	015-91-6082	015-91-3086	015-91-3080	015-91-6083	015-91-3088		015-91-0088	015-91-5089	08																						
	10	12.70	.500	10.16	.400	015-91-2100	015-91-6100	015-91-3107	015-91-0100	015-91-6102	015-91-3106	015-91-3100	015-91-6103	015-91-3108		015-91-0108	015-91-5109	10																						
H	12	15.24	.600	12.70	.500	015-91-2120	015-91-6120	015-91-3127	015-91-0120	015-91-6122	015-91-3126	015-91-3120	015-91-6123	015-91-3128		015-91-0128	015-91-5129	12	H																					
	14	17.78	.700	15.24	.600	015-91-2140	015-91-6140	015-91-3147	015-91-0140	015-91-6142	015-91-3146	015-91-3140	015-91-6143	015-91-3148		015-91-0148	015-91-5149	14																						
	16	20.32	.800	17.78	.700	015-91-2160	015-91-6160	015-91-3167	015-91-0160	015-91-6162	015-91-3166	015-91-3160	015-91-6163	015-91-3168		015-91-0168	015-91-5169	16																						
	18	22.86	.900	20.32	.800	015-91-2180		015-91-3187	015-91-0180		015-91-3186	015-91-3180		015-91-3188		015-91-0188	015-91-5189	18																						
G	20	25.40	1.000	22.86	.900	015-91-2200	015-91-6200	015-91-3207	015-91-0200	015-91-6202	015-91-3206	015-91-3200	015-91-6203	015-91-3208		015-91-0208	015-91-5209	20	G																					
	22	27.94	1.100	25.40	1.000	015-91-2220		015-91-3227	015-91-0220		015-91-3226	015-91-3220		015-91-3228		015-91-0228	015-91-5229	22																						
	24	30.48	1.200	27.94	1.100	015-91-2240		015-91-3247	015-91-0240		015-91-3246	015-91-3240		015-91-3248		015-91-0248	015-91-5249	24																						
	26	33.02	1.300	30.48	1.200	015-91-2260	015-91-6260	015-91-3267	015-91-0260	015-91-6262	015-91-3266	015-91-3260		015-91-3268		015-91-0268	015-91-5269	26																						
G	28	35.56	1.400	33.02	1.300	015-91-2280		015-91-3287	015-91-0280		015-91-3286	015-91-3280		015-91-3288		015-91-0288	015-91-5289	28	G																					
	30	38.10	1.500	35.56	1.400	015-91-2300		015-91-3307	015-91-0300		015-91-3306	015-91-3300		015-91-3308		015-91-0308	015-91-5309	30																						
	32	40.64	1.600	38.10	1.500	015-91-2320		015-91-3327	015-91-0320		015-91-3326	015-91-3320		015-91-3328		015-91-0328	015-91-5329	32																						
	34	43.18	1.700	40.64	1.600	015-91-2340		015-91-3347	015-91-0340		015-91-3346	015-91-3340		015-91-3348		015-91-0348	015-91-5349	34																						
F	36	45.72	1.800	43.18	1.700	015-91-2360		015-91-3367	015-91-0360		015-91-3366	015-91-3360		015-91-3368		015-91-0368	015-91-5369	36	F																					
	38	48.26	1.900	45.72	1.800	015-91-2380		015-91-3387	015-91-0380		015-91-3386	015-91-3380		015-91-3388		015-91-0388	015-91-5389	38																						
	40	50.80	2.000	48.26	1.900	015-91-2400	015-91-6400	015-91-3407	015-91-0400	015-91-6402	015-91-3406	015-91-3400	015-91-6403	015-91-3408		015-91-0408	015-91-5409	40																						
	42	53.34	2.100	50.80	2.000	015-91-2420		015-91-3427	015-91-0420		015-91-3426	015-91-3420		015-91-3428		015-91-0428	015-91-5429	42																						
F	44	55.88	2.200	53.34	2.100	015-91-2440		015-91-3447	015-91-0440		015-91-3446	015-91-3440		015-91-3448		015-91-0448	015-91-5449	44	F																					
	46	58.42	2.300	55.88	2.200	015-91-2460		015-91-3467	015-91-0460		015-91-3466	015-91-3460		015-91-3468		015-91-0468	015-91-5469	46																						
	48	60.96	2.400	58.42	2.300	015-91-2480		015-91-3487	015-91-0480		015-91-3486	015-91-3480		015-91-3488		015-91-0488	015-91-5489	48																						
	50	63.50	2.500	60.96	2.400	015-91-2500	015-91-6500	015-91-3507	015-91-0500	015-91-6502	015-91-3506	015-91-3500	015-91-6503	015-91-3508		015-91-0508	015-91-5509	50																						
E	52	66.04	2.600	63.50	2.500	015-91-2520		015-91-3527	015-91-0520		015-91-3526	015-91-3520		015-91-3528		015-91-0528	015-91-5529	52	E																					
	54	68.58	2.700	66.04	2.600	015-91-2540		015-91-3547	015-91-0540		015-91-3546	015-91-3540		015-91-3548		015-91-0548	015-91-5549	54																						
	56	71.12	2.800	68.58	2.700	015-91-2560		015-91-3567	015-91-0560		015-91-3566	015-91-3560		015-91-3568		015-91-0568	015-91-5569	56																						
	58	73.66	2.900	71.12	2.800	015-91-2580		015-91-3587	015-91-0580		015-91-3586	015-91-3580		015-91-3588		015-91-0588	015-91-5589	58																						
E	60	76.20	3.000	73.66	2.900	015-91-2600		015-91-3607	015-91-0600		015-91-3606	015-91-3600		015-91-3608		015-91-0608	015-91-5609	60	E																					
	62	78.74	3.100	76.20	3.000	015-91-2620																																		

13		12		11				10		9		8		7		6		5		4		3		2		1	
J		IN TAPE AND REEL WITH SHALLOW POCKET TAPE										BULK / IN TUBES										J					
		PACKAGING SEE NOTE 4. SHT 1		4-8 CKT		TAPE-N-REEL W/ VAC CAPS		TAPE-N-REEL W/ VAC CAPS										BULK		BULK							
				10-100 CKT		TAPE-N-REEL W/ VAC CAPS		TAPE-N-REEL W/ VAC CAPS										TUBES		TUBES							
		DIM. M±0.25 MM				6.10 (.240)		6.10 (.240)										8.13 (.320)		13.59 (.535)							
		PLATING				30 GOLD		15 GOLD										150 TIN		150 TIN							
		DIM. H				2.54 (.100)		2.54 (.100)										4.57 (.180)		4.57 (.180)							
I		CKTS		DIM. A		DIM. B		EDP NUMBER		EDP NUMBER								EDP NUMBER		EDP NUMBER		CKTS					
				MM	IN	MM	IN																				
H		04	5.08	.200	2.54	.100	015-91-6148										713088010		71308-8210								
		06	7.62	.300	5.08	.200																	015-91-6068				
		08	10.16	.400	7.62	.300																	015-91-6088				
		10	12.70	.500	10.16	.400																	015-91-6108				
		12	15.24	.600	12.70	.500																					
		14	17.78	.700	15.24	.600																					
		16	20.32	.800	17.78	.700											713088016										
		18	22.86	.900	20.32	.800																					
		20	25.40	1.000	22.86	.900																					
		G		22	27.94	1.100	25.40	1.000																			
24	30.48			1.200	27.94	1.100																					
26	33.02			1.300	30.48	1.200																					
28	35.56			1.400	33.02	1.300																					
30	38.10			1.500	35.56	1.400																					
32	40.64			1.600	38.10	1.500																					
34	43.18			1.700	40.64	1.600																					
36	45.72			1.800	43.18	1.700																					
38	48.26			1.900	45.72	1.800																					
40	50.80			2.000	48.26	1.900																					
F		42	53.34	2.100	50.80	2.000																					
		44	55.88	2.200	53.34	2.100																					
		46	58.42	2.300	55.88	2.200																					
		48	60.96	2.400	58.42	2.300																					
		50	63.50	2.500	60.96	2.400																					
		52	66.04	2.600	63.50	2.500																					
		54	68.58	2.700	66.04	2.600																					
		56	71.12	2.800	68.58	2.700																					
		58	73.66	2.900	71.12	2.800																					
		60	76.20	3.000	73.66	2.900																					
E		62	78.74	3.100	76.20	3.000																					
		64	81.28	3.200	78.74	3.100																					
		66	83.82	3.300	81.28	3.200																					
		68	86.36	3.400	83.82	3.300																					
		70	88.90	3.500	86.36	3.400																					
		72	91.44	3.600	88.90	3.500																					
		74	93.98	3.700	91.44	3.600																					
		76	96.52	3.800	93.98	3.700																					
		78	99.06	3.900	96.52	3.800																					
		80	101.60	4.000	99.06	3.900																					
D		82	104.14	4.100	101.60	4.000																					
		84	106.68	4.200	104.14	4.100																					
		86	109.22	4.300	106.68	4.200																					
		88	111.76	4.400	109.22	4.300																					
		90	114.30	4.500	111.76	4.400																					
		92	116.84	4.600	114.30	4.500																					
		94	119.38	4.700	116.84	4.600																					
		96	121.92	4.800	119.38	4.700																					
		98	124.46	4.900	121.92	4.800																					
		100	127.00	5.000	124.46	4.900																					
B		NO PEG VERSION										SEE SHEET 1 EC NO: UCP2015-0081 DRAWN BY: CHKD-NGUYEN CHKD-NGUYEN APPR:FSMITH 2014/05/22 2014/11/26 2015/01/08		QUALITY SYMBOLS ▽=0 ▽=0 ▽=0		GENERAL TOLERANCES (UNLESS SPECIFIED)		DIMENSION STYLE MM/IN		SCALE		DESIGN UNITS INCH		THIRD ANGLE PROJECTION			
																DRAWN BY KMS		DATE 1999/10/15		CHECKED BY KMS		DATE 1999/10/15		APPROVED BY KMS		DATE 1999/10/15	
A		(ALSO SEE SHEET 2)										K7		REV		ANGULAR ±1/2° DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS		SIZE C		THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX INCORPORATED AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION		DOCUMENT NO. SD-71308-001		SHEET NO. 3 OF 6			
1b_frame_C_P_AM.T Rev. G 2012/01/11		12		11		10		9		8		7		6		5		4		3		2		1			

13		12		11		10		9		8		7		6		5		4		3		2		1					
J		PACKAGING SEE NOTE 4 SHT 1				4-8 CKT		BULK		TAPE-N-REEL W/ VAC CAPS		BULK		TAPE-N-REEL W/ VAC CAPS		BULK		TAPE-N-REEL W/ VAC CAPS		BULK		BULK		BULK		J			
						10-100 CKT		TUBES		TAPE-N-REEL W/ VAC CAPS		TUBES		TAPE-N-REEL W/ VAC CAPS		TUBES		TAPE-N-REEL W/ VAC CAPS		TUBES		TUBES		TUBES					
						DIM. M±0.25 MM		6.10 (.240)				6.10 (.240)				6.10 (.240)				8.13 (.320)		8.13 (.320)		8.13 (.320)					
						PLATING		150 TIN				15 GOLD				30 GOLD				150 TIN		15 GOLD		30 GOLD					
						DIM. H		2.54 (.100)				2.54 (.100)				2.54 (.100)				4.57 (.180)		4.57 (.180)		4.57 (.180)					
I	CKTS	DIM. A		DIM. B		DIM. C		EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	EDP NUMBER	CKTS				
		MM	IN	MM	IN	MM	IN																						
H	04	5.08	.200	2.54	.100	----	----	015-91-1041	015-91-6044	015-91-1042	015-91-6045	015-91-1043	015-91-6046	015-91-1044	015-91-0047	015-91-1040			04										
	06	7.62	.300	5.08	.200	2.54	.100	015-91-1061	015-91-6064	015-91-1062	015-91-6065	015-91-1063	015-91-6066	015-91-1064	015-91-0067	015-91-1060			06										
	08	10.16	.400	7.62	.300	5.08	.200	015-91-1081	015-91-6084	015-91-1082	015-91-6085	015-91-1083	015-91-6086	015-91-1084	015-91-0087	015-91-1080			08										
	10	12.70	.500	10.16	.400	7.62	.300	015-91-1101	015-91-6104	015-91-1102	015-91-6105	015-91-1103	015-91-6106	015-91-1104	015-91-0107	015-91-1100			10										
	12	15.24	.600	12.70	.500	10.16	.400	015-91-1121		015-91-1122		015-91-1123		015-91-1124	015-91-0127	015-91-1120			12										
	14	17.78	.700	15.24	.600	12.70	.500	015-91-1141	015-91-6144	015-91-1142	015-91-6145	015-91-1143	015-91-6146	015-91-1144	015-91-0147	015-91-1140			14										
	16	20.32	.800	17.78	.700	15.24	.600	015-91-1161	015-91-6164	015-91-1162	015-91-6165	015-91-1163	015-91-6166	015-91-1164	015-91-0167	015-91-1160			16										
	18	22.86	.900	20.32	.800	17.78	.700	015-91-1181		015-91-1182		015-91-1183		015-91-1184	015-91-0187	015-91-1180			18										
	20	25.40	1.000	22.86	.900	20.32	.800	015-91-1201		015-91-1202		015-91-1203		015-91-1204	015-91-0207	015-91-1200			20										
	22	27.94	1.100	25.40	1.000	22.86	.900	015-91-1221		015-91-1222		015-91-1223		015-91-1224	015-91-0227	015-91-1220			22										
G	24	30.48	1.200	27.94	1.100	25.40	1.000	015-91-1241	71308-6901	015-91-1242		015-91-1243		015-91-1244	015-91-0247	015-91-1240			24										
	26	33.02	1.300	30.48	1.200	27.94	1.100	015-91-1261		015-91-1262		015-91-1263		015-91-1264	015-91-0267	015-91-1260			26										
	28	35.56	1.400	33.02	1.300	30.48	1.200	015-91-1281		015-91-1282		015-91-1283		015-91-1284	015-91-0287	015-91-1280			28										
	30	38.10	1.500	35.56	1.400	33.02	1.300	015-91-1301		015-91-1302		015-91-1303		015-91-1304	015-91-0307	015-91-1300			30										
	32	40.64	1.600	38.10	1.500	35.56	1.400	015-91-1321		015-91-1322		015-91-1323		015-91-1324	015-91-0327	015-91-1320			32										
	34	43.18	1.700	40.64	1.600	38.10	1.500	015-91-1341		015-91-1342		015-91-1343		015-91-1344	015-91-0347	015-91-1340			34										
	36	45.72	1.800	43.18	1.700	40.64	1.600	015-91-1361		015-91-1362		015-91-1363		015-91-1364	015-91-0367	015-91-1360			36										
	38	48.26	1.900	45.72	1.800	43.18	1.700	015-91-1381		015-91-1382		015-91-1383		015-91-1384	015-91-0387	015-91-1380			38										
	40	50.80	2.000	48.26	1.900	45.72	1.800	015-91-1401		015-91-1402		015-91-1403		015-91-1404	015-91-0407	015-91-1400			40										
	42	53.34	2.100	50.80	2.000	48.26	1.900	015-91-1421		015-91-1422		015-91-1423		015-91-1424	015-91-0427	015-91-1420			42										
F	44	55.88	2.200	53.34	2.100	50.80	2.000	015-91-1441		015-91-1442		015-91-1443		015-91-1444	015-91-0447	015-91-1440			44										
	46	58.42	2.300	55.88	2.200	53.34	2.100	015-91-1461		015-91-1462		015-91-1463		015-91-1464	015-91-0467	015-91-1460			46										
	48	60.96	2.400	58.42	2.300	55.88	2.200	015-91-1481		015-91-1482		015-91-1483		015-91-1484	015-91-0487	015-91-1480			48										
	50	63.50	2.500	60.96	2.400	58.42	2.300	015-91-1501	015-91-6504	015-91-1502	015-91-6505	015-91-1503	015-91-6506	015-91-1504	015-91-0507	015-91-1500			50										
	52	66.04	2.600	63.50	2.500	60.96	2.400	015-91-1521		015-91-1522		015-91-1523	71308-5203	015-91-1524	015-91-0527	015-91-1520			52										
	54	68.58	2.700	66.04	2.600	63.50	2.500	015-91-1541		015-91-1542		015-91-1543		015-91-1544	015-91-0547	015-91-1540			54										
	56	71.12	2.800	68.58	2.700	66.04	2.600	015-91-1561		015-91-1562		015-91-1563		015-91-1564	015-91-0567	015-91-1560			56										
	58	73.66	2.900	71.12	2.800	68.58	2.700	015-91-1581		015-91-1582		015-91-1583		015-91-1584	015-91-0587	015-91-1580			58										
	60	76.20	3.000	73.66	2.900	71.12	2.800	015-91-1601		015-91-1602		015-91-1603		015-91-1604	015-91-0607	015-91-1600			60										
	62	78.74	3.100	76.20	3.000	73.66	2.900	015-91-1621		015-91-1622		015-91-1623		015-91-1624	015-91-0627	015-91-1620			62										
E	64	81.28	3.200	78.74	3.100	76.20	3.000	015-91-1641		015-91-1642		015-91-1643		015-91-1644	015-91-0647	015-91-1640			64										
	66	83.82	3.300	81.28	3.200	78.74	3.100	015-91-1661		015-91-1662		015-91-1663		015-91-1664	015-91-0667	015-91-1660			66										
	68	86.36	3.400	83.82	3.300	81.28	3.200	015-91-1681		015-91-1682		015-91-1683		015-91-1684	015-91-0687	015-91-1680			68										
	70	88.90	3.500	86.36	3.400	83.82	3.300	015-91-1701		015-91-1702		015-91-1703		015-91-1704	015-91-0707	015-91-1700			70										
	72	91.44	3.600	88.90	3.500	86.36	3.400	015-91-1721		015-91-1722		015-91-1723		015-91-1724	015-91-0727	015-91-1720			72										
	74	93.98	3.700	91.44	3.600	88.90	3.500	015-91-1741		015-91-1742		015-91-1743		015-91-1744	015-91-0747	015-91-1740			74										
	76	96.52	3.800	93.98	3.700	91.44	3.600	015-91-1761		015-91-1762		015-91-1763		015-91-1764	015-91-0767	015-91-1760			76										
	78	99.06	3.900	96.52	3.800	93.98	3.700	015-91-1781		015-91-1782		015-91-1783		015-91-1784	015-91-0787	015-91-1780			78										
	80	101.60	4.000	99.06	3.900	96.52	3.800	015-91-1801		015-91-1802		015-91-1803		015-91-1804	015-91-0807	015-91-1800			80										
	82	104.14	4.100	101.60	4.000	99.06	3.900	71308-4082		71308-4182		71308-4282		71308-5082	71308-5182	71308-5282			82										
C	84	106.68	4.200	104.14	4.100	101.60	4.000	71308-4084		71308-4184		71308-4284		71308-5084	71308-5184	71308-5284			84										
	86	109.22	4.300	106.68	4.200	104.14	4.100	71308-4086		71308-4186		71308-4286		71308-5086	71308-5186	71308-5286			86										
	88	111.76	4.400	109.22	4.300	106.68	4.200	71308-4088		71308-4188		71308-4288		71308-5088	71308-5188	71308-5288			88										
	90	114.30	4.500	111.76	4.400	109.22	4.300	71308-4090		71308-4190		71308-4290		71308-5090	71308-5190	71308-5290			90										
	92	116.84	4.600	114.30	4.500	111.76	4.400	71308-4092		71308-4192		71308-4292		71308-5092	71308-5192	71308-5292			92										
	94	119.38	4.700	116.84	4.600	114.30	4.500	71308-4094		71308-4194		71308-4294		71308-5094	71308-5194	71308-5294			94										
	96	121.92	4.800	119.38	4.700	116.84	4.600	71308-4096		7																			

13		12		11		10		9		8		7		6		5		4		3		2		1																			
J			PACKAGING SEE NOTE 4 SHT 1		4-8 CKT		BULK		TAPE-N-REEL W/ VAC CAPS		BULK		TAPE-N-REEL W/ VAC CAPS		TAPE-N-REEL W/ VAC CAPS																												
					10-100 CKT		TUBES		TAPE-N-REEL W/ VAC CAPS		TUBES		TAPE-N-REEL W/ VAC CAPS		TAPE-N-REEL W/ VAC CAPS																												
			DIM. M±0.25 MM		6.10 (.240)		6.10 (.240)		8.13 (.320)																																		
			PLATING		30 GOLD		150 TIN		150 TIN																																		
			DIM. H		2.54 (.100)		2.54 (.100)		4.57 (.180)																																		
I	CKTS	DIM. A		DIM. B		DIM. C		EDP NUMBER		EDP NUMBER		EDP NUMBER		EDP NUMBER		EDP NUMBER		EDP NUMBER		EDP NUMBER		EDP NUMBER		CKTS																			
		MM	IN	MM	IN	MM	IN																																				
H	04	5.08	.200	2.54	.100	----	----	015-91-1048	015-91-6047														04																				
	06	7.62	.300	5.08	.200	2.54	.100	015-91-1068	015-91-6067	71308-6106	71308-6206											06																					
	08	10.16	.400	7.62	.300	5.08	.200	015-91-1088	015-91-6087	71308-6108	71308-6208											08																					
	10	12.70	.500	10.16	.400	7.62	.300	015-91-1108	015-91-6107	71308-6110	71308-6210											10																					
	12	15.24	.600	12.70	.500	10.16	.400	015-91-1128														12																					
	14	17.78	.700	15.24	.600	12.70	.500	015-91-1148	015-91-6147													14																					
	16	20.32	.800	17.78	.700	15.24	.600	015-91-1168	015-91-6167													16																					
	18	22.86	.900	20.32	.800	17.78	.700	015-91-1188															18																				
	20	25.40	1.000	22.86	.900	20.32	.800	015-91-1208	015-91-6207														20																				
	22	27.94	1.100	25.40	1.000	22.86	.900	015-91-1228															22																				
G	24	30.48	1.200	27.94	1.100	25.40	1.000	015-91-1248															24																				
	26	33.02	1.300	30.48	1.200	27.94	1.100	015-91-1268		71308-6126		71308-8426										26																					
	28	35.56	1.400	33.02	1.300	30.48	1.200	015-91-1288														28																					
	30	38.10	1.500	35.56	1.400	33.02	1.300	015-91-1308														30																					
	32	40.64	1.600	38.10	1.500	35.56	1.400	015-91-1328														32																					
	34	43.18	1.700	40.64	1.600	38.10	1.500	015-91-1348														34																					
	36	45.72	1.800	43.18	1.700	40.64	1.600	015-91-1368														36																					
	38	48.26	1.900	45.72	1.800	43.18	1.700	015-91-1388														38																					
	40	50.80	2.000	48.26	1.900	45.72	1.800	015-91-1408														40																					
	42	53.34	2.100	50.80	2.000	48.26	1.900	015-91-1428														42																					
F	44	55.88	2.200	53.34	2.100	50.80	2.000	015-91-1448														44																					
	46	58.42	2.300	55.88	2.200	53.34	2.100	015-91-1468														46																					
	48	60.96	2.400	58.42	2.300	55.88	2.200	015-91-1488														48																					
	50	63.50	2.500	60.96	2.400	58.42	2.300	015-91-1508	015-91-6507													50																					
	52	66.04	2.600	63.50	2.500	60.96	2.400	015-91-1528														52																					
	54	68.58	2.700	66.04	2.600	63.50	2.500	015-91-1548														54																					
	56	71.12	2.800	68.58	2.700	66.04	2.600	015-91-1568														56																					
	58	73.66	2.900	71.12	2.800	68.58	2.700	015-91-1588														58																					
	60	76.20	3.000	73.66	2.900	71.12	2.800	015-91-1608														60																					
	62	78.74	3.100	76.20	3.000	73.66	2.900	015-91-1628														62																					
E	64	81.28	3.200	78.74	3.100	76.20	3.000	015-91-1648														64																					
	66	83.82	3.300	81.28	3.200	78.74	3.100	015-91-1668														66																					
	68	86.36	3.400	83.82	3.300	81.28	3.200	015-91-1688														68																					
	70	88.90	3.500	86.36	3.400	83.82	3.300	015-91-1708														70																					
	72	91.44	3.600	88.90	3.500	86.36	3.400	015-91-1728														72																					
	74	93.98	3.700	91.44	3.600	88.90	3.500	015-91-1748														74																					
	76	96.52	3.800	93.98	3.700	91.44	3.600	015-91-1768														76																					
	78	99.06	3.900	96.52	3.800	93.98	3.700	015-91-1788														78																					
	80	101.60	4.000	99.06	3.900	96.52	3.800	015-91-1808														80																					
	82	104.14	4.100	101.60	4.000	99.06	3.900	71308-6082														82																					
D	84	106.68	4.200	104.14	4.100	101.60	4.000	71308-6084														84																					
	86	109.22	4.300	106.68	4.200	104.14	4.100	71308-6086														86																					
	88	111.76	4.400	109.22	4.300	106.68	4.200	71308-6088														88																					
	90	114.30	4.500	111.76	4.400	109.22	4.300	71308-6090														90																					
	92	116.84	4.600	114.30	4.500	111.76	4.400	71308-6092														92																					
	94	119.38	4.700	116.84	4.600	114.30	4.500	71308-6094														94																					
	96	121.92	4.800	119.38	4.700	116.84	4.600	71308-6096														96																					
	98	124.46	4.900	121.92	4.800	119.38	4.700	71308-6098														98																					
	100	127.00	5.000	124.46	4.900	121.92	4.800	71308-6100														100																					
	B	SHORT PEG VERSION (.055")																								REMOVE 15-91-6407 EC NO: UCP2015-0081 DRAWN:KIPPER 2014/05/22 CHKD:NGUYEN 2014/11/26 APPR:FSM/ITH 2015/01/08	REV	K7	DESCRIPTION	QUALITY SYMBOLS ▽=0 ▽=0 ▽=0	GENERAL TOLERANCES (UNLESS SPECIFIED)		DIMENSION STYLE MM/IN		SCALE	DESIGN UNITS INCH	THIRD ANGLE PROJECTION		TITLE SALES ASSY INSULATOR DUAL ROW SMT W/BREAK-OFF .025SQ PIN GULLWING .100 molex	DOCUMENT NO. SD-71308-001	SHEET NO. 5 OF 6		
DRAWN BY DATE KMS 1999/10/15																															CHECKED BY DATE KMS 1999/10/15		APPROVED BY DATE KMS 1999/10/15										
A																									K7	REV	DESCRIPTION	QUALITY SYMBOLS ▽=0 ▽=0 ▽=0	ANGULAR ±1/2°		DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS		SIZE C	THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX INCORPORATED AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION									
1b_frame_C_P_AM.T Rev. G 2012/01/11		12		11		10		9		8		7		6		5		4		3		2		1																			

		13		12		11		10		9		8		7		6		5		4		3		2		1									
J		PACKAGING SEE NOTE 4, SHT 1		4-6 CKT		BULK		TAPE-N-REEL W/VAC CAPS		N/A		4-8 CKT		TAPE-N-REEL W/VAC CAPS		BULK		BULK		BULK		TAPE-N-REEL W/VAC CAPS		BULK		BULK		TAPE-N-REEL W/ VAC CAPS							
						TUBES		TAPE-N-REEL W/VAC CAPS		TUBES W/ VAC CAPS				10-100 CKT		TAPE-N-REEL W/VAC CAPS		TUBES		TUBES		TUBES		TAPE-N-REEL W/VAC CAPS		TUBES		BULK		TAPE-N-REEL W/ VAC CAPS					
				8-100 CKT		DIM. M±0.25 MM		6.10 (.240)						8.13(.320)		13.59(.535)		6.10(.240)		8.13(.320)		6.10 (.240)													
						PLATING		59 TIN						59 TIN		59 TIN		59 TIN		59 TIN		59 TIN													
						DIM. H		2.54(.100)						4.57(.180)		4.57(.180)		2.54(.100)		4.57(.180)		2.54(.100)													
I		CKTS		DIM. A		DIM. B		DIM. C		EDP NUMBER		EDP NUMBER		EDP NUMBER		EDP NUMBER		EDP NUMBER		EDP NUMBER		EDP NUMBER		EDP NUMBER		EDP NUMBER		EDP NUMBER		CKTS					
				MM IN		MM IN		MM IN																											
H		04		5.08 .200		2.54 .100		---		---		71308-5404		71308-5504		N/A				71308-6404		71308-6504		71308-6604		71308-6706		71308-6806		04					
		06		7.62 .300		5.08 .200		2.54 .100		71308-5406		71308-5506		N/A						71308-6406		71308-6506		71308-6606		71308-6708		71308-6808		06					
		08		10.16 .400		7.62 .300		5.08 .200		71308-5408		71308-5508		71308-5608						71308-6408		71308-6508		71308-6608		71308-6710		71308-6810		08					
		10		12.70 .500		10.16 .400		7.62 .300		71308-5410		71308-5510		71308-5610				71308-5810		71308-5910		71308-6410		71308-6510		71308-6610		71308-6710		10					
		12		15.24 .600		12.70 .500		10.16 .400		71308-5412		71308-5512		71308-5612								71308-6412		71308-6512		71308-6612				12					
		14		17.78 .700		15.24 .600		12.70 .500		71308-5414		71308-5514		71308-5614								71308-6414		71308-6514		71308-6614				14					
		16		20.32 .800		17.78 .700		15.24 .600		71308-5416		71308-5516		71308-5616				71308-5816				71308-6416		71308-6516		71308-6616				16					
		18		22.86 .900		20.32 .800		17.78 .700		71308-5418				71308-5618								71308-6418				71308-6618				18					
		20		25.40 1.000		22.86 .900		20.32 .800		71308-5420		71308-5520		71308-5620								71308-6420				71308-6620				20					
		22		27.94 1.100		25.40 1.000		22.86 .900		71308-5422				71308-5622								71308-6422				71308-6622				22					
G		24		30.48 1.200		27.94 1.100		25.40 1.000		71308-5424				71308-5624		71308-5724		71308-5824		71308-6424				71308-6624						24					
		26		33.02 1.300		30.48 1.200		27.94 1.100		71308-5426				71308-5626								71308-6426				71308-6626		71308-6726		26					
		28		35.56 1.400		33.02 1.300		30.48 1.200		71308-5428				71308-5628								71													