
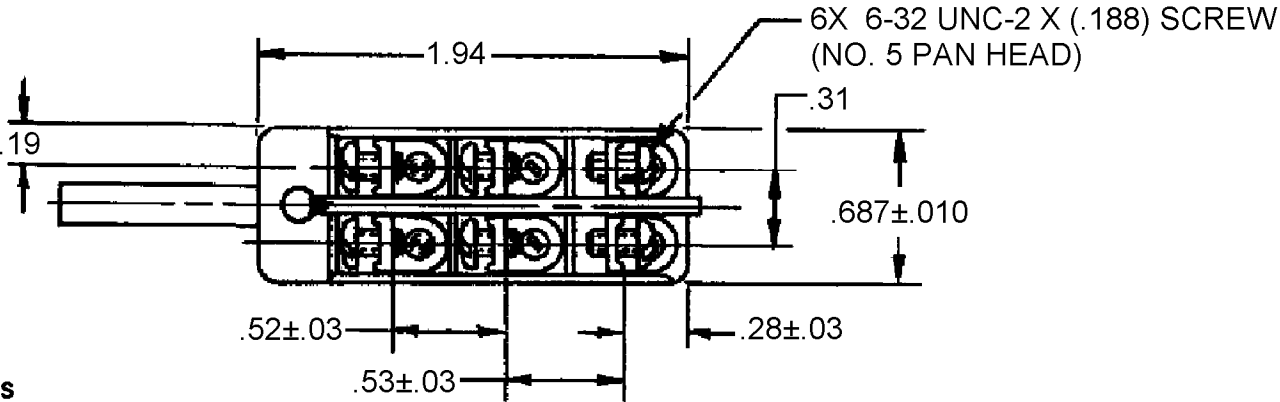


HONEYWELL PART NUMBER
DT-2RV49-B6
PRODUCT CODE
AZF3052

REV	DOCUMENT	CHANGED BY	CHECK
2	0064802	PRS 24MAY10	CMH

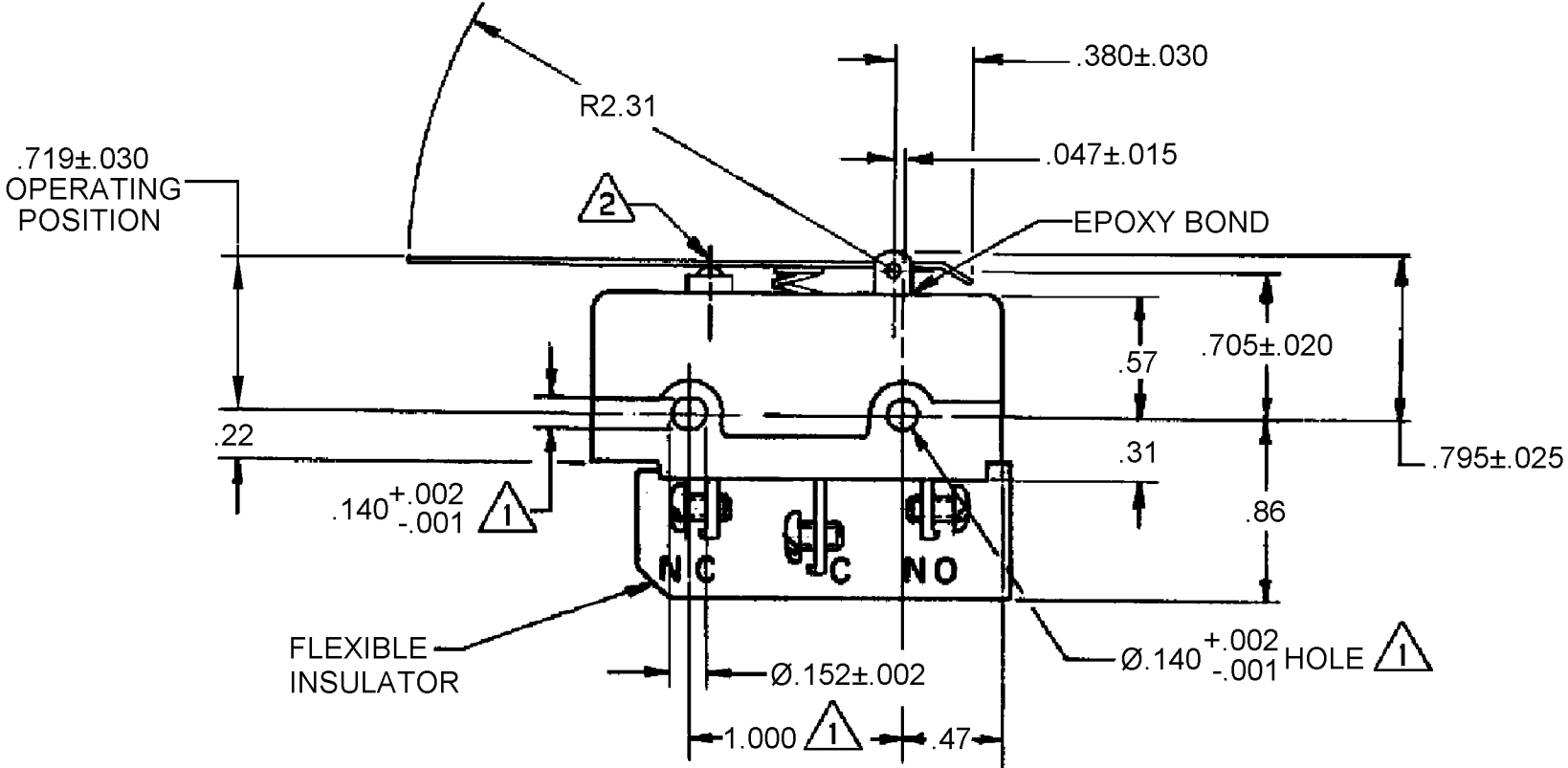

- NOTES:
- 1 - MOUNTING HOLES WILL ACCEPT PINS OR SCREWS OF Ø.139 MAX ON 1.000±.002 CENTERS
 - 2 - OVERTRAVEL TO BE MEASURED AT CENTERLINE OF PLUNGER
 - 3 - RELEASE NO. : PR-24108
 - 4 - REPLACES: X111847-DT

CHARACTERISTICS	ELECTRICAL DATA
OPERATING FORCE-----14 OZ MAX	CONTACT ARRANGEMENT D P D T
RELEASE FORCE----- 3 1/2 OZ MIN	
DIFFERENTIAL TRAVEL----- .100 - .175	
OVERTRAVEL----- 2 .010 MIN	
	L59 10A 125 OR 250 VAC 0.3A 125 VDC, 0.15A 250 VDC

DESIGN UNITS: INCH			
TOLERANCES UNLESS NOTED:			
NO PLACES	x	±	-
ONE PLACE	.x	±	.030
TWO PLACE	.xx	±	.015
THREE PLACE	.xxx	±	.005
ANGLES	x	±	-
THIRD ANGLE PROJECTION			

DRAWN	JJA	28JUN99
CHECK	JAF	28JUN99
THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF HONEYWELL. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE PERMISSION OF HONEYWELL.		
INTERPRET PER ASME Y14.5M-1994 OTHER HONEYWELL ENGINEERING STANDARDS MAY APPLY		
RASTER		

Honeywell					
TITLE SWITCH - BASIC					
SIZE	TYPE	CAGE CODE	DRAWING NAME	REV	
B	I	-	DT-2RV49-B6	2	
SCALE NONE		SHEET 1 OF 1			