

THIS DRAWING IS UNPUBLISHED.

RELEASED FOR PUBLICATION

ALL RIGHTS RESERVED.

© COPYRIGHT - By -

LOC  
H

DIST  
-

REVISIONS

P LTR

DESCRIPTION

DATE

DWN

APVD




A

INITIAL DRAWING


04FEB2015

GSK

BvH

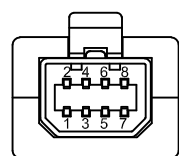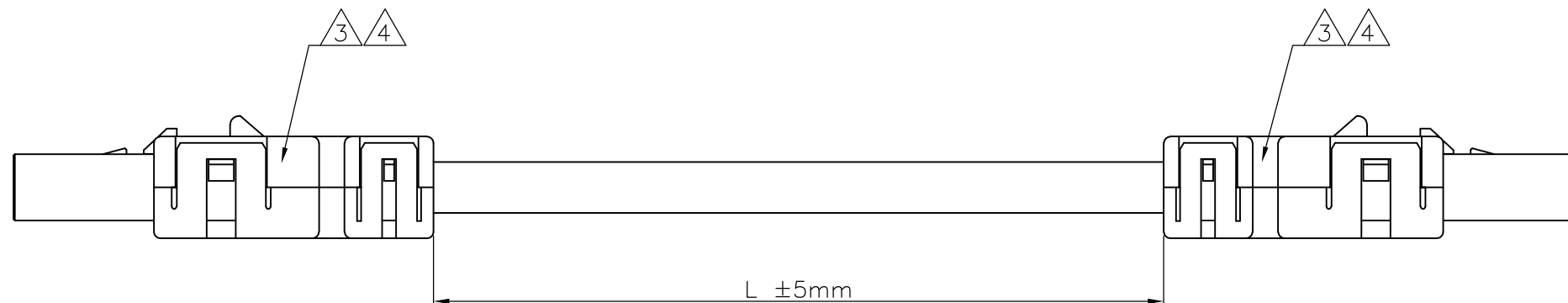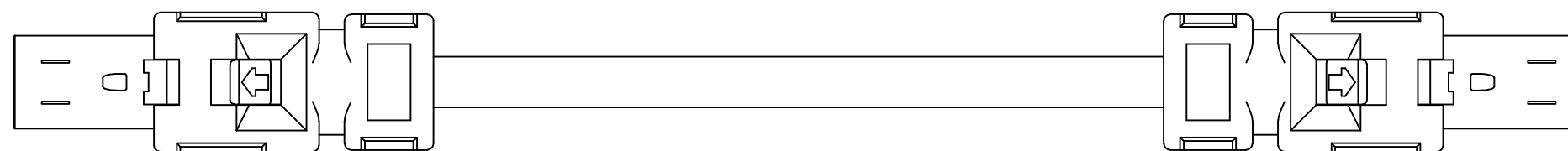

VIEW A

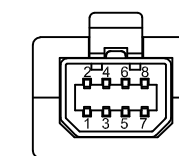

VIEW B

NOTES:

- 1 PACKAGING: ACC. TO TE SPEC. 107-18032
- 2 ELECTRICAL TEST ACCORDING TE SPECIFICATION 108-18857.  
SHORT-CIRCUIT AND CONTINUITY TEST AT 500V DC, 0.1s
- 3 KEEP THE DIRECTION OF CONNECTOR TO THE CABLE ON BOTH SIDE THE SAME
- 4 WIRING SCHEMA ACC. TO TIA/EIA-568-B AS SHOWN IN WIRING SCHEDULE

WIRING SCHEDULE

| CAVITY SIDE A | COLOR | CAVITY SIDE B |
|---------------|-------|---------------|
| 1             | WH/OG | 1             |
| 2             | OG    | 2             |
| 3             | WH/GN | 3             |
| 4             | BU    | 4             |
| 5             | WH/BU | 5             |
| 6             | GN    | 6             |
| 7             | WH/BN | 7             |
| 8             | BN    | 8             |

|          |                              |             |
|----------|------------------------------|-------------|
| 10       | HiFlex MultiPurpose 70°C PUR | 2-2205132-6 |
| 5        | HiFlex MultiPurpose 70°C PUR | 2-2205132-5 |
| 3        | HiFlex MultiPurpose 70°C PUR | 2-2205132-4 |
| 2        | HiFlex MultiPurpose 70°C PUR | 2-2205132-3 |
| 1        | HiFlex MultiPurpose 70°C PUR | 2-2205132-2 |
| 0.5      | HiFlex MultiPurpose 70°C PUR | 2-2205132-1 |
| 10       | HI 125°C TPE                 | 1-2205132-6 |
| 5        | HI 125°C TPE                 | 1-2205132-5 |
| 3        | HI 125°C TPE                 | 1-2205132-4 |
| 2        | HI 125°C TPE                 | 1-2205132-3 |
| 1        | HI 125°C TPE                 | 1-2205132-2 |
| 0.5      | HI 125°C TPE                 | 1-2205132-1 |
| 10       | STD 110°C PVC                | 2205132-6   |
| 5        | STD 110°C PVC                | 2205132-5   |
| 3        | STD 110°C PVC                | 2205132-4   |
| 2        | STD 110°C PVC                | 2205132-3   |
| 1        | STD 110°C PVC                | 2205132-2   |
| 0.5      | STD 110°C PVC                | 2205132-1   |
| Length/m | Cable version                | TE PN       |

|  |  |                                   |                                    |                 |
|--|--|-----------------------------------|------------------------------------|-----------------|
| THIS DRAWING IS A CONTROLLED DOCUMENT.   |  | DWN 04FEB2015<br>SATHISH KUMAR .G | TE Connectivity                    |                 |
| DIMENSIONS: mm   |  | CHK 04FEB2015<br>B.VELDHOVEN      |                                    |                 |
| TOLERANCES UNLESS OTHERWISE SPECIFIED:   |  | APVD 04FEB2015<br>A.VAN ZANDVOORT | NAME<br>CA MINI IO MINI IO TYPE II |                 |
| 0 PLC ± -  |  | PRODUCT SPEC<br>108-78955         | SIZE                               |                 |
| 1 PLC ± -  |  | APPLICATION SPEC<br>114-5506      | CAGE CODE                          |                 |
| 2 PLC ± -  |  | WEIGHT<br>-                       | DRAWING NO<br>A3 00779 C-2205132   |                 |
| 3 PLC ± -  |  | CUSTOMER DRAWING                  | RESTRICTED TO<br>-                 |                 |
| 4 PLC ± -  |  |                                   | SCALE<br>NTS                       | SHEET<br>1 OF 1 |
| ANGLES ± 1°  |  |                                   |                                    |                 |
| FINISH   |  |                                   |                                    |                 |
| MATERIAL   |  |                                   |                                    |                 |
| PRODUCT CHARACTERISTIC ACC. OMP EMEA_12<br>BESONDERE MERKMALE NACH OMP EMEA_12 |  |                                   |                                    |                 |