


Contractor Series

RACK ENCLOSURE DIMENSIONS

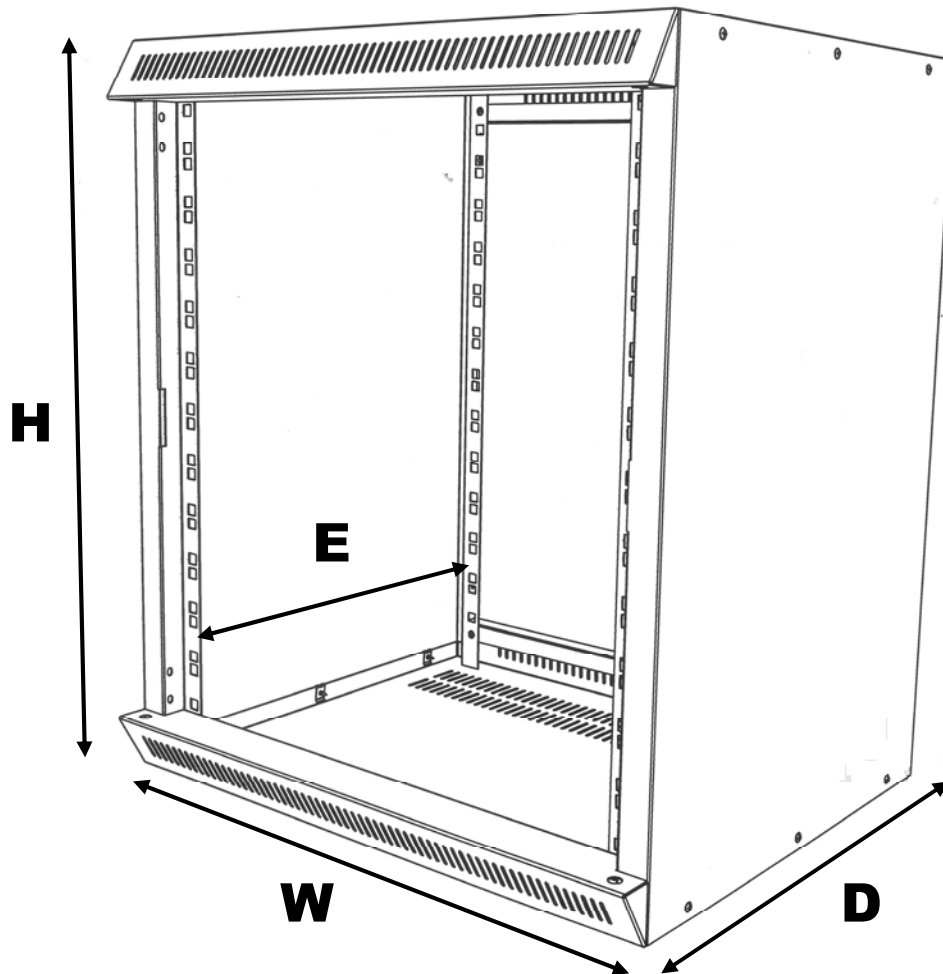

Rack Space R	Max Height H	WMR Wall Rack Depth	WMR-300 Wall Depth	Contractor Depth Depth	Contractor 600 Depth	Mounting Depth E				Max Width W
						250	300	STD	600	
2U Hi	138	-	-	453	-	-	-	393	560	543
4U Hi	219	-	-	453	-	-	-	393	560	543
6U Hi	308	250	300	453	596	220	225	393	560	543
8U Hi	397	250	300	453	596	220	225	393	560	543
12U Hi	634	-	300	457	600	-	225	393	560	543
16U Hi	814	-	300	457	600	-	225	393	560	543
20U Hi	991	-	-	457	600	-	-	393	560	543
24U Hi	1169	-	-	457	600	-	-	393	560	543
28U Hi	1347	-	-	457	600	-	-	393	560	543
32U Hi	1525	-	-	457	600	-	-	393	560	543
35U Hi	1658	-	-	457	600	-	-	393	560	543