


1

2

3

4

5

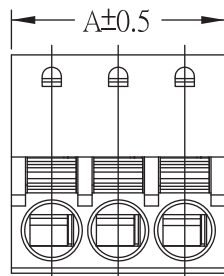

Pitch:3.81mm	
Poles	A(mm)
2	8.42
3	12.23
4	16.04
5	19.85
6	23.66
7	27.47
8	31.28
9	35.09
10	38.90
11	42.71
12	46.52

TECHNICAL CHARACTERISTICS

MATERIAL
INSULATOR: PA 66
FLAMABILITY RATING: UL94-V0
COLOR: GREEN & ORANGE
METAL SPRING: STAINLESS STRIP STEEL
WIRE GUARD: PbZn TIN PLATED

ENVIRONMENTAL
OPERATING TEMPERATURE: -40 UP TO 115°C
COMPLIANCE: LEAD FREE AND ROHS

ELECTRICAL
CURRENT RATING: 8A
WORKING VOLTAGE: 300VAC
WITHSTANDING VOLTAGE: 2.0KV
CONTACT RESISTANCE: 20 mOhm max



STANDARD
ULus CERTIFIED E315414 / Model number 69136830

MECHANICAL
SOLID WIRE: 28-16 AWG / 0.08-1.3MM²
STRANDED WIRE: 28-16 AWG / 0.08-1.3MM²

WIRE STRIPE LENGTH: 9MM
PITCH: 3.81MM

PACKAGING: BOX

SERIE 368B

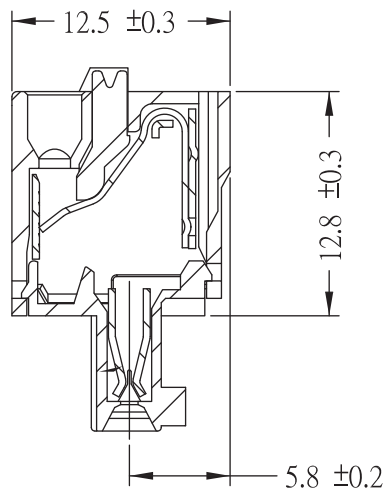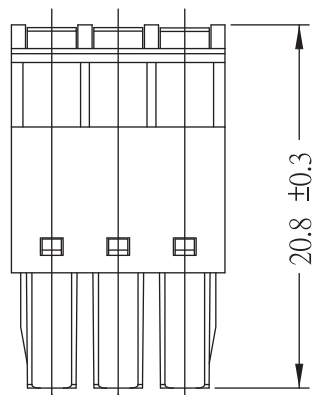


3.81 ±0.1

20.8 ±0.3

5.8 ±0.2

RoHS Compliant

 PROJECTION:



GENERAL TOLERANCE

.X = ± 0.2 .XX = ± 0.15 

WÜRTH ELEKTRONIK

APPROVAL: RJ

UNIT: MM

SCALE:

SHEET: 1/1

DRAW: MARVIN

DESCRIPTION: SERIE 368B - 3.81MM Scwless Vertical Cable Entry Plug -
1,3 mm² Wire

WERI PART NO: 691 368 300 0xx B

SIZE

A4

REV	DATE	FILE	BY
A	20-JUN-12	PDF	GG
B	02-JUL-13	STANDARD POLES	QL
C			
D			
E			
F			
G			