

8 7 6 5 4 3 2 1

RESETABLE CIRCUIT
BREAKER

PILOT LIGHT

482.60 mm
[19.000 in]

43.64 mm
[1.718 in]

165.10 mm
[6.500 in]

50.80 mm TYP
[2.000 in]

ASSEMBLY - VIEW FROM FRONT

19.05 mm
[0.750 in]

444.50 mm
[17.500 in]

5.08 mm
[0.200 in]

67.58 mm
[2.661 in]

A

A

6' FOOT
POWER CORD
(NEMA 5-20P)

ASSEMBLY - VIEW FROM BOTTOM

10.31 mm
[0.406 in]

461.98 mm
[18.188 in]


5.97 mm
[0.235 in]

31.70 mm
[1.248 in]


127.00 mm
[5.000 in]

SECTION A-A

R3.18 mm
[0.125 in]

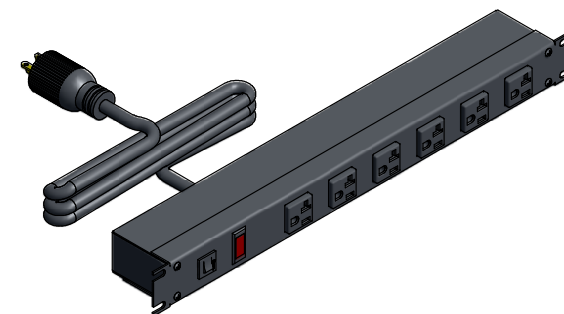

ISOMETRIC VIEW

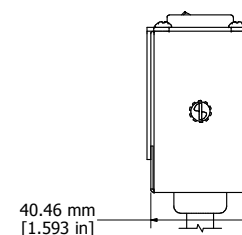

ASSEMBLY - VIEW FROM SIDE

1589T6F1BKRF

Finish - Front - Black Painted Steel

Back - Black Painted Steel

Rated - 125 VAC, 60 Hz, 20 Amps

Approvals - CSA Certified Standards C22.2 (No. 21-95, 42-99)

- UL Recognized Standard UL 1363



HAMMOND
MANUFACTURING™

1589T6F1BKRF

www.hammondmfg.com

8 7 6 5 4 3 2 1