


Har-Flex female 32pole, with Strain relief, PL2

C1

Har-Flex 32P female connector

C2

Har-Flex 32P female connector

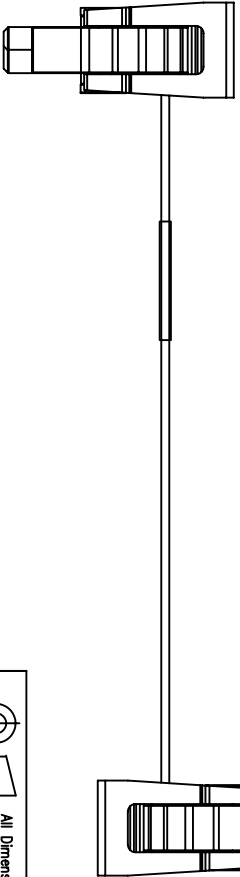

Part-No./产品号码	Length/长度
33 15 243 050 0012 .00	500±5
33 15 243 020 0011 .00	200±3
33 15 243 010 0010 .00	100±3

- NOTES/要求:
- 1.) CABLE MUST BE PERFORMED 100% CONTINUITY TEST AND HI-POT (300VDC) TEST.
 - 2.) CABLE OPERATION TEMPERATURE=-30° C TO +105° C.
 - 3.) WHITE LABEL CONTENT:

DATE CODE & LOT INFORMATION
HARTING P/N & REVISION

Rev.	Description	Appr.	Date
01	Add side view.	Lucy.Z	15/04/13
00	Prototype	Andr-ew.H	24/05/11

All Dimensions in mm Original Size DIN A4		Ref: MB Mat: SEE BILL OF MATERIAL	
Free size tol.	cm ³	A=	cm ²
V=	Name	Date	Scale
Detail			Sheet
Insp.			1 of 1
Approved			
HARTING (Zhuohai) Manufacturing Co., Ltd 		Title Har-Flex female 32pole, double ended Flat cable assembly, L=xMM	

DWG. No.	TB_33 15 0004 .01
----------	-------------------