

 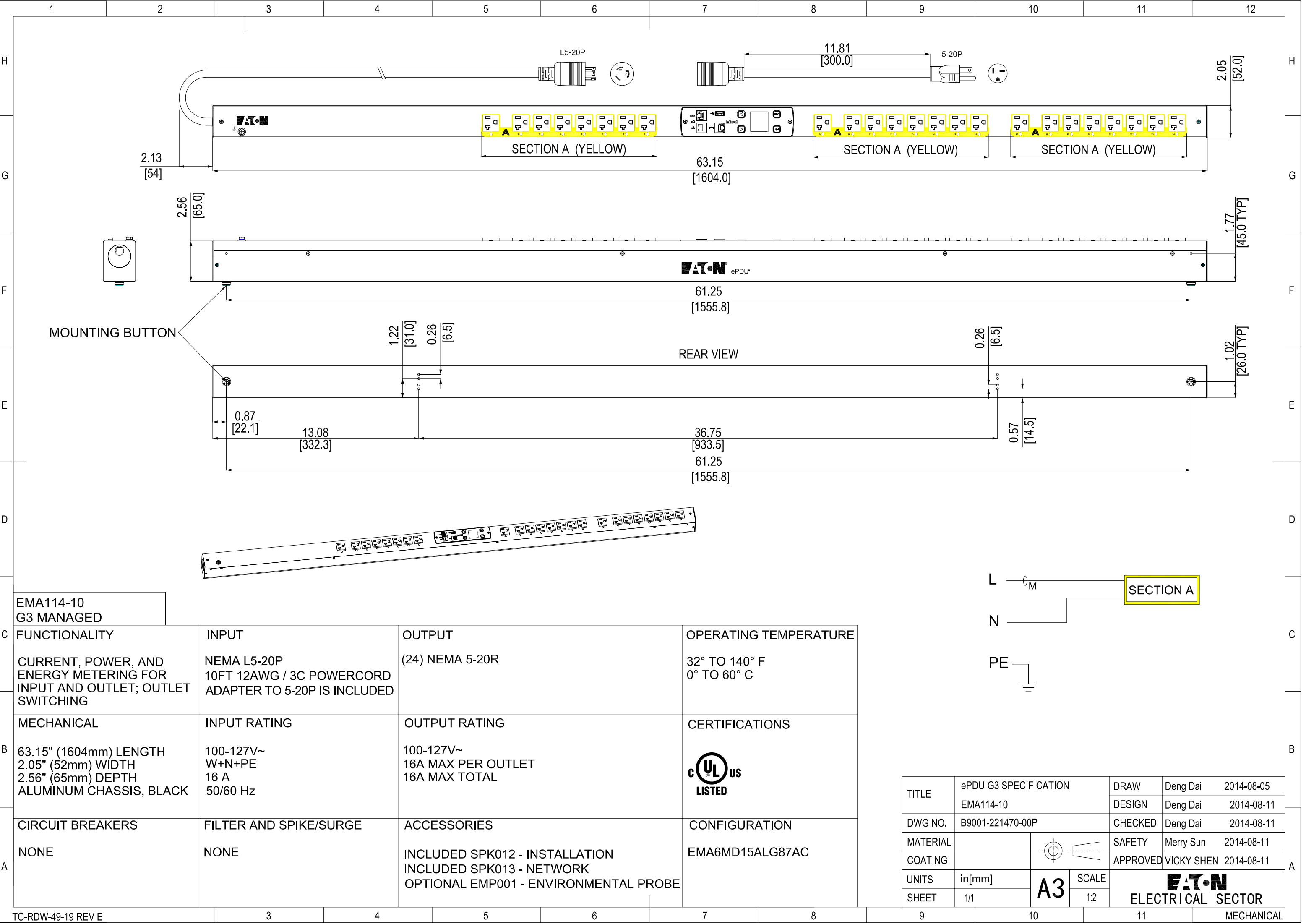


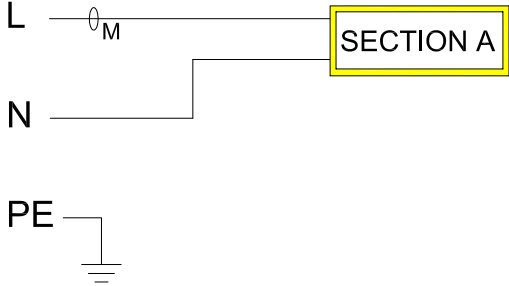

EMA114-10
G3 MANAGED

C	FUNCTIONALITY	INPUT	OUTPUT	OPERATING TEMPERATURE
	CURRENT, POWER, AND ENERGY METERING FOR INPUT AND OUTLET; OUTLET SWITCHING	NEMA L5-20P 10FT 12AWG / 3C POWERCORD ADAPTER TO 5-20P IS INCLUDED	(24) NEMA 5-20R	32° TO 140° F 0° TO 60° C
B	MECHANICAL	INPUT RATING	OUTPUT RATING	CERTIFICATIONS
	63.15" (1604mm) LENGTH 2.05" (52mm) WIDTH 2.56" (65mm) DEPTH ALUMINUM CHASSIS, BLACK	100-127V~ W+N+PE 16 A 50/60 Hz	100-127V~ 16A MAX PER OUTLET 16A MAX TOTAL	
A	CIRCUIT BREAKERS	FILTER AND SPIKE/SURGE	ACCESSORIES	CONFIGURATION
	NONE	NONE	INCLUDED SPK012 - INSTALLATION INCLUDED SPK013 - NETWORK OPTIONAL EMP001 - ENVIRONMENTAL PROBE	EMA6MD15ALG87AC



TITLE	ePDU G3 SPECIFICATION EMA114-10	DRAW	Deng Dai	2014-08-05
DWG NO.	B9001-221470-00P	DESIGN	Deng Dai	2014-08-11
MATERIAL		CHECKED	Deng Dai	2014-08-11
COATING		SAFETY	Merry Sun	2014-08-11
UNITS	in[mm]	APPROVED	VICKY SHEN	2014-08-11
SHEET	1/1	 EATON ELECTRICAL SECTOR		