

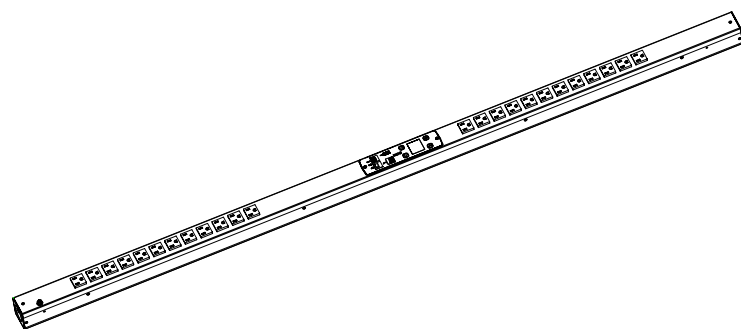
 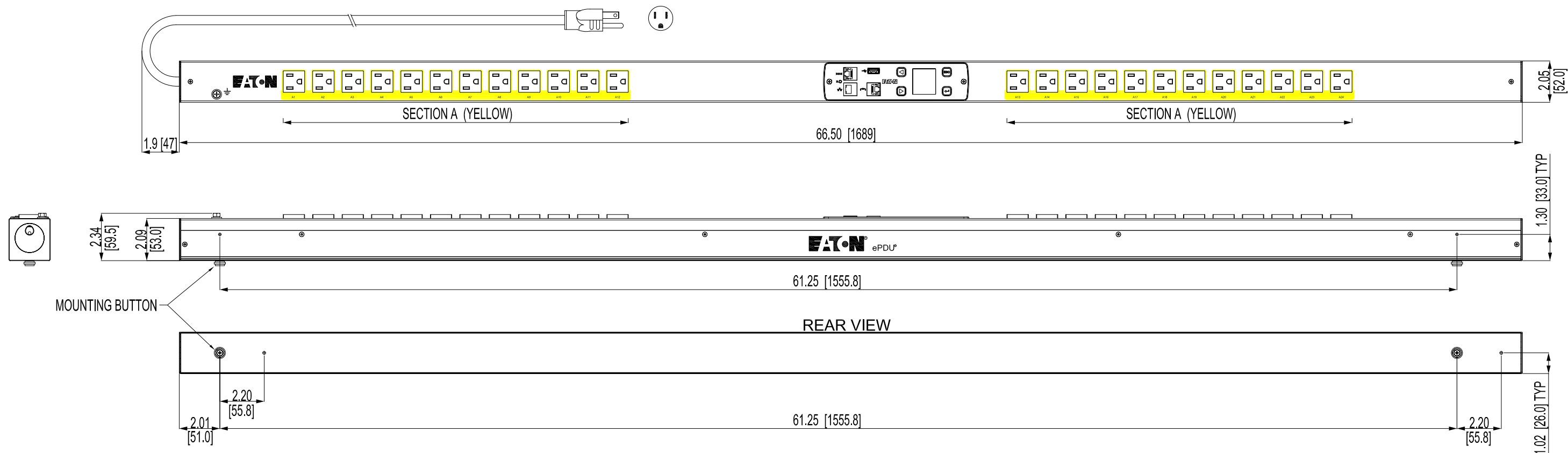


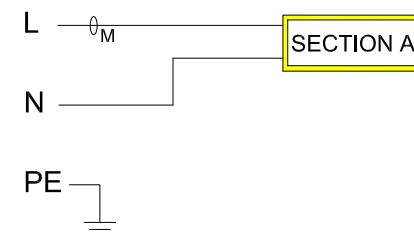

EMI100-10 G3 METERED INPUT			
FUNCTIONALITY	INPUT	OUTPUT	OPERATING TEMPERATURE
CURRENT, POWER, AND ENERGY METERING FOR INPUT	NEMA 5-15P 10FT 14AWG / 3C POWERCORD	(24) NEMA 5-15R	32° TO 140° F 0° TO 60° C
MECHANICAL	INPUT RATING	OUTPUT RATING	CERTIFICATIONS
66.50" (1689mm) LENGTH 2.05" (52mm) WIDTH 2.09" (53mm) DEPTH ALUMINUM CHASSIS, BLACK	100-127V~ W+N+PE 12A 50/60HZ	100-127V~ 12A MAX PER OUTLET 12A MAX TOTAL	
CIRCUIT BREAKERS	FILTER AND SPIKE/SURGE	ACCESSORIES	CONFIGURATION
NONE	NONE	INCLUDED SPK012 - INSTALLATION INCLUDED SPK013 - NETWORK OPTIONAL EMP001 - ENVIRONMENTAL PROBE	EMI3MA15ALJ78AC



TITLE	ePDU G3 SPECIFICATION EMI100-10		DRAW	SPOCK LIU	2013-11-20
			DESIGN		
DWG NO.	B9001-221250-01P		CHECKED	ELON GUO	2013-11-20
MATERIAL			SAFETY		
COATING			APPROVED	VICKY SHEN	2013-11-20
UNITS	in[mm]	A3	SCALE	 ELECTRICAL SECTOR	
SHEET	1/1		1:5		