
 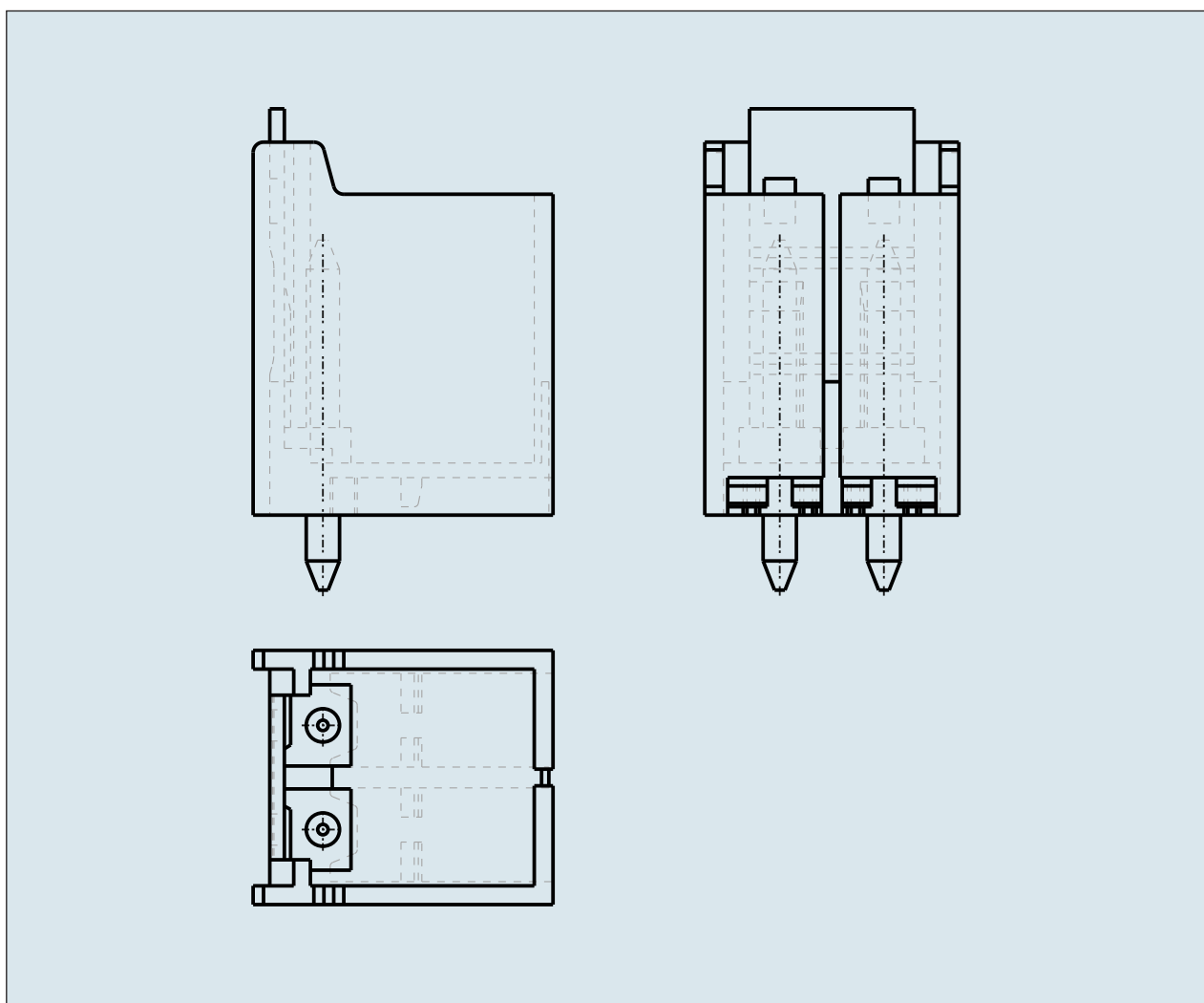



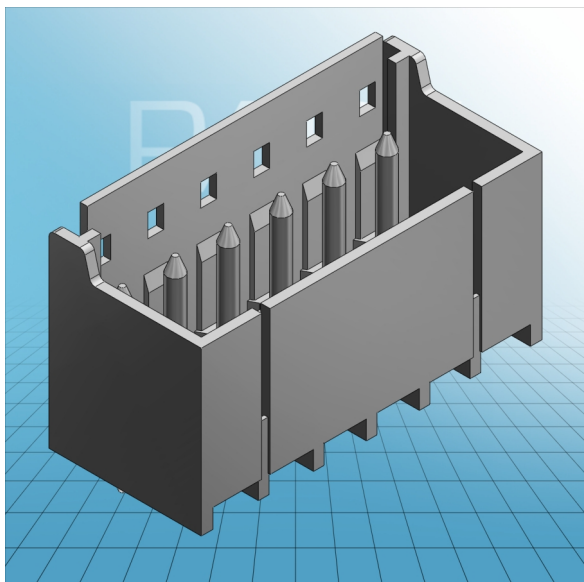

ITEM-NO. (ITEM-NO.)	2092-1406
Measured voltage (Measured voltage / V)	320
Measured shock voltage (Measured shock voltage / kV)	4
Pollution degree (Pollution degree)	2
Current intensity (Current intensity / A)	16
RM (PIN SPACING / mm)	5
P (NO. OF POLES)	6
Height (Height / mm)	19.5
Width (Width / mm)	32.2
Depth (Depth / mm)	14.4
COLOR (COLOR)	lichtgrau
Comment (Comment)	L = (No. of poles - 1) x Pin Spacing + 7.2 mm
Dimensions (Dimensions)	1.6 +0.1 mm