

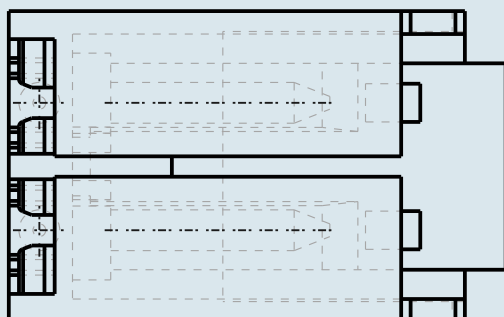
 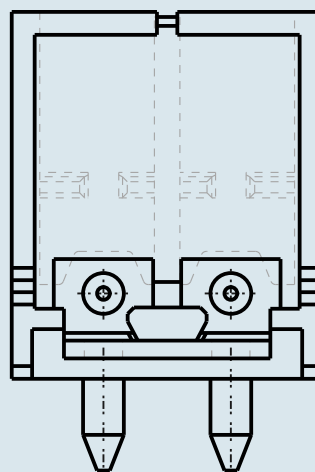
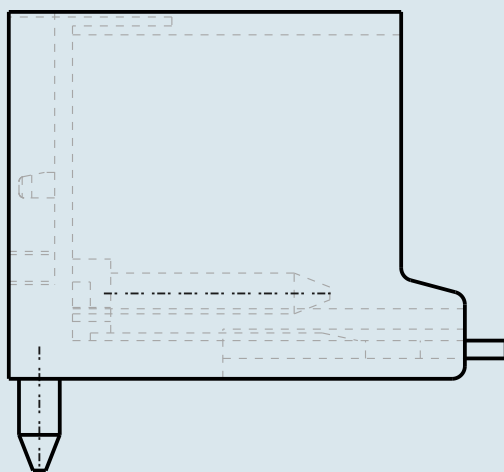




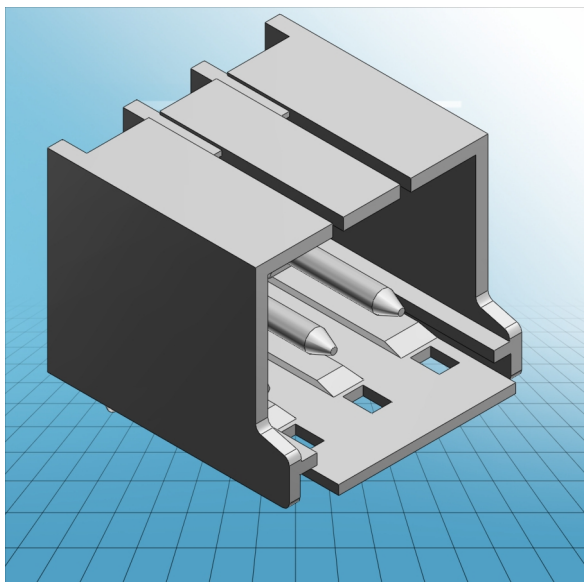

**Plug with right angled solder pin pin
spacing 5 mm / 0.197 in
2092-1422 bis 2092-1432**

PDF DATASHEET

© 1992 - 2011 CADENAS GmbH

ITEM-NO. (ITEM-NO.)	2092-1423
Measured voltage (Measured voltage / V)	320
Measured shock voltage (Measured shock voltage / kV)	4
Pollution degree (Pollution degree)	2
Current intensity (Current intensity / A)	16
RM (PIN SPACING / mm)	5
P (NO. OF POLES)	3
Height (Height / mm)	14.4
Width (Width / mm)	17.2
Depth (Depth / mm)	19.5
COLOR (COLOR)	lichtgrau
Comment (Comment)	$L = (\text{No. of poles} - 1) \times \text{Pin Spacing} + 7.2 \text{ mm}$
Dimensions (Dimensions)	1.6 +0.1 mm