
 
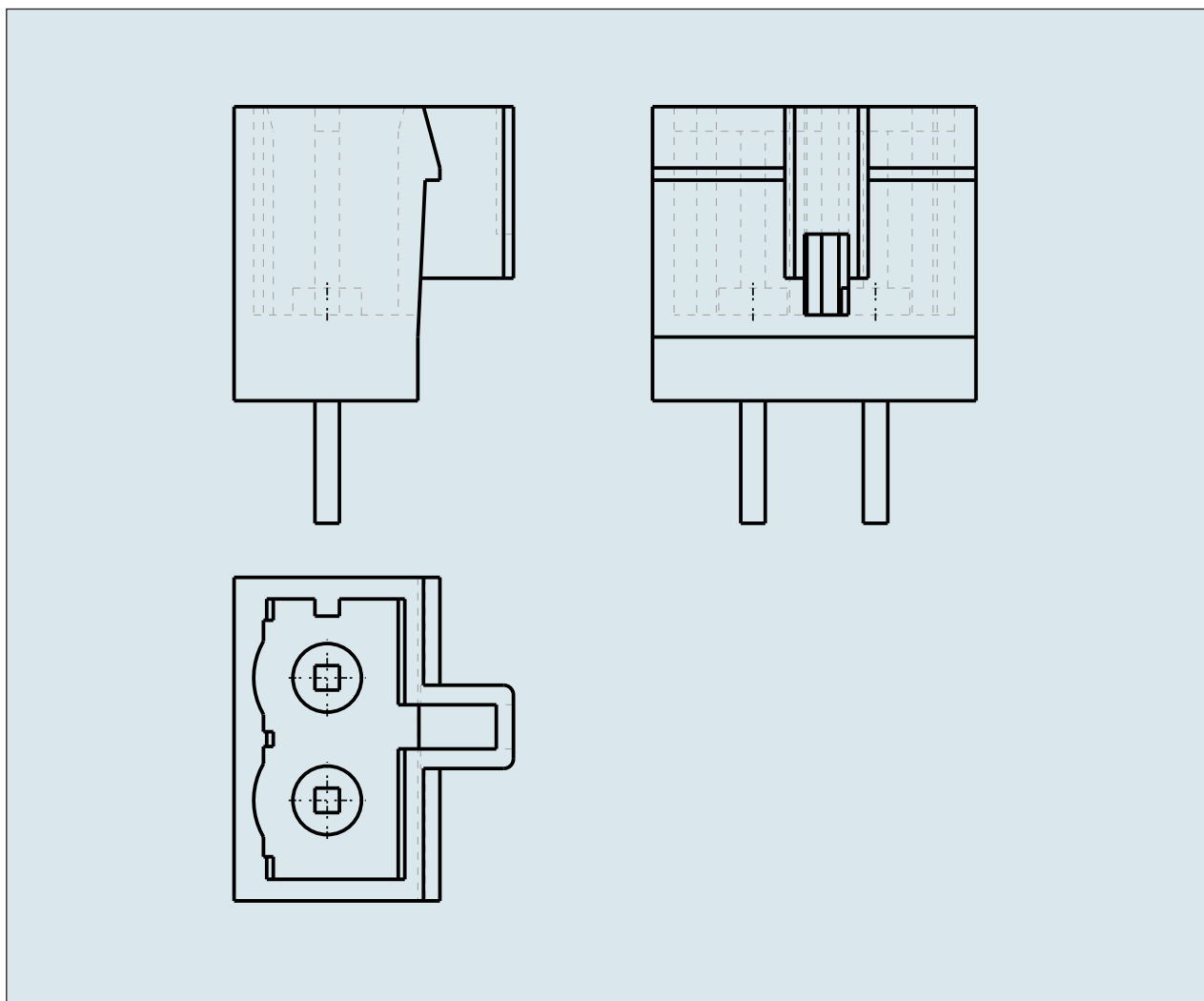




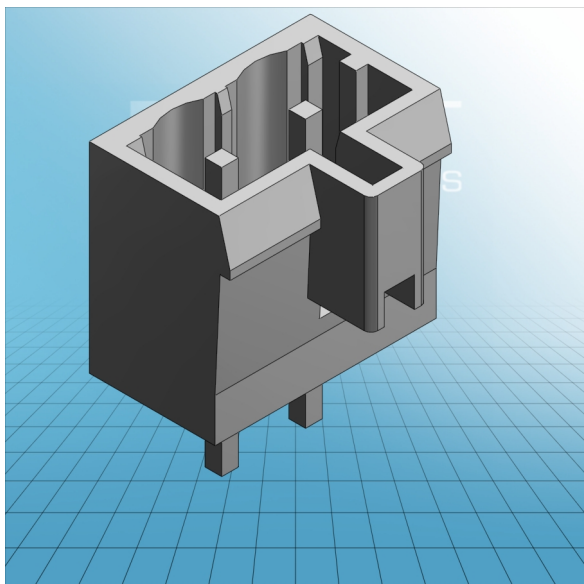

**HEADER STRAIGHT SOLDER PIN, 1X1
MM / 0.039X 0.039 IN PIN SPACING 5
MM / 0.197 IN 100% PROTECTED
AGAINST MISMATING WITH
721-132/001-000 TO 721-150/001-000**

PDF DATASHEET

© 1992 - 2011 CADENAS GmbH

ITEM-NO. (ITEM-NO.)	721-132/001-000
Measured voltage (Measured voltage / V)	320
Measured shock voltage (Measured shock voltage / kV)	4
Pollution degree (Pollution degree)	2
Current intensity (Current intensity / A)	12
RM (PIN SPACING / mm)	5
P (NO. OF POLES)	2
Height (Height / mm)	12
Width (Width / mm)	13.2
Depth (Depth / mm)	11.4
COLOR (COLOR)	lichtgrau
Comment (Comment)	A = (No. of poles x Pin Spacing) + 3,2 mm
Dimensions (Dimensions)	1,4 +0,1 mm