


 
 


1544545-3 Product Details

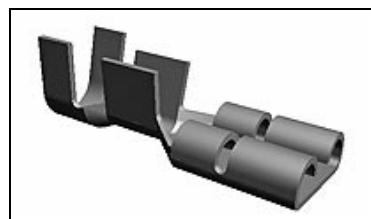

1544545-3

TE Internal Number: 1544545-3



FASTON Uninsulated Receptacles & Housings



Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Terminal
- Terminal Type = Receptacle
- Mating Area Interface Dimensions = 2.79 x 0.50 mm
- Board Mount = No
- Receptacle Style = Straight

[View all Features](#)

Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)



[Add to My Part List](#)



[Request Sample](#)



[Find Similar Products](#)



[Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [2.8 MM FEMALE TERMINAL, STANDARDS CEI AND DIN, WIRE ...](#) (TIF, English)

Catalog Pages/Data Sheets:

- [1654742_HOUSEHOLD_APPLIANCES_RAST5](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: (CAD Format & Compression Information)

- [2D Drawing](#) (DXF, Version C4)
- [3D Model](#) (IGES, Version C4)
- [3D Model](#) (STEP, Version C4)

[List all Documents](#)

Related Products:

- [Tooling](#)

Feedback

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Terminal
- [Receptacle Style](#) = Straight
- [Insulation Support](#) = Insulation Support
- [Wire/Cable Type](#) = Stranded
- [Insertion Force](#) = Low
- [Finish](#) = Pre-Tin

Mechanical Attachment:

- [Board Mount](#) = No

Termination Features:

- [Crimp Type](#) = F-Crimp

Dimensions:

- [Mating Area Interface Dimensions \(mm \[in\]\)](#) = 2.79 x 0.50 [.110 x .019]
- [Insulation Diameter \(mm \[in\]\)](#) = 3.00 [.118]

Body Features:

- [Weld Tab](#) = Without
- [Wire Range \(mm \[AWG\]\)](#) = 0.20-1.00² [24-17]
- [Material](#) = Brass

Contact Features:

- [Terminal Type](#) = Receptacle

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant
- Approved Standards = IEC 760
- UL Rating = Listed
- CSA Certified = Yes

Conditions for Usage:

- [For Hermetic Header Tab](#) = No

Packaging Features:

- [Packaging Method](#) = Strip
- Packaging Quantity = 15,000

Other:

- Line = PRONER
- Brand = TE Connectivity

[About TE](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)
[Terms & Conditions](#)
[Privacy Policy](#)
[AODA Accessibility Policy](#)
[AODA Multi-Year Accessibility Plan](#)

[Distributor Inventory](#)
[Product Cross Reference](#)
[Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Knowledge Base](#)
[Manage Your Account](#)

