

 
Type: 011818100

External dimensions: 180 x 180 x 101 mm


Weight: 2400 g

DIN rail length in mm	max. fitting length in mm	Earthing rail clamp	Mounting plate (thickness in mm)	External mounting brackets	External hinge* set	EMC version	Internal hinge* set	SWB / SBGL / SBGL Corr.protection	Allen lid screws	Silicone lid seal	Sealable lid screws in steel	Turn bolt fastener on request	Quick lock
TS 35													
166	140	8	1.5	•	•	•	•	•	•	•	•	•	•

Maximum number of cable glands to DIN 50262*




Lid

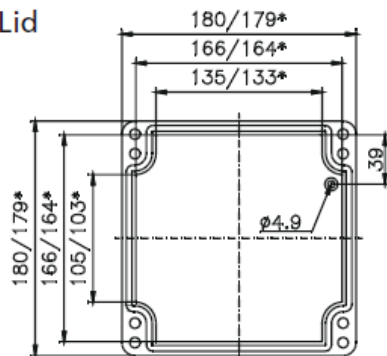


* = Conical form tapering downwards
Free dimensions-tolerance to GTA 13/5 DIN 1688

Cylinder screw
M6x35/10
similar to DIN 84

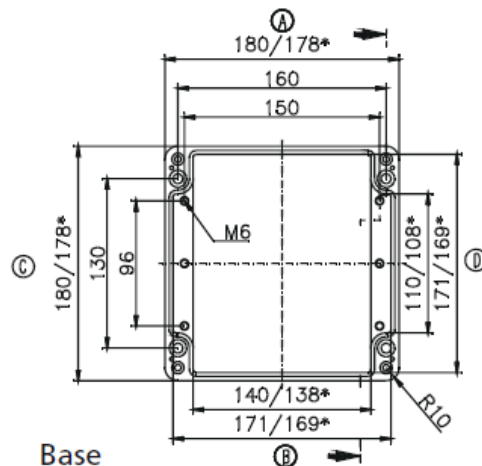

Base

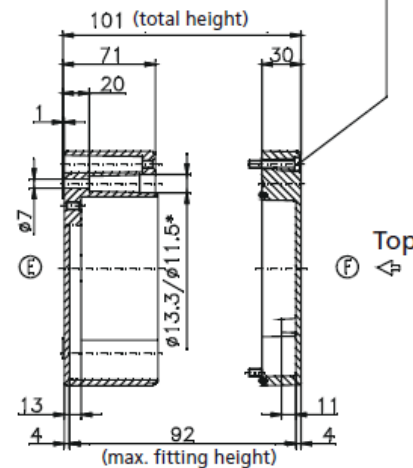

Top
↗

M	Corner dim.	Side		PG	Corner dim.	Side	
		A	C			A	C
		B	D			B	D
12	17.25	30	20	7	17.25	28	20
16	25.30	15	9	9	21.85	18	14
20	27.60	11	8	11	25.30	15	8
25	37.95	6	3	13.5	27.60	11	8
32	48.30	3	2	16	31.05	8	6
40	60.95	2	2	21	37.95	6	3
50	69.00	2		29	48.30	3	2
63	74.75			36	60.95	2	2
				42	69.00	2	
				48	74.75		

DATE		7330 Executive Way Frederick, MD 21704 (301) 696-9411 voice (301) 696-9494 fax	 ROSE
17 MAY 2017			
SHEET		1	
1			
DESCRIPTION			
ENCLOSURE, STANDARD, ALUMINUM 180 X 180 X 101MM, RAL 7001			
SIZE	DRAWING NUMBER		REV
A	011818100		-