

 
Type: 020816080

External dimensions: 75 x 160 x 75 mm


Weight: 540 g

DIN rail length in mm	max. fitting length in mm	Mounting plate (thickness in mm)	External mounting brackets	External hinge* set	EMC version	Allen lid screws	Silicone lid seal	Sealable lid screws
TS 15								
148	129	2	•		•	•	•	•


Maximum number of
cable glands to DIN 50262*




Lid

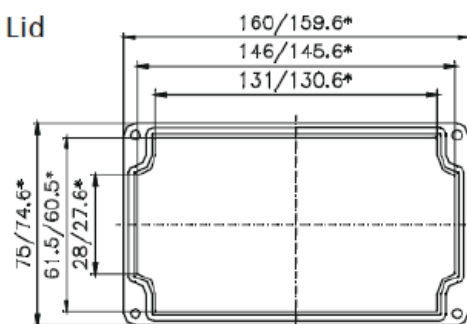

* = Conical form tapering downwards
Free dimensions-tolerance to DIN 16901 - 130

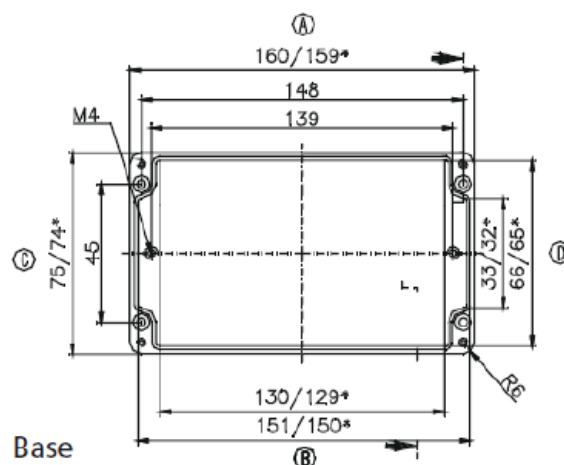

Cylinder screw
M4x24/7
similar to DIN 84

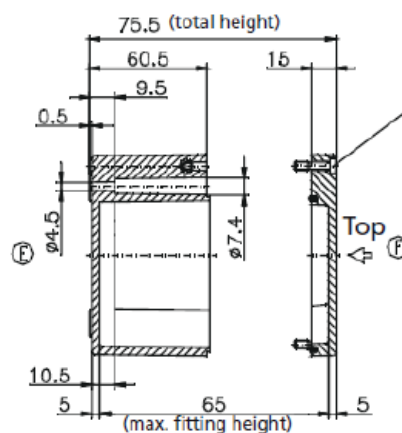

M	Corner dim.	Side		PG	Corner dim.	Side	
		A B	C D			A B	C D
12	17,25	18	5	7	17,25	18	5
16	25,30	8	2	9	21,85	11	3
20	27,60	8	2	11	25,30	8	2
25	37,95	3	1	13,5	27,60	8	2
32	48,30	2	1	16	31,05	5	1
40	60,95			21	37,95	3	1
50	69,00			29	48,30	2	
63	74,75			36	60,95		
				42	69,00		
				48	74,75		

DATE	17 MAY 2017	7330 Executive Way Frederick, MD 21704 (301) 696-9411 voice (301) 696-9494 fax	
SHEET	1		
DESCRIPTION		ENCLOSURE, STANDARD, FIBERGLASS 75 X 160 X 75MM, RAL 7000	
SIZE	DRAWING NUMBER		REV
A	020816080		