 



Type: 010606030

External dimensions: 64 x 58 x 34 mm



Weight: 165 g

	DIN rail length in mm	
	max. fitting length in mm	
	Earthing rail clamp	
	Mounting plate (thickness in mm)	
	External mounting brackets	
	External hinge* set	
•	EMC version	
	Internal hinge* set	
•	SWB / SBG / SBGL Corr. protection	
•	Allen lid screws	
•	Silicone lid seal	
•	Sealable lid screws in steel	
	Turn bolt fastener on request	
	Quick lock	

Maximum number of cable glands to DIN 50262*							
							
M	Corner dim.	Side		PG	Corner dim.	Side	
		A B	C D			A B	C D
12	17.25	2	1	7	17.25	2	1
16	25.30			9	21.85	1	1
20	27.60			11	25.30		
25	37.95			13.5	27.60		
32	48.30			16	31.05		
40	60.95			21	37.95		
50	69.00			29	48.30		
63	74.75			36	60.95		
				42	69.00		
				48	74.75		

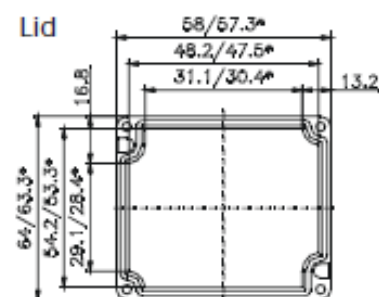

* - Conical form tapering downwards
Free dimensions-tolerance to GTA 13/5 DIN 1688

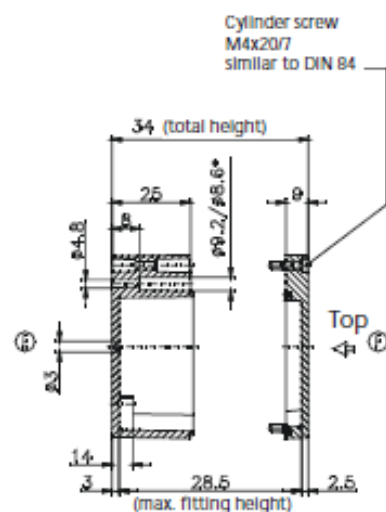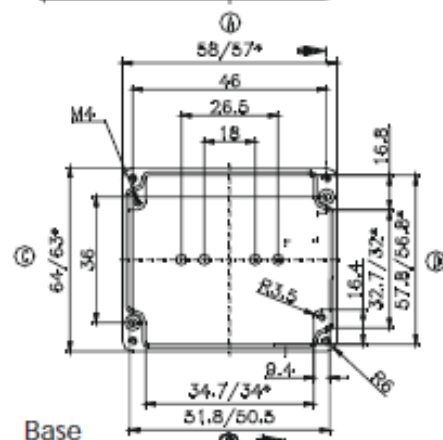

DATE	17 MAY 2017	7330 Executive Way Frederick, MD 21704 (301) 696-9411 voice (301) 696-9494 fax	
SHEET	1		
DESCRIPTION		ENCLOSURE, STANDARD, ALUMINUM 64 X 58 X 34MM, RAL7001	
SIZE	DRAWING NUMBER	010606030	REV
A			