 



Type: **041020060**External dimensions: **100 x 200 x 61 mm**Weight: **840 g**

DIN rail length in mm	max. fitting length in mm	Mounting plate (thickness in mm)	External mounting brackets	External hinge* set	EMC version	SWB / SBGL corrosion protection	Allen lid screws	Silicone lid seal	Sealable lid screws in steel	Lid safety strip
TS 15/TS 35										
188	170	2	•	•	•	•	•	•	•	•

Maximum number of cable glands to DIN 50262*




Lid

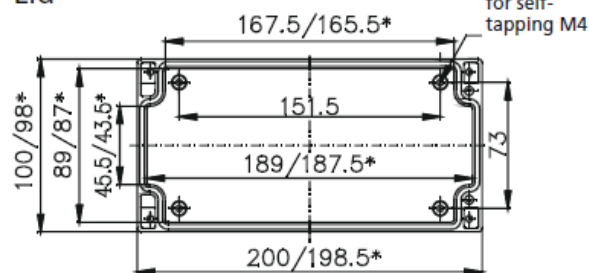


* = Conical form tapering downwards
Free dimensions-tolerance to GTA 13/5 DIN 1688

View F

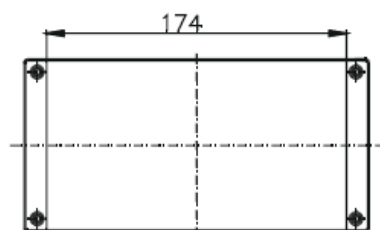

Cylinder screw
M4x20/7
similar to DIN 84

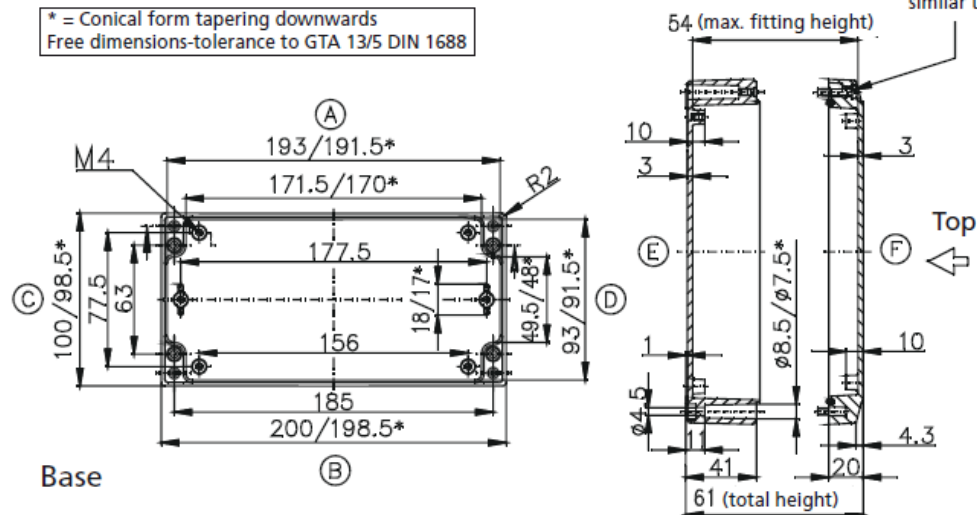

Base

M	Corner dim.	Side		PG	Corner dim.	Side	
		A	C			A	C
12	17.25	15	4	7	17.25	14	4
16	25.30	7	2	9	21.85	8	2
20	27.60	6	2	11	25.30	7	2
25	37.95			13,5	27.60	6	2
32	48.30			16	31.05	5	1
40	60.95			21	37.95		
50	69.00			29	48.30		
63	74.75			36	60.95		
				42	69.00		
				48	74.75		

DATE	17 MAY 2017	7330 Executive Way Frederick, MD 21704 (301) 696-9411 voice (301) 696-9494 fax	 ROSE
SHEET	1		
DESCRIPTION		ENCLOSURE, ALUFORM, ALUMINUM 100 X 200 X 61MM, RL 7038	
SIZE A	DRAWING NUMBER 041020060		REV -