
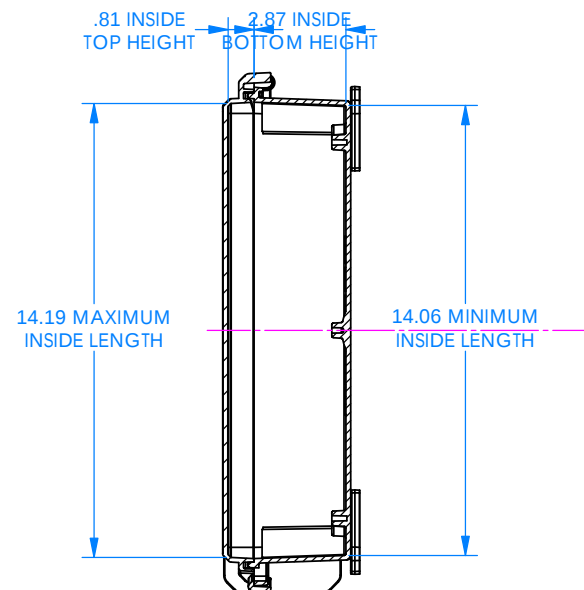



SERPAC I602HL

Electronic Enclosures

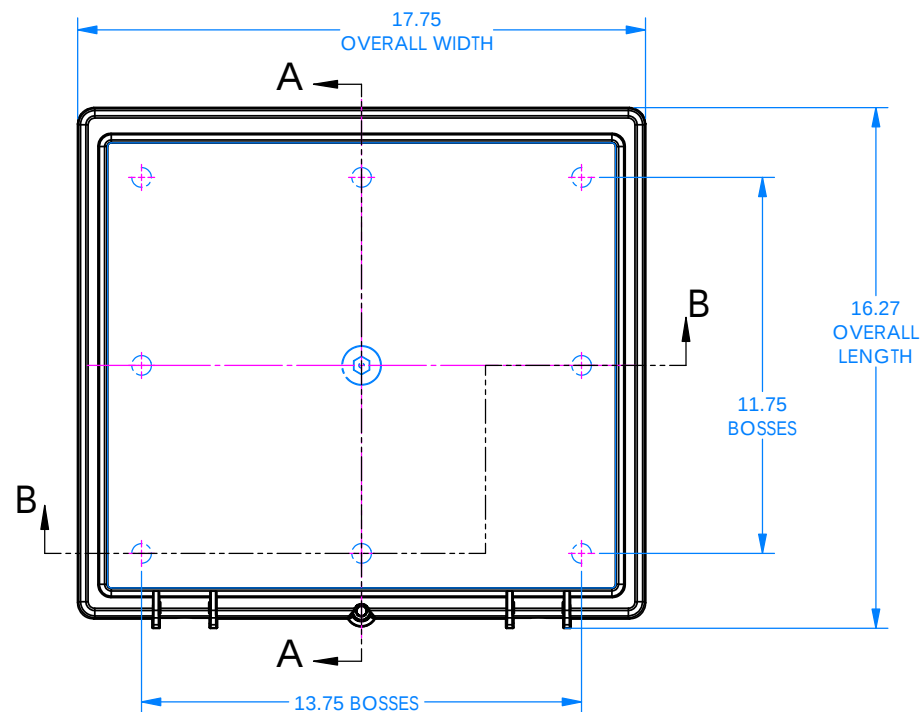


SECTION A-A

4 Mounting Brackets included.
See Sheet 2 for dimensions.

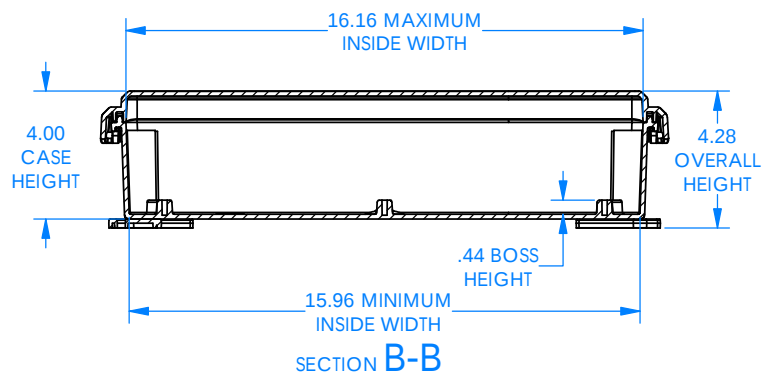

SECTION B-B

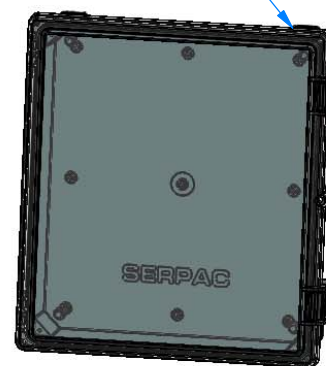


Aluminum Panel Kits are available
as options, see sheets 3-5.
The aluminum panel options are:
Bottom Panel Kit p/n 73000B
Top Panel Kit p/n 73040T
Hinged Panel Kit p/n 73020TH

Material: UV stabilized Polycarbonate
Flammability UL 94 V-2
-Watertight enclosure meets or
exceeds Nema 4 and or IP67.

PARTS INCLUDED		
P/N	Qty.	Description
I650 HLT	1	I650HL Top
I600 HLB	1	I600HL Bottom
8650	1	650 Perimeter O-ring
7011M	2	I-Series Safety Latch
1355	4	Corner Mounting Bracket
6028	9	SS #10 X 5/8" Pan H/L

I602HL Mounting Bracket Dimensions

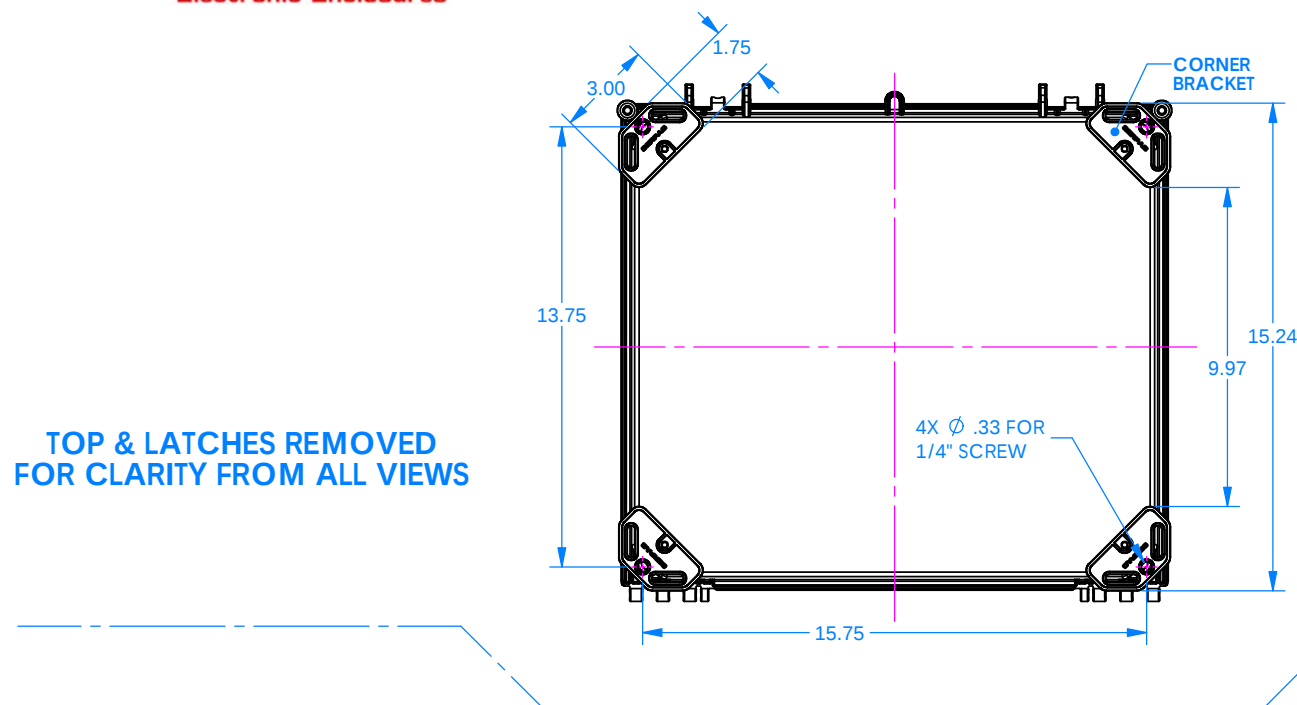


INCLUDED ♂ (4)
CORNER BRACKETS



PARTS INCLUDED		
P/N	Qty.	Description
1355	4	Mounting Corner Bracket
6028	4	SS #10 X 5/8" Pan Combo H/L Screw

OPTIONAL CORNER FEET

PARTS INCLUDED		
P/N	Qty.	Description
1306	4	Mounting Corner Feet
6028	4	SS #10 X 5/8" Pan Combo H/L Screw

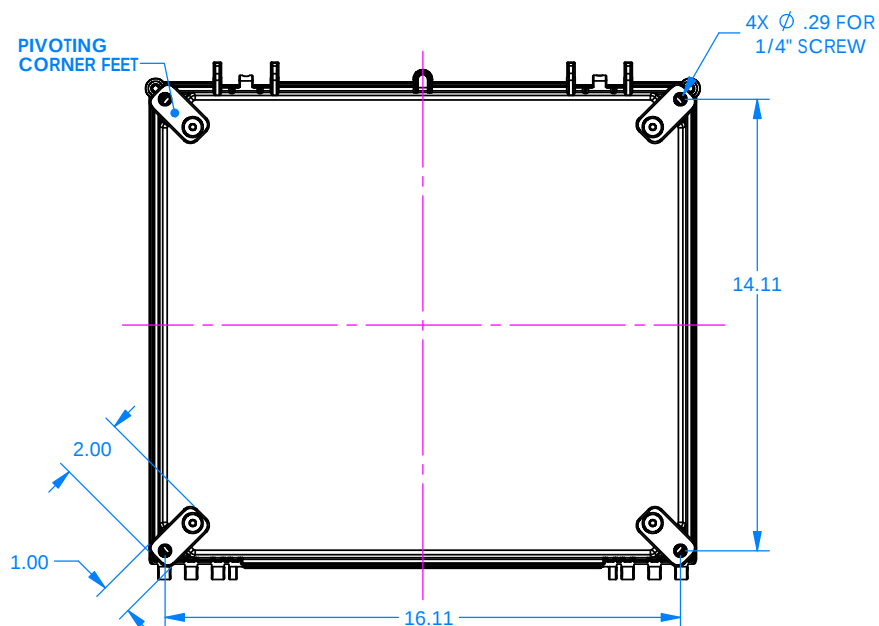



7300T Top Panel Kit for I602HL

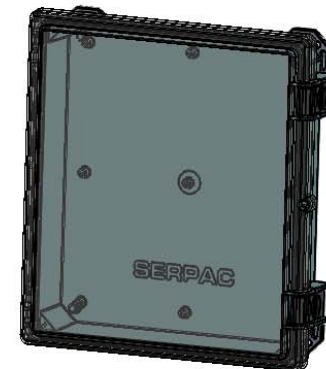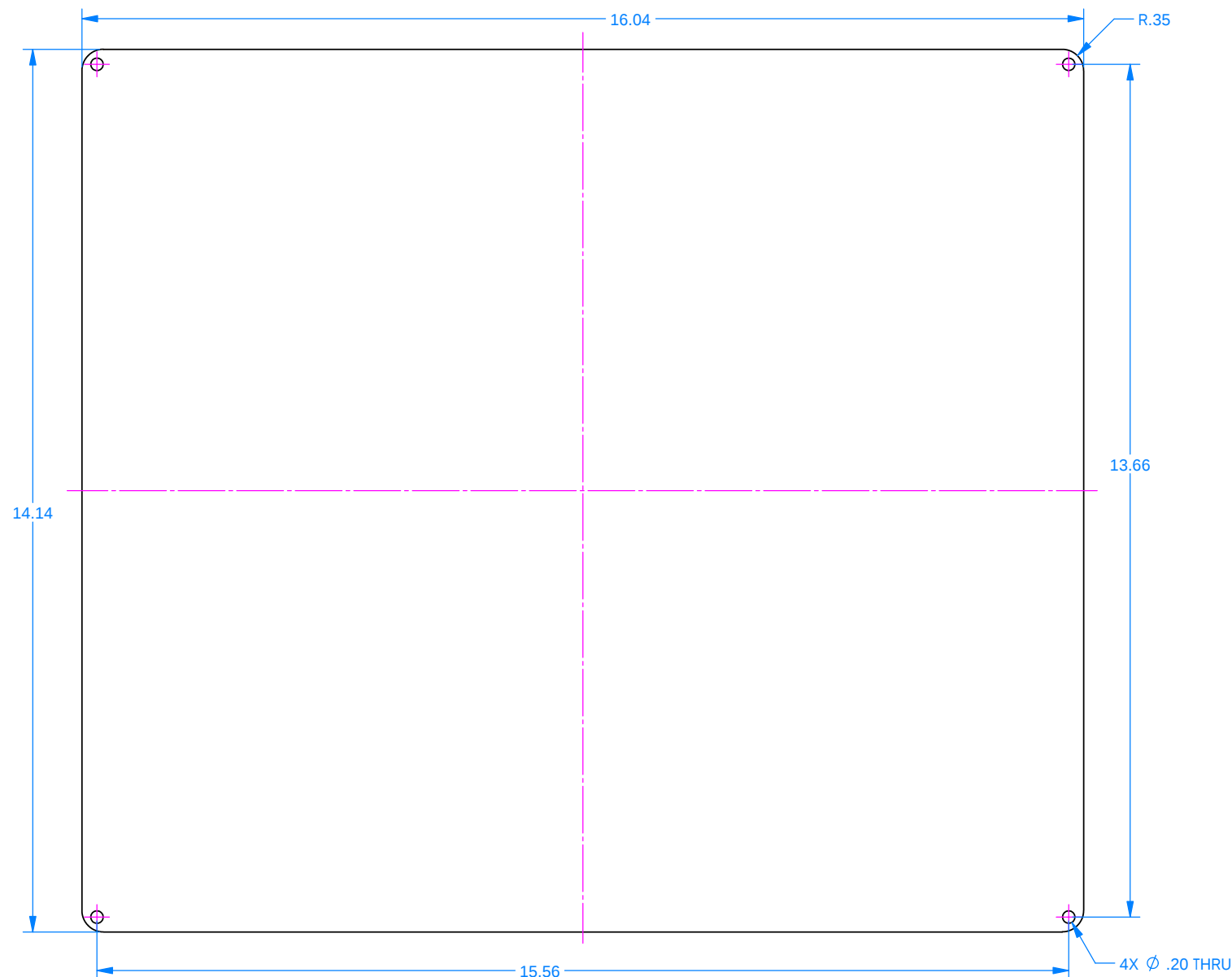

OPTIONAL ACCESSORY

PARTS INCLUDED		
P/N	Qty.	Description
73040	1	Top Aluminum Panel
6029	4	SS #10 X 3/8" Pan HL Screw



7300B Bottom Panel Kit for I602HL

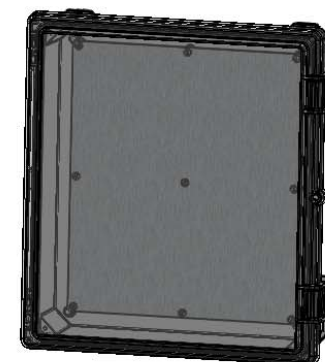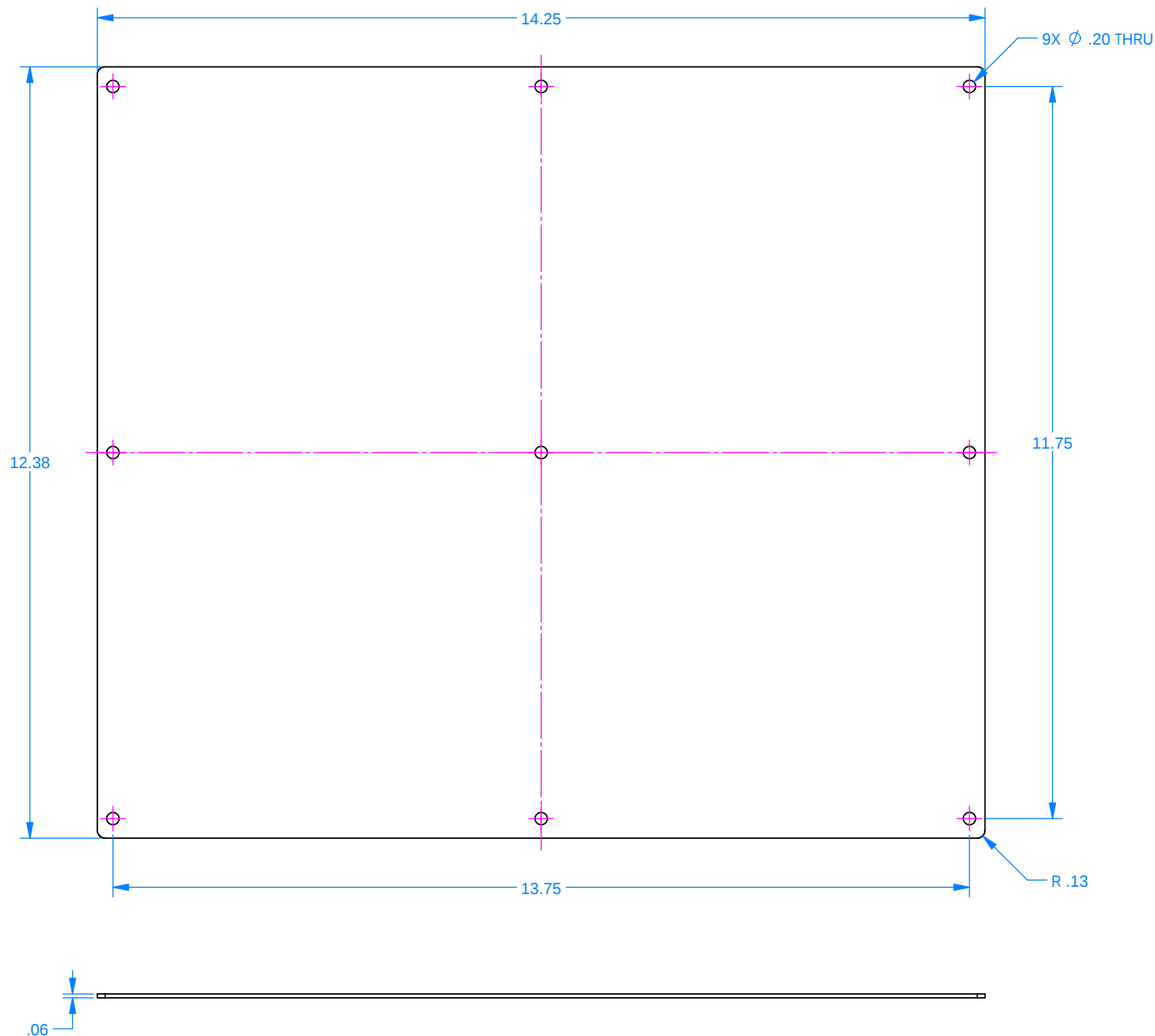

OPTIONAL ACCESSORY

PARTS INCLUDED		
P/N	Qty.	Description
73000	1	Bottom Aluminum Panel
6029	9	SS #10 X 3/8" Pan HL Screw

7300TH Hinged Top Panel Kit for I602HL

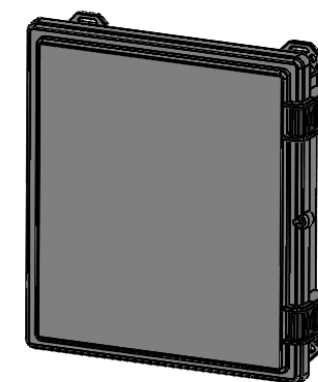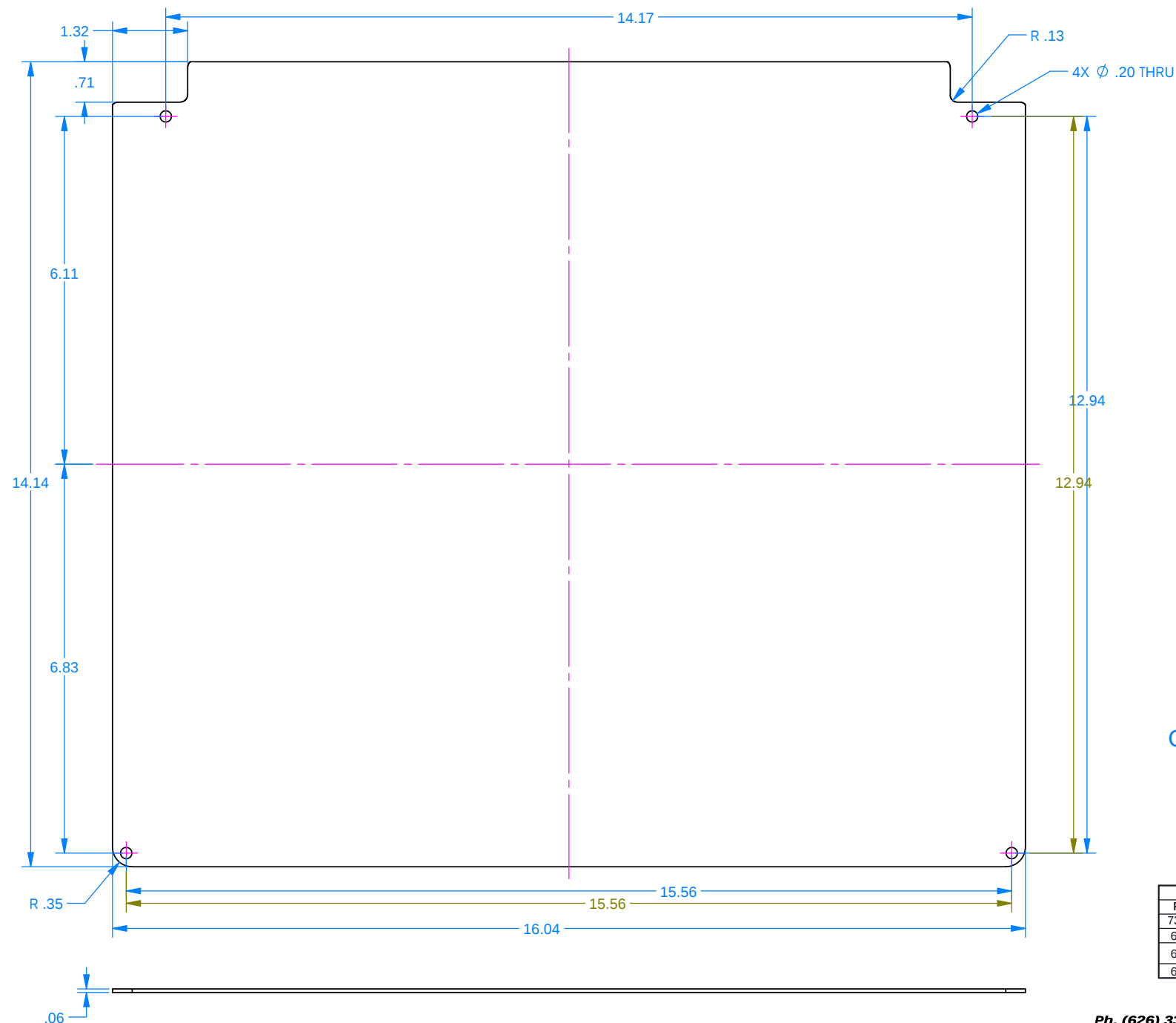

OPTIONAL ACCESSORY

PARTS INCLUDED		
P/N	Qty.	Description
73020	1	Hinged Top Aluminum Panel
6029	2	SS #10 X 3/8" Pan HL Screw
6030	2	SS #10 X 3/8" Pan Combo H/L Screw
6105	2	SS #10-32 X1/8" Nut