

Mercury Free Alkaline manganese batteries

LR44 (A76)



Specifications

Average Service Capacity(to 0.9 volts) 120 mAh
(Rated capacity at 4.7k ohms at 23°C)

Terminals Flat contacts

Average weight 2.0 g


Characteristics

Minimum OCV 1.50 volts

Minimum -10°C CCV (200 ohms / 5 seconds) 1.10 volts

Minimum Capacity (4.7k ohms to 0.9 volts) 108 mAh

Dimension

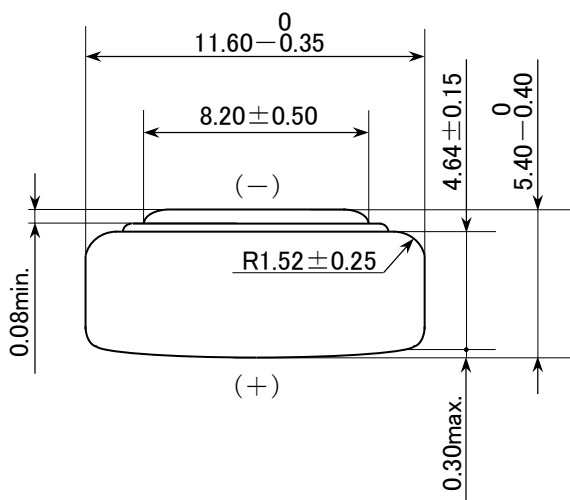

Discharge curve

