

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2177971042

Status:


Active

Overview:

Off-the-Shelf Cable Assemblies

Description:

KK 254-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, 2.54mm Pitch, Single Row, 300.00mm Length, 4 Circuits, Natural

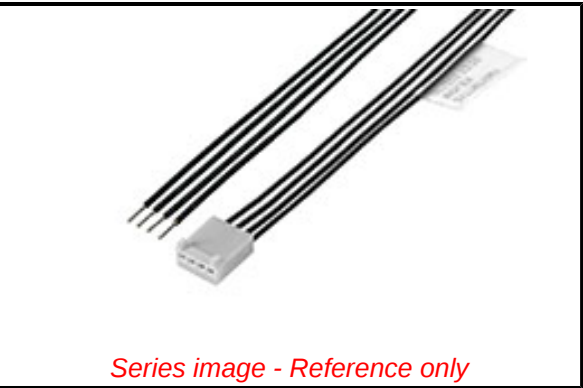

Series image - Reference only

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Datasheet \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	217797
Assembly Configuration	Dual Ended Connectors
Connector to Connector	KK 254-to-Pigtail
Overview	Off-the-Shelf Cable Assemblies
Product Name	KK 254
Type	Discrete Wire Assembly
UPC	195842123052
Physical	
Cable Length	300.00mm
Circuits (Loaded)	4
Color - Resin	Natural (White)
Gender	Female-Pigtail
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	5.848/g
Number of Rows	1
Pitch - Mating Interface	2.54mm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.57mm max.
Wire Size AWG	22
Wire/Cable Type	UL 11028

Material Info

Reference - Drawing Numbers

Sales Drawing

2177971041-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

217797 Series

Mates With

KK254 PCB Headers
 42375 , 42377 , 42376 , 4030 , 6373 , 6410 , 1718 56, 171857

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION