

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2181110900

Status:


Active

Overview:

PicoBlade Connector System

Description:

PicoBlade Male-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, Single Row, 75.00mm Length, 9 Circuits, Natural

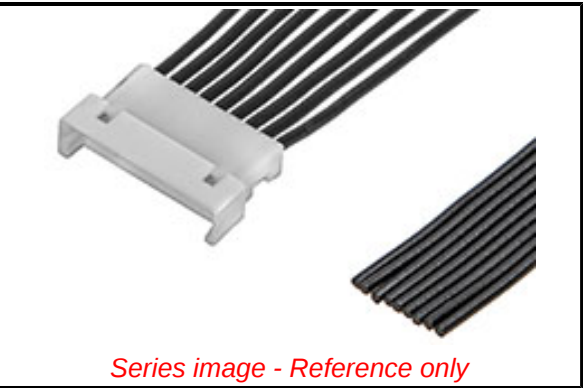

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable Assemblies
Series	218111
Application	Signal, Wire-to-Wire
Assembly Configuration	Single Ended Connector
Connector to Connector	PicoBlade-to-Pigtail
Overmolded	No
Overview	PicoBlade Connector System
Product Name	PicoBlade
Type	Discrete Wire Assembly
UPC	195842250383
Physical	
Cable Length	75.00mm
Circuits (Loaded)	9
Color - Resin	Natural
Gender	Male-Pigtail
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	1.400/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	1.25mm
Plating min - Mating	0.889µm
Plating min - Termination	0.914µm
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.50-1.00mm
Wire Size AWG	28
Wire/Cable Type	UL 1061

Material Info

Reference - Drawing Numbers

Sales Drawing

2181110900-000

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2020)9139-DC (19 Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

218111 Series

Mates With

PicoBlade Receptacle Housing 51021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION