

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2181100602

Status:


Active

Overview:

PicoBlade Connector System

Description:

PicoBlade Male-to-PicoBlade Male Off-the-Shelf (OTS) Cable Assembly, Single Row, 225.00mm Length, 6 Circuits, Natural

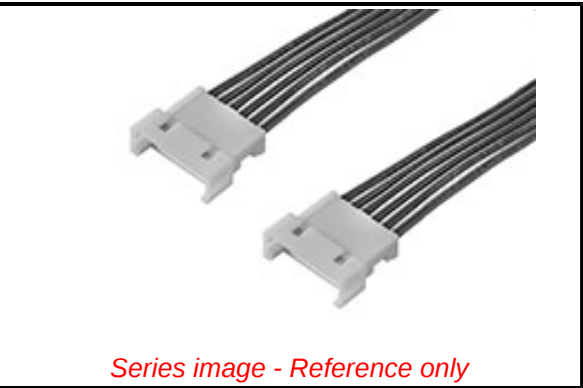

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable Assemblies
Series	218110
Application	Signal, Wire-to-Wire
Assembly Configuration	Dual Ended Connectors
Connector to Connector	PicoBlade-to-PicoBlade
Overmolded	No
Overview	PicoBlade Connector System
Product Name	PicoBlade
Type	Discrete Wire Assembly
UPC	195842249806
Physical	
Cable Length	225.00mm
Circuits (Loaded)	6
Color - Resin	Natural
Gender	Male-Male
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	2.463/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	1.25mm
Plating min - Mating	0.889µm
Plating min - Termination	0.914µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.50-1.00mm
Wire Size AWG	28
Wire/Cable Type	UL 1061

Material Info

Reference - Drawing Numbers

Sales Drawing

2181100600-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

218110 Series

Mates With

PicoBlade Receptacle Housing [51021](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION