

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0152660099

Status:


Active

Overview:

FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description:

0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 76.00mm Cable Length, Tin (Sn) Plating, 10 Circuits

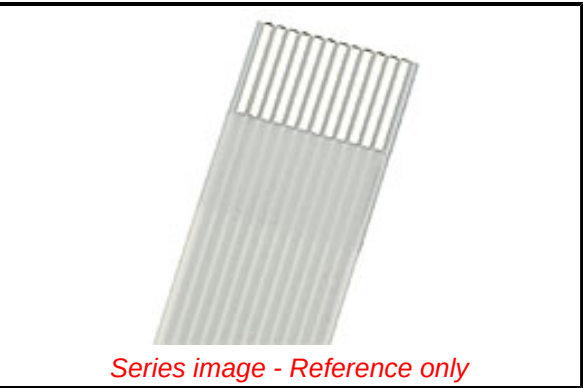

Series image - Reference only

Documents:

- [Drawing \(PDF\)](#)
- [Product Specification PS-15266-001-001 \(PDF\)](#)
- [Datasheet \(PDF\)](#)
- [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable
Series	15266
Comments	Contacts on the same side, Type A
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
UPC	884982429123

Physical

Cable Length	76.00mm
Circuits (Loaded)	10
Contact Layout Type	A (same side)
Material - Plating Mating	Tin
Net Weight	0.258/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

Solder Process Data

Lead-freeProcess Capability	N/A
Max. Cycles at Max. Process Temperature	001
Process Temperature max. C	250

Material Info

Reference - Drawing Numbers

Product Specification	PS-15266-001-001
Sales Drawing	SD-15266-001-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

15266 Series

Mates With

Easy-On FFC/FPC Connector:

[527451033](#) , [527461033](#) , [525591033](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION