


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0731160076
Status: Active
Overview: RF Connectors and Microwave Products
Description: MCRF-to-Pigtail, 0.81mm Cable Diameter, Length 230.13mm, H18, 50 Ohms, One Piece Per Bag

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	73116
Assembly Configuration	Single Ended Connector
Connector to Connector	MCRF-to-Pigtail
Overview	RF Connectors and Microwave Products
Product Name	MCRF, RF
Type	RF Cable Assembly
UPC	884982813632
Physical	
Cable Length	230.13mm (9.060")
Circuits (Loaded)	0
Gender	Plug-Pigtail
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Resin	Polyester
Net Weight	0.800/g
Number of Rows	1
Packaging Type	Bag
Single Ended	Yes
Wire/Cable Type	Coaxial
Electrical	
Impedance	50Ω
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-73116-007

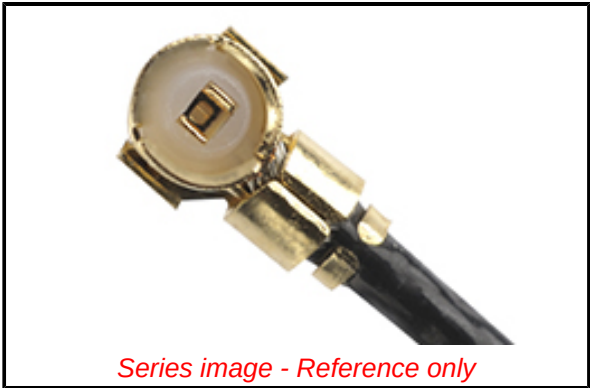

EU ELV Not Relevant	
EU RoHS Not Reviewed REACH SVHC Not Contained Per - ED/61/2018 (27 June 2018) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
Green Image Not Relevant Not Contained	

Search Parts in this Series
73116 Series

Mates With
734120110 MCRF, 50 Ohm, Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION