

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5035661102

Status:


Active

Overview:

Easy-On FFC FPC Connectors

Description:

Easy-On FPC Connector, 0.30mm Pitch, Right-Angle, Bottom Contact, 0.95mmHeight, 11 Circuits, Gold over Nickel Plating

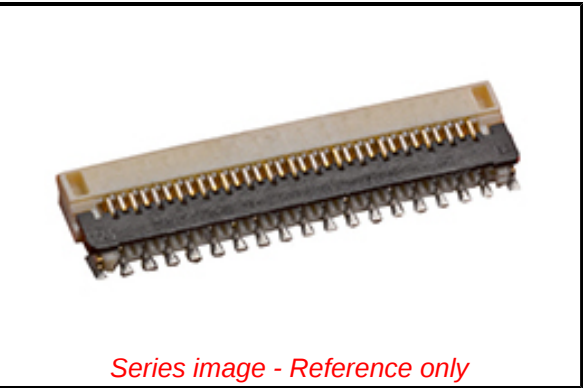

Series image - Reference only

Documents:

- [3D Model](#)
- [Drawing \(PDF\)](#)
- [3D Model \(PDF\)](#)
- [Product Specification 5035660000-000 \(PDF\)](#)
- [Application Specification 5035660000-A00 \(PDF\)](#)
- [Packaging Specification 5035669200-200 \(PDF\)](#)
- [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family

Series

Overview

Product Name

UPC

FFC/FPC Connectors

503566

Easy-On FFC FPC Connectors

Easy-On

191128129749

Physical

Actuator Type

Circuits (Loaded)

Circuits (maximum)

Color - Resin

Contact Position

Durability (mating cycles max)

Mated Height

Material - Metal

Material - Plating Mating

Material - Plating Termination

Material - Resin

Net Weight

Number of Rows

Orientation

PCB Locator

PCB Mounting

PCB Retention

Packaging Type

Pitch - Mating Interface

Polarized to PCB

Stackable

Surface Mount Compatible (SMC)

Temperature Range - Operating

Wire/Cable Type

Front Flip

11

11

Natural

Bottom

10

0.95mm

Phosphor Bronze

Gold

Gold

Liquid Crystal Polymer

20.154/mg

1

Right Angle

No

Surface Mount

None

Embossed Tape on Reel

0.30mm

Yes

No

Yes

-40° to +105°C

FPC only

Electrical

Current - Maximum per Contact

Voltage - Maximum

0.3A

50V

Solder Process Data

Lead-freeProcess Capability

Max. Cycles at Max. Process Temperature

Process Temperature max. C

REFLOW

002

250

Material Info

Reference - Drawing Numbers

Application Specification

5035660000-A00

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series
503566 Series

Packaging Specification
Product Specification
Sales Drawing

5035669200-200
5035660000-000
5035660001-000, 5035661001-000

This document was generated on 10/21/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION