

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5046184012](#)
Status: **Active**
Overview: [SlimStack Board-to-Board/Board-to-FPC Connectors](#)
Description: SlimStack Board-to-Board Receptacle, 0.35mm Pitch, SSB6 Standard Series, 0.60mm Mated Height, 2.00mm Mated Width, 40 Circuits

Documents:

- [3D Model](#)
[Drawing \(PDF\)](#)
[3D Model \(PDF\)](#)
[Product Specification 5046180000-000 \(PDF\)](#)
[Product Specification PS-504622-001-001 \(PDF\)](#)
[Application Specification 5046180000-A00 \(PDF\)](#)
- [Packaging Specification 5046189200-202 \(PDF\)](#)
[Datasheet \(PDF\)](#)
[Product Guide \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)
[Reference Guide \(PDF\)](#)

General

Product Family	PCB Receptacles
Series	504618
Application	Board-to-Board
Overview	SlimStack Board-to-Board/Board-to-FPC Connectors
Product Name	SlimStack
Series Name	0.35, SSB6
UPC	191128130363

Physical

Circuits (Loaded)	40
Circuits (maximum)	40
Color - Resin	Black
Durability (mating cycles max)	30
Glow-Wire Capable	No
Mated Height	0.60mm
Mated Width	2.00mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	30.454/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.35mm
Pitch - Termination Interface	0.35mm
Plating min - Mating	0.100µm
Plating min - Termination	0.050µm
Polarized to Mating Part	No
Polarized to PCB	No
Temperature Range - Operating	-40° to +85°C
Termination Interface: Style	Surface Mount


Electrical

Current - Maximum per Contact	0.3A
Voltage - Maximum	50V

Material Info

Reference - Drawing Numbers

Application Specification	5046180000-A00
---------------------------	----------------

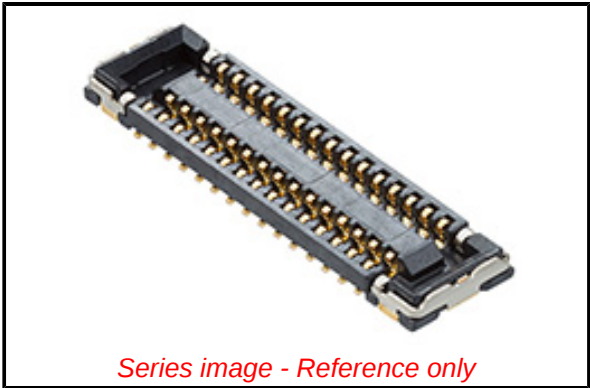

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[504618](#) Series

Mates With

SlimStack SSB6 Plug [504622](#)

Packaging Specification
Product Specification
Sales Drawing

5046189200-202
5046180000-000, PS-504622-001-001
5046180000-004, 5046181000-003

This document was generated on 05/24/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION