


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1731110076](#)
Status: **Active**
Overview: [FCT D-Sub Connectors](#)
Description: FCT Metal Backshell for D-Sub Connector, Shell Size 1, 45° Angle Cable Outlet, Large Inner Chamber, with Rubber Bushing and Knurled Thumb Screw Lock

Documents:
[Datasheet \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

General	
Product Family	D-Sub Products
Series	173111
Overview	FCT D-Sub Connectors
Product Category	Backshell
Product Name	FCT Products
Type	Rugged Metal
UPC	889056487764
Physical	
Cable Diameter	3.00-9.50mm
Material - Backshell	Zinc Die-cast
Material - Bushing	TPE
Material - Screw	Brass
Mounting Style	Knurled Thumb Screw Lock
Net Weight	40.000/g
Orientation	45° Angle
Packaging Type	Carton
Plating - Backshell	Nickel
Shield Type	Solid Metal
Shielded	Yes
Temperature Range - Operating	-35° to +100°C
Thread Size	4-40 UNC
Thread Type	Standard
Tightening Test Torque	40 Ncm
Waterproof / Dustproof	No
Material Info	
Engineering Number	FMK1-K282

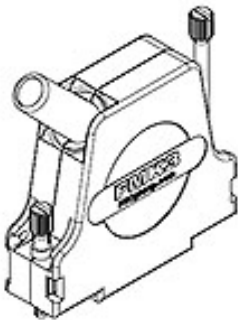

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant with Exemption 6(a)-I,6(c) REACH SVHC Contained Per - ED/71/2019 (16 July 2019) Lead Halogen-Free Status Not Reviewed For more information, please visit Contact US	China RoHS
China ROHS ELV RoHS Phthalates	50 Image Not Relevant Not Contained

Search Parts in this Series
[173111 Series](#)

Use With
FCT D-Sub, Size 1

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION