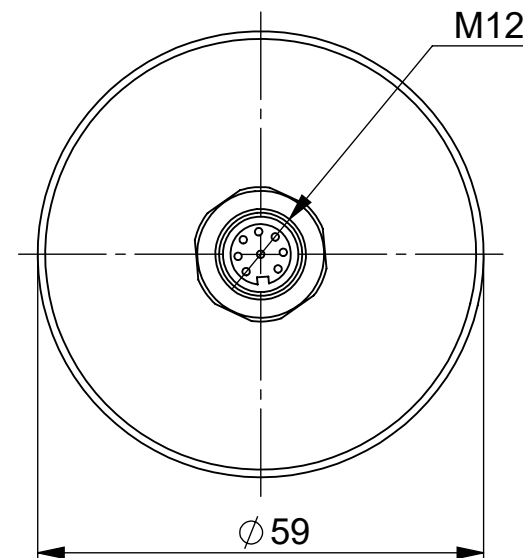
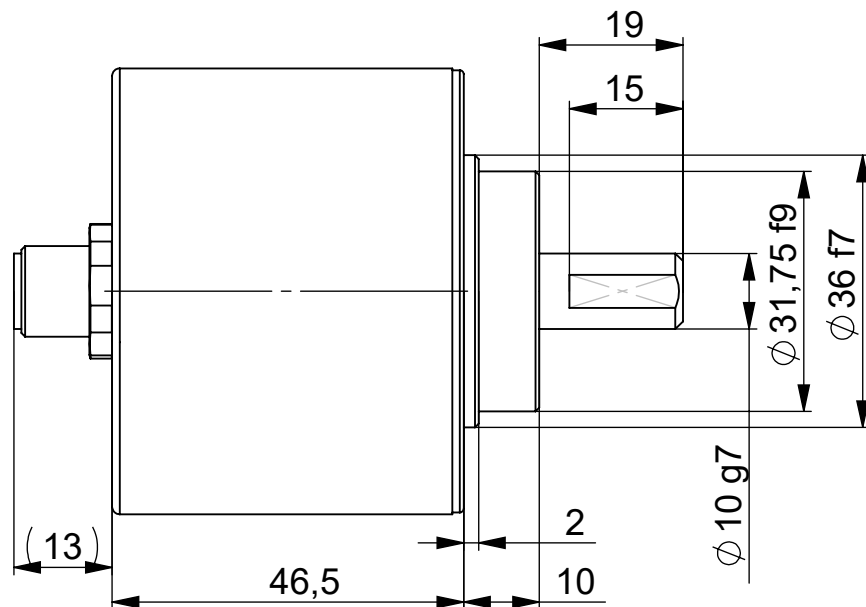
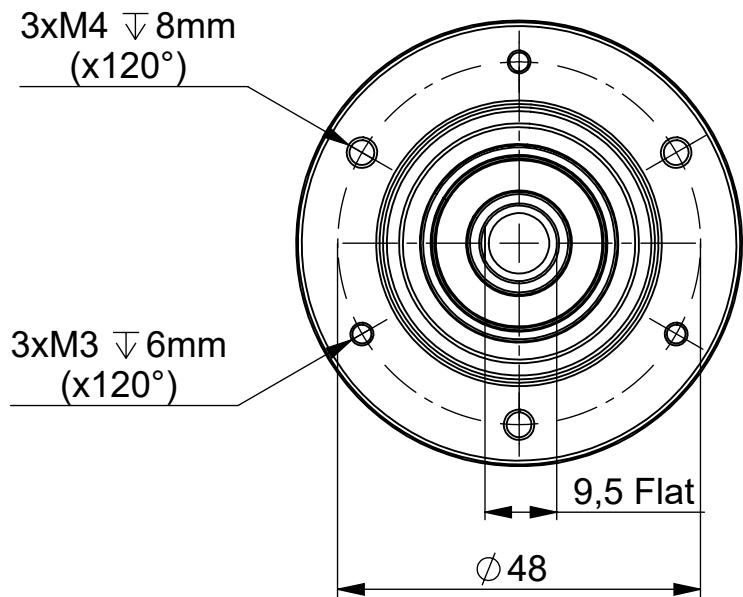


UNCONTROLLED COPY			
FIRST ISSUE DATE : 21/10/2021 DRAWN : RHM APPROVED : JHH DATE : 21/10/2021	SENSATA TECHNOLOGIES PROPRIETARY AND CONFIDENTIAL. NEITHER THIS PRINT NOR THE INFORMATION CONTAINED HEREON IS TO BE USED AGAINST THE INTERESTS OF SENSATA TECHNOLOGIES OR AGAINST THE INTERESTS OF ANY OF ITS AFFILIATED COMPANIES OR WHOLLY OWNED SUBSIDIARIES.		Sensata Technologies BEI Sensors BEI SENSORS SAS Espace Européen de l'Entreprise 9, rue de Copenhague BP 70044 - F 67013 STRASBOURG Cedex Tel : +33 (0)3 88 20 81 40
ECN :	UNLESS OTHERWISE SPECIFIED DIMENSIONS ARE IN MILLIMETERS [INCHES] AND ARE INTENDED AS NOMINAL. SEE PRODUCT SPECIFICATION FOR MORE DETAILS.		TITLE
DATE : 21/10/2021			THM510_ M12 connector Output_Axial
Housing material : Steel	DO NOT SCALE DRAWING	EUROPEAN SYSTEM	SIZE A3
Flange material : Aluminum			DWG NO.
Shaft material : Stainless Steel			REV.
		SCALE	1/1
		SOLIDWORKS	SHEET 1 OF 1

DEVICE:

PROJECT: