

Check Stock/Pricing by Product No.

Search By Size and Type

Find a Distributor / Rep

[Home](#) / [Products](#) / [General Use Boxes](#) / [Showcase Metal Electronics Box](#) / Showcase Metal Electronics Box Blue BB-1802-RB

Showcase Metal Electronics Box Blue BB-1802-RB



Series Photo

Model # BB-1802-RB

[Showcase Metal Electronics Box](#)

- Top, sides, and bottom, 0.05-inch aluminum
- Front panel 0.09-inch aluminum
- Rear panel, 0.05-inch aluminum
- Extruded aluminum frame
- Side gussets provide added strength
- Strong, flexible handle is recessed and secured firmly into top for safe handling
- Carrying handle limited to 25# load capacity
- Ventilation slots under handle
- Use with chassis or PC boards
- Front panel and chassis may be loaded from front or rear
- Comes with front and rear panels and bail

Compare Sizes and Models

[Request Modifications](#)

Check Stock / Pricing

External Size H x W x D: 8.18" x 5.50" x 11.00"

Internal Size H x W x D: 7.69" x 5.00" x 10.00"




Weight: 3.75 lbs

Color: Royal Blue Textured Body / White Frame

Ventilated: Ventilated

Handles: Handles

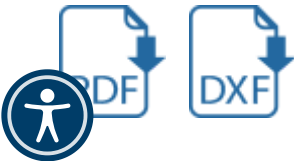

Help



PART NAME	SHOWCASE	PART No.	BB-1800 thru BB-1809	REV. DATE	7-17-12
-----------	----------	----------	----------------------	-----------	---------

MATERIAL:



CORNER GUSSETS _____ 16 GA. STEEL
 FRONT PANEL _____ 0.090 ALUMINUM
 SHELF, COVER, REAR PANEL
 AND SHELF GUSSETS _____ 0.050 ALUMINUM
 FRAME _____ 6063-T42 ALUMINUM EXTRUSION
 BAIL _____ 0.125 DIAMETER SPRING WIRE
 FEET _____ NYLON
 HANDLE _____ VINYL WRAPPED STEEL

FINISH:

COVER AND PANELS _____ ROYAL BLUE TEXTURE
 _____ BLACK TEXTURE
 SHELF ASSEMBLY _____ WHITE TEXTURE
 HANDLE AND FEET _____ WHITE
 HANDLE CAPS _____ NICKEL PLATED
 BAIL _____ CHROME PLATED

NOTE:

MAXIMUM WEIGHT FOR HANDLE IS 25 LBS.

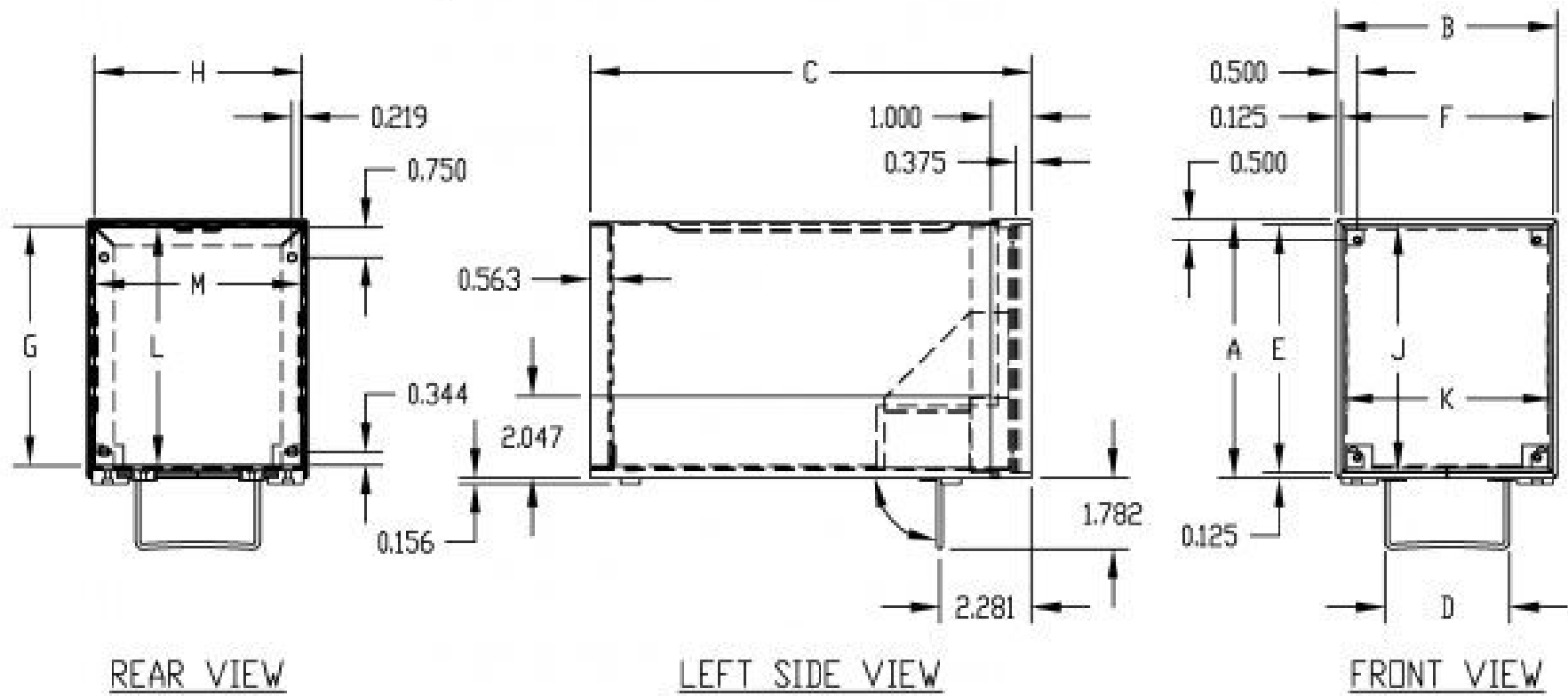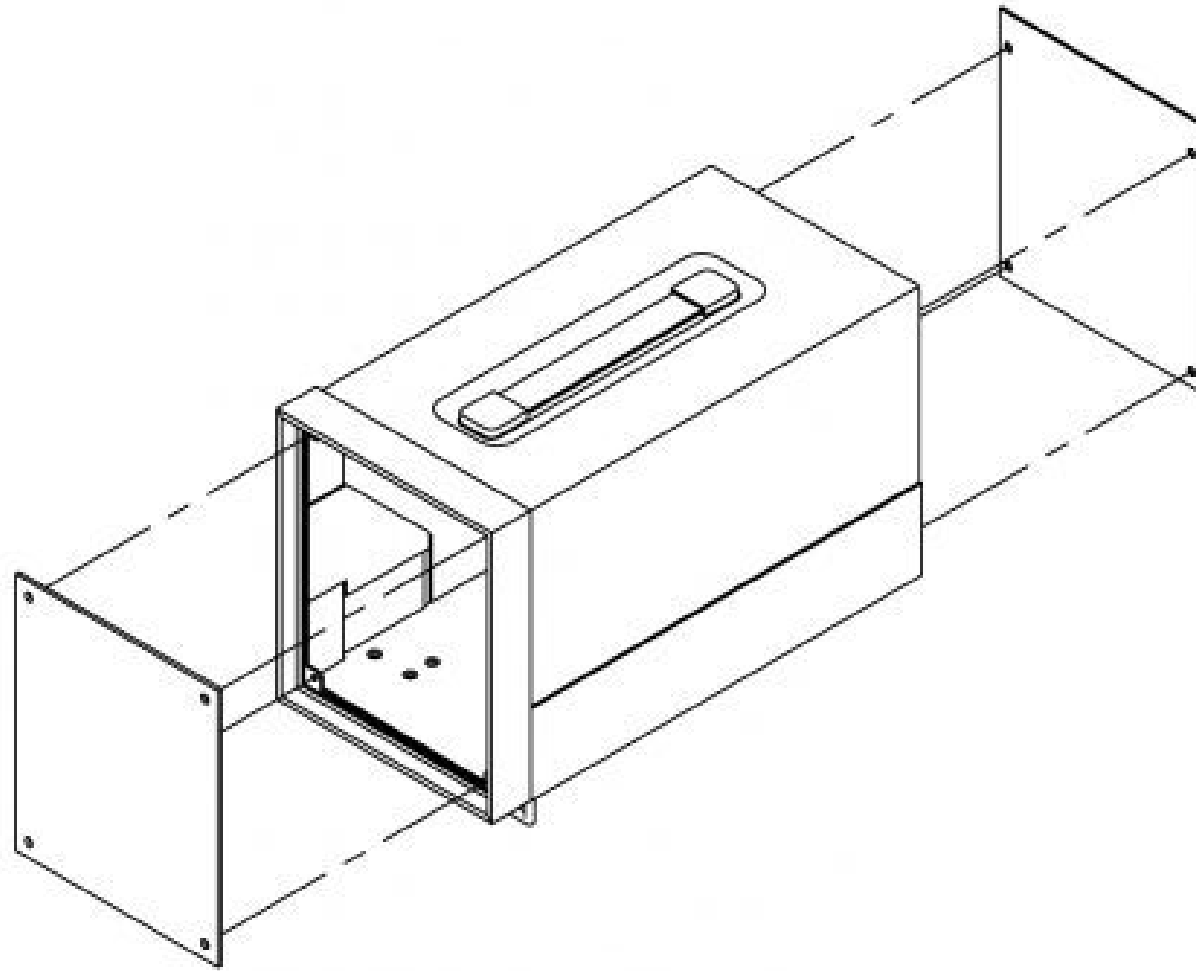

PART NUMBER	OVERALL				PANEL SPACE				PANELS				INSIDE		
	A	B	C	D	FRONT		REAR		FRONT		REAR		HEIGHT	WIDTH	DEPTH
					E	F	G	H	J	K	L	M			
BB-1800	6.438	5.500	11.000	3.125	6.188	5.250	5.978	5.175	6.125	5.188	5.938	5.125	5.938	5.000	10.000
BB-1801	6.438	8.313	11.000	5.938	6.188	8.047	5.978	7.972	6.125	7.984	5.938	7.922	5.938	7.797	10.000
BB-1802	8.188	5.500	11.000	3.125	7.938	5.250	7.728	5.175	7.875	5.188	7.688	5.125	7.688	5.000	10.000
BB-1803	8.188	8.313	11.000	5.938	7.938	8.047	7.728	7.972	7.875	7.984	7.688	7.922	7.688	7.797	10.000
BB-1804	8.188	11.063	11.000	8.688	7.938	10.828	7.728	10.753	7.875	10.766	7.688	10.703	7.688	10.578	10.000
BB-1806	9.938	8.313	11.000	5.938	9.688	8.047	9.478	7.972	9.625	7.984	9.438	7.922	9.438	7.797	10.000
BB-1807	9.938	8.313	15.000	5.938	9.688	8.047	9.478	7.972	9.625	7.984	9.438	7.922	9.438	7.797	14.000
BB-1808	9.938	11.063	11.000	8.688	9.688	10.828	9.478	10.753	9.625	10.766	9.438	10.703	9.438	10.578	10.000
BB-1809	9.938	11.063	15.000	8.688	9.688	10.828	9.478	10.753	9.625	10.766	9.438	10.703	9.438	10.578	14.000



OTHER MODELS IN THIS SERIES

-- External Dimensions --

▼

-- Internal Dimensions --

▼

Model #	External Dimensions	Internal Dimensions !
BB-1800-BT	6.43" x 5.50" x 11.00"	5.94" x 5.00" x 10.00"
BB-1800-RB	6.43" x 5.50" x 11.00"	5.94" x 5.00" x 10.00"
BB-1801-BT	6.43" x 8.31" x 11.00"	5.94" x 7.80" x 10.00"
BB-1801-RB	6.43" x 8.31" x 11.00"	5.94" x 7.80" x 10.00"
BB-1804-BT	8.18" x 11.06" x 11.00"	7.69" x 10.58" x 10.00"
BB-1804-RB	8.18" x 11.06" x 11.00"	7.69" x 10.58" x 10.00"
BB-1802-BT	8.18" x 5.50" x 11.00"	7.69" x 5.00" x 10.00"
BB-1802-RB	8.18" x 5.50" x 11.00"	7.69" x 5.00" x 10.00"
BB-1803-BT	8.18" x 8.31" x 11.00"	7.69" x 7.92" x 10.00"
BB-1803-RB	8.18" x 8.31" x 11.00"	7.69" x 7.92" x 10.00"
BB-1808-BT	9.93" x 11.06" x 11.00"	9.44" x 10.58" x 10.00"
BB-1808-RB	9.93" x 11.06" x 11.00"	9.44" x 10.58" x 10.00"
BB-1809-BT	9.93" x 11.06" x 15.00"	9.44" x 10.58" x 14.00"
BB-1809-RB	9.93" x 11.06" x 15.00"	9.44" x 10.58" x 14.00"
BB-1806-BT	9.93" x 8.31" x 11.00"	9.44" x 7.80" x 10.00"
BB-1806-RB	9.93" x 8.31" x 11.00"	9.44" x 7.80" x 10.00"
BB-1807-BT	9.93" x 8.31" x 15.00"	9.44" x 7.80" x 14.00"
BB-1807-RB	9.93" x 8.31" x 15.00"	9.44" x 7.80" x 14.00"

RELATED PRODUCT SERIES



Champion Series Electronics Cabinet

VIEW SERIES DETAILS



Contour Utility Series Enclosure

VIEW SERIES DETAILS



Converta Box Metal Enclosure

VIEW SERIES DETAILS

