



RESETABLE CIRCUIT
BREAKER

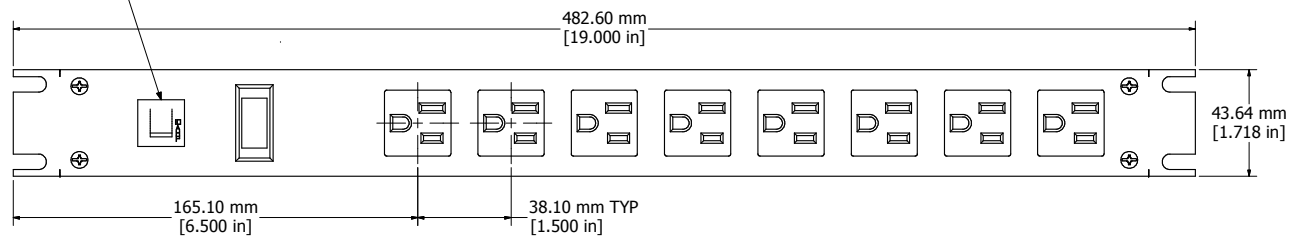


ASSEMBLY - VIEW FROM FRONT

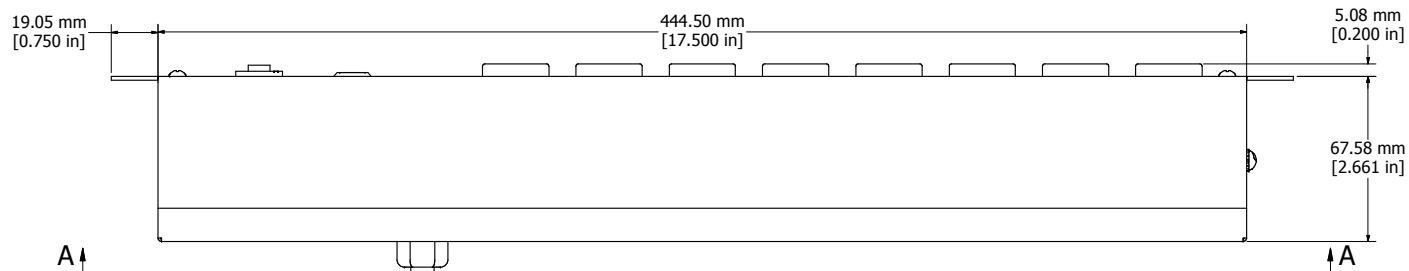


6' FOOT LOCKING
POWER CORD
(NEMA L5-15P)


ASSEMBLY - VIEW FROM BOTTOM

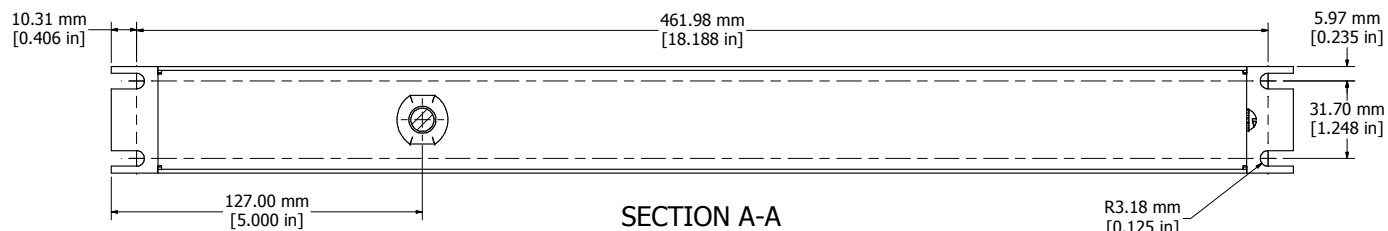

SECTION A-A

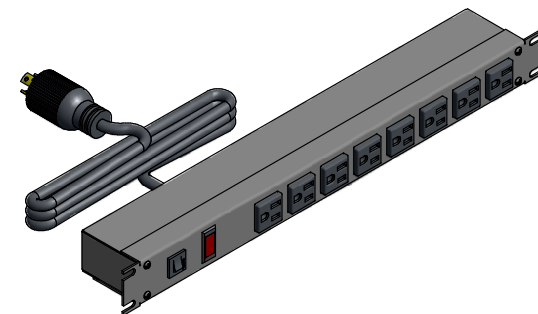

ISOMETRIC VIEW

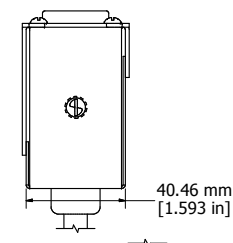

ASSEMBLY - VIEW FROM SIDE

1582T8C1

Finish - Front - ASA 61 Grey Painted Steel

Back - ASA 61 Grey Painted Steel

Rated - 125 VAC, 60 Hz, 15 Amps

Approvals - CSA Certified Standards C22.2 (No. 21-95, 42-99)

- UL Recognized Standard UL1363



HAMMOND
MANUFACTURING™

1582T8C1

www.hammondmfg.com