


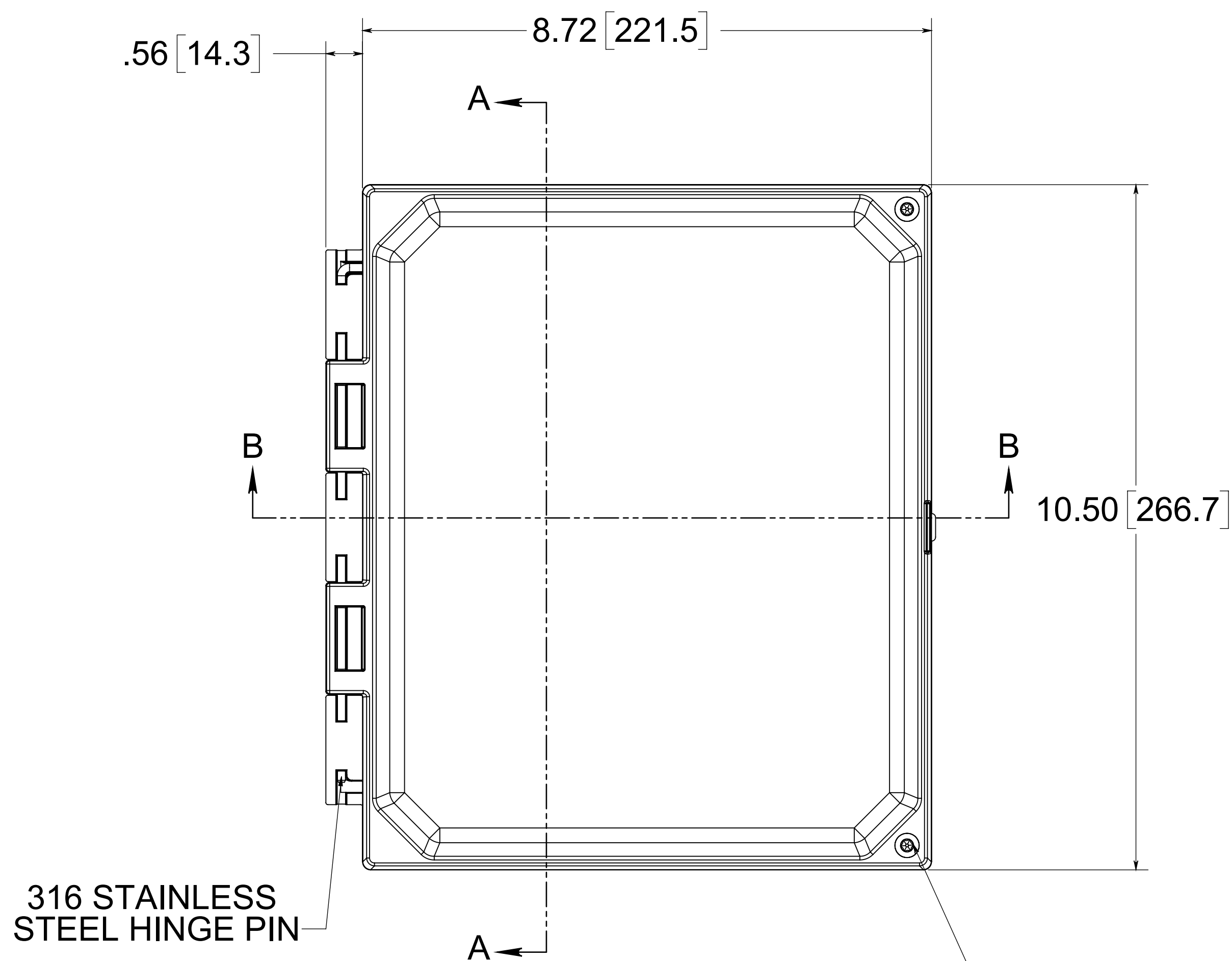

316 STAINLESS
STEEL HINGE PIN

(2) EACH #10-32 BRASS
INSERTS, AND 316 STAINLESS
STEEL CAPTIVE TAMPER
PROOF SCREWS WITH O-RINGS


FIP
POLYURETHANE
GASKET

.145 [3.7]

SECTION B-B
SCALE 1 : 1.5



FIP
POLYURETHANE
GASKET

MATERIAL:
BOX- INJECTION POLYCARBONATE
STANDARD COVER- INJECTION POLYCARBONATE
CLEAR COVER-INJECTION POLYCARBONATE

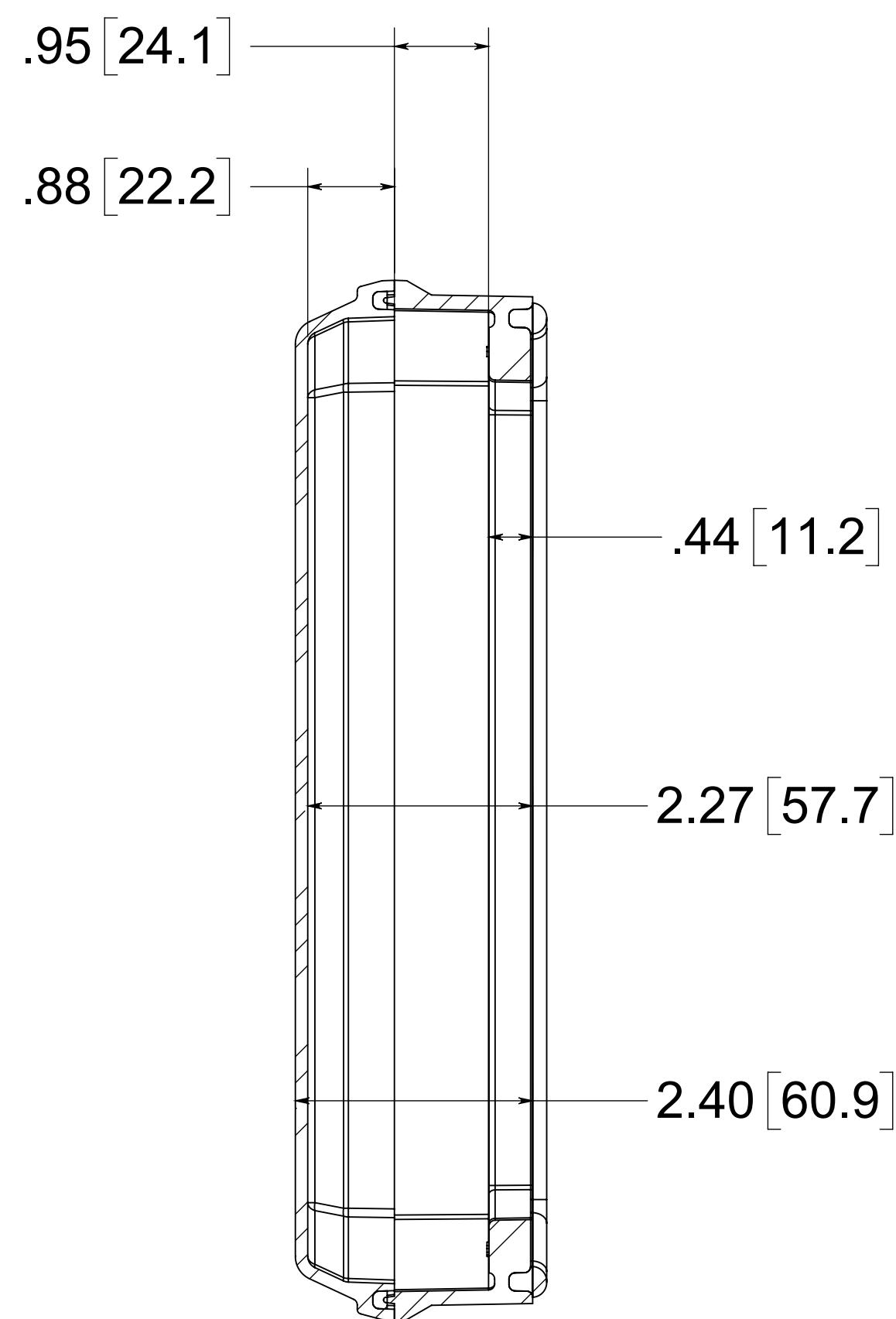

SECTION A-A


Ø .23 [5.8]

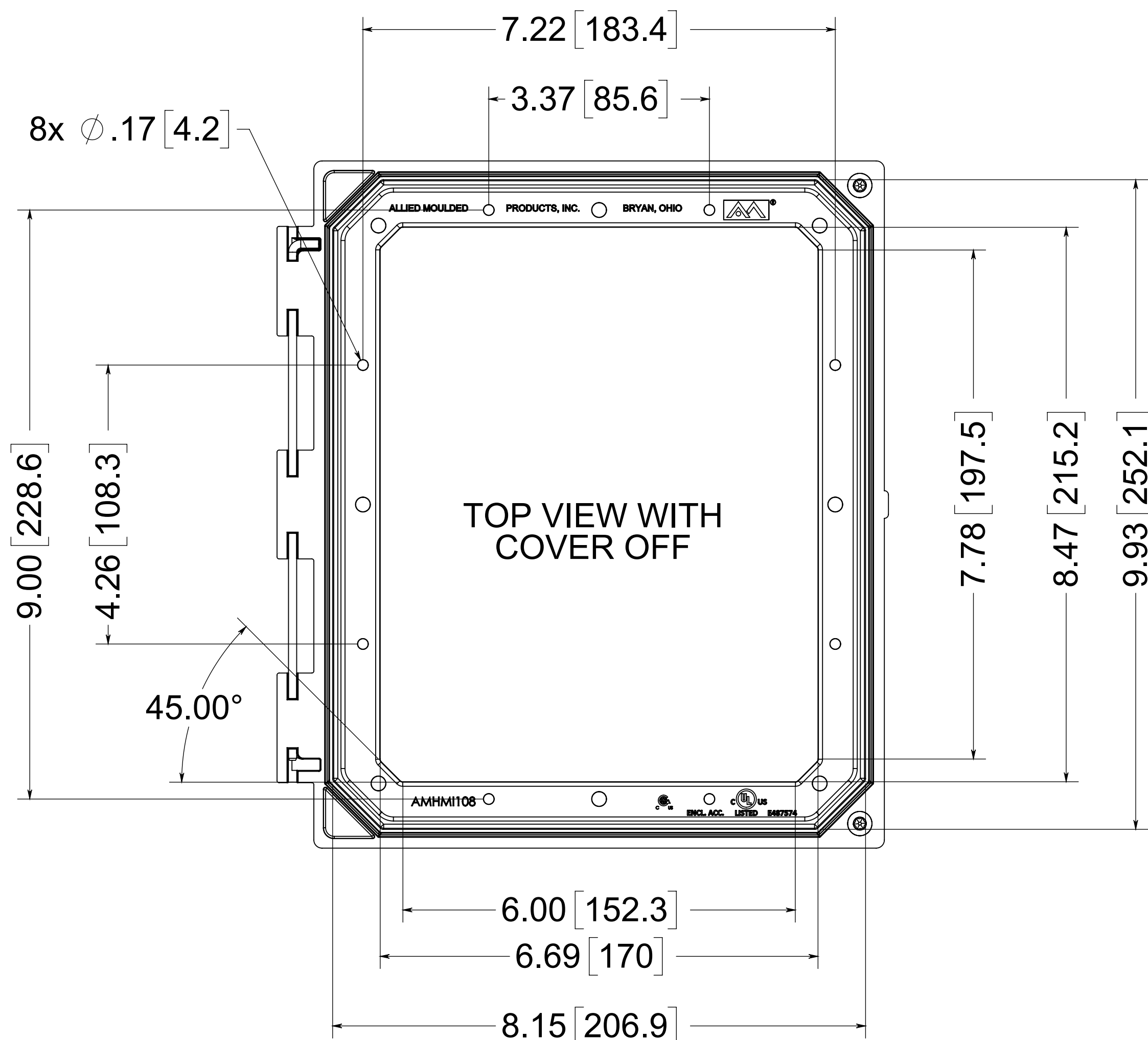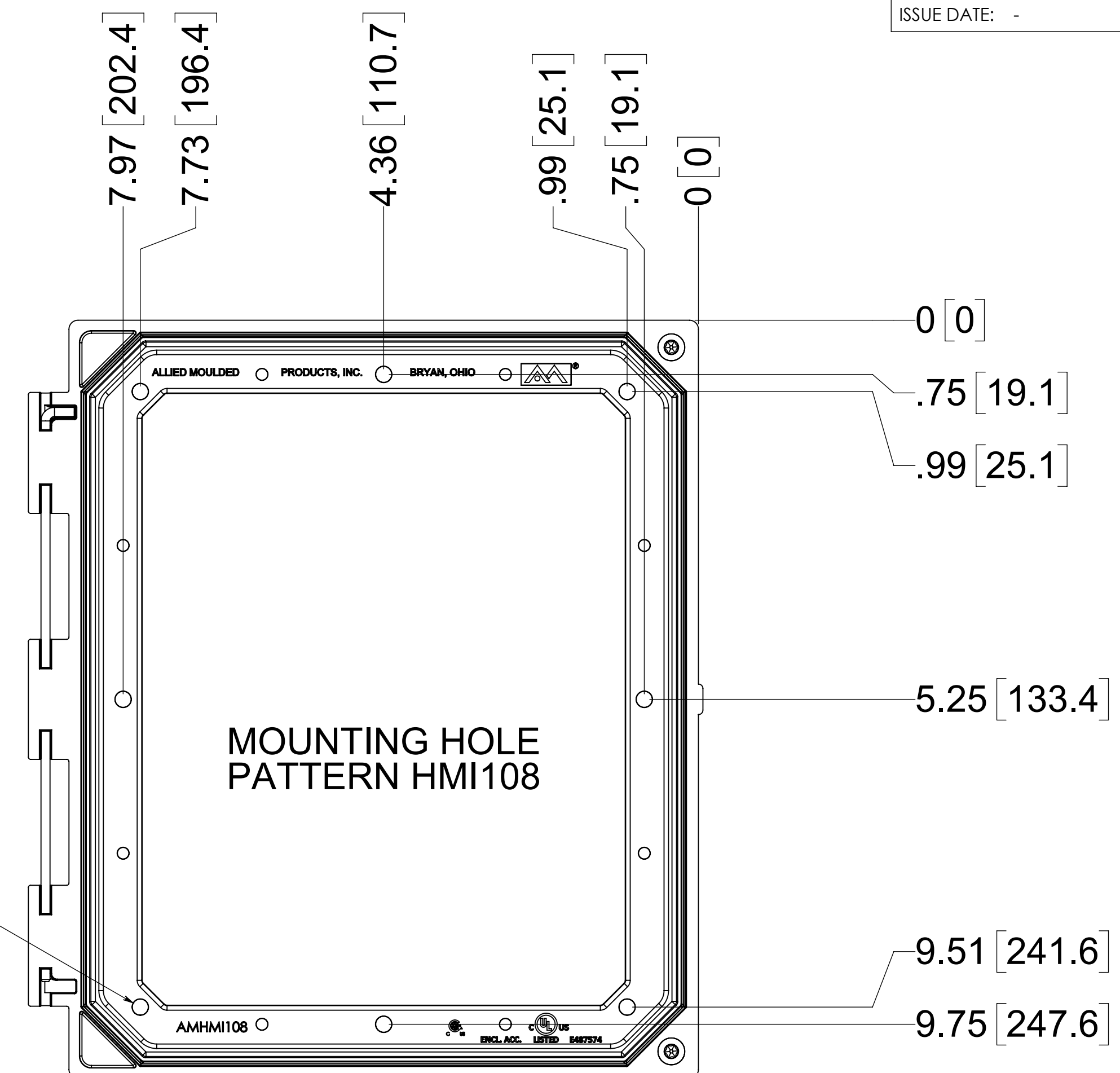

8x Ø .17 [4.2]

45.00°

NOTE:
1. DATA SUBJECT TO CHANGE
2. WILL FIT ENCLOSURE
SIZES 12X10 AND LARGER

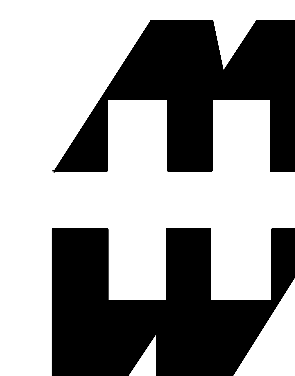

PART No. PJHMI108CCHTP

for more information visit
www.hammfg.com
Data subject to change without notice
Drawing Not to Scale