

RESETABLE CIRCUIT
BREAKER

LIGHTED ON/OFF
POWER SWITCH

10.31 mm
[0.406 in]


461.98 mm
[18.188 in]

5.97 mm
[0.235 in]

31.70 mm
[1.248 in]

R3.18 mm
[0.125 in]

ASSEMBLY - VIEW FROM FRONT

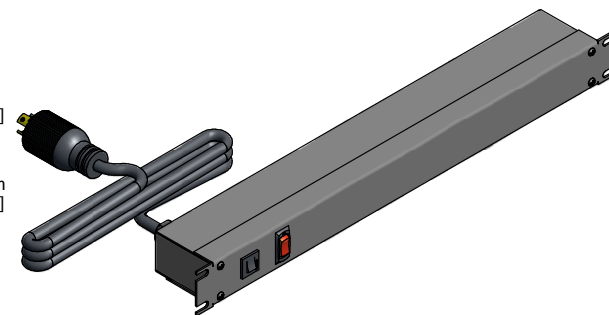

ISOMETRIC VIEW

19.05 mm
[0.750 in]

444.50 mm
[17.500 in]

2.40 mm
[0.094 in]

67.58 mm
[2.661 in]


A

A

6' FOOT LOCKING
POWER CORD
(NEMA L5-15P)

ASSEMBLY - VIEW FROM BOTTOM

ASSEMBLY - VIEW FROM SIDE

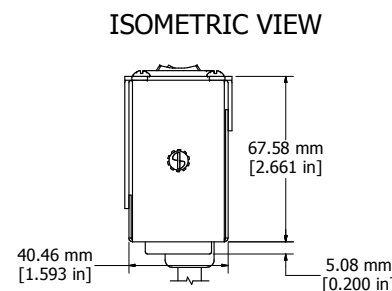

482.60 mm
[19.000 in]

43.64 mm
[1.718 in]

152.15 mm
[5.990 in]

38.10 mm TYP
[1.500 in]

76.20 mm TYP
[3.000 in]

SECTION A-A

1583H6C1

Finish - Front - ASA 61 Grey Painted Steel

Back - ASA 61 Grey Painted Steel

Rated - 125 VAC, 60 Hz, 15 Amps

Approvals - CSA Certified Standards C22.2 (No. 21-95, 42-99)

- UL Recognized Standard UL1363



HAMMOND
MANUFACTURING™

1583H6C1

www.hammondmfg.com