




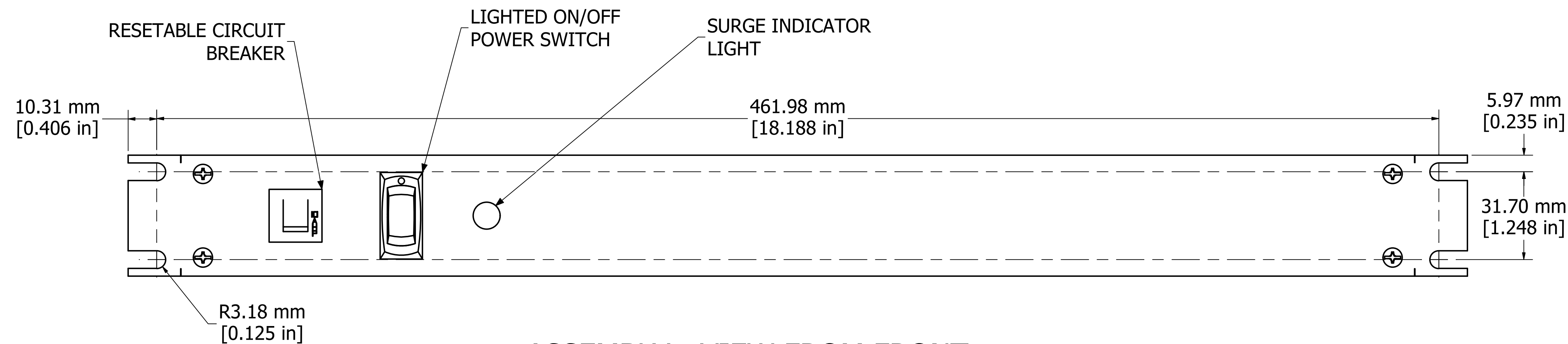


ASSEMBLY - VIEW FROM FRONT

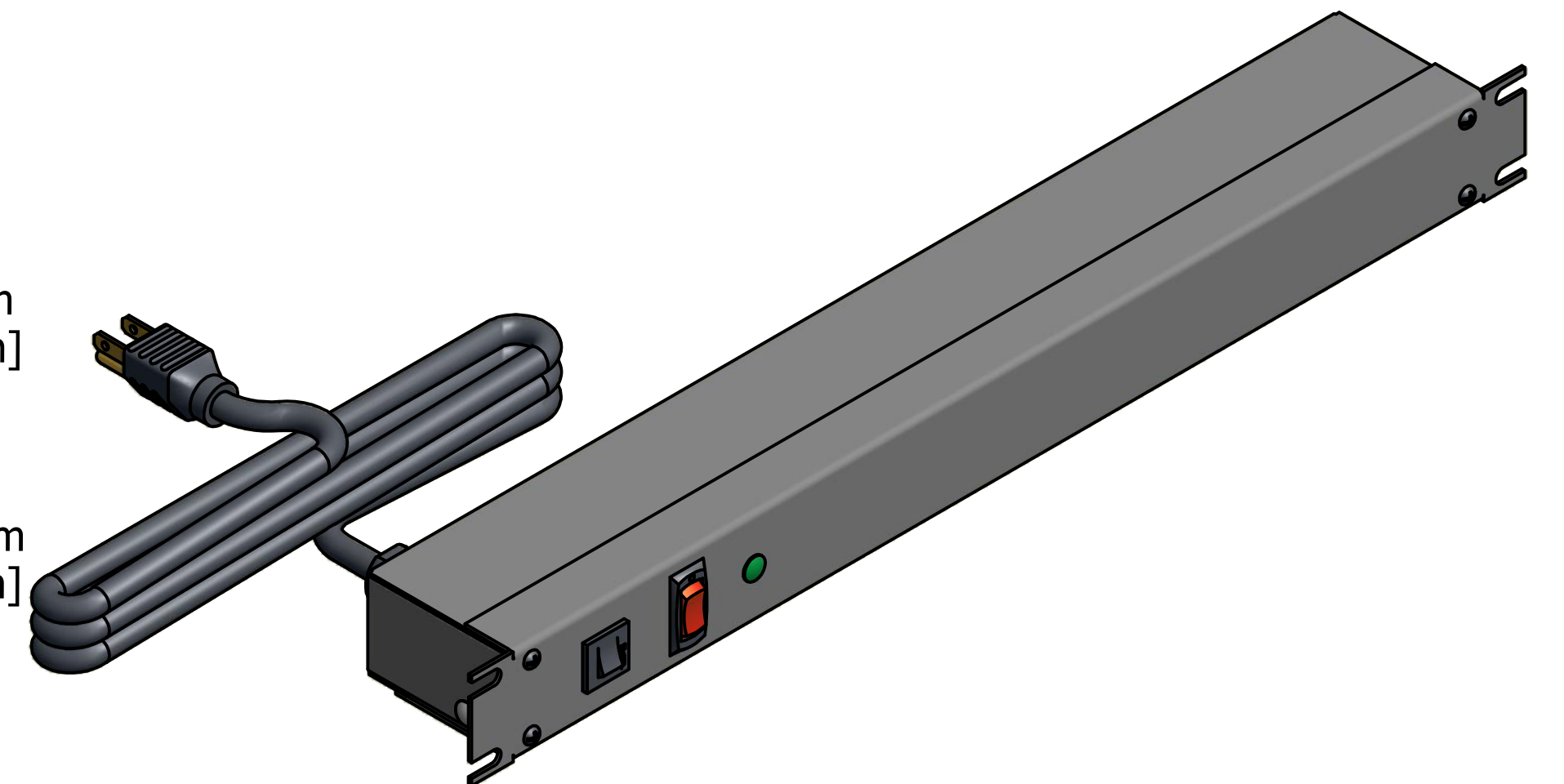


ISOMETRIC VIEW

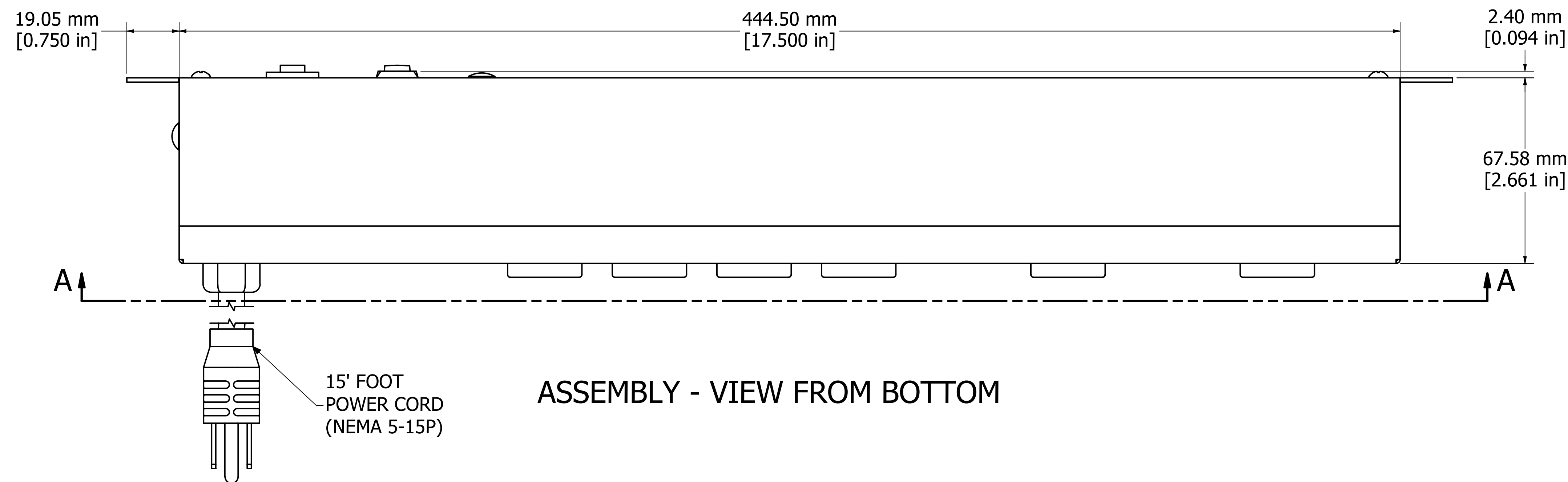

ASSEMBLY - VIEW FROM BOTTOM

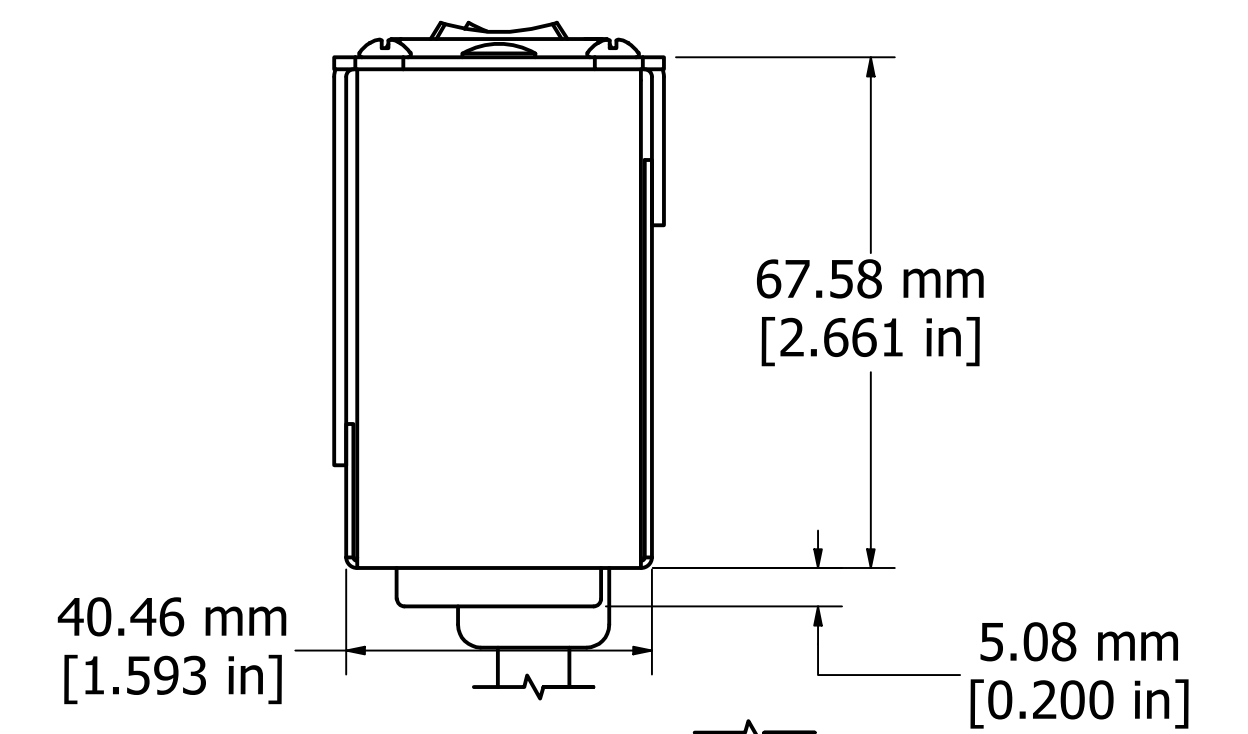


ASSEMBLY - VIEW FROM SIDE

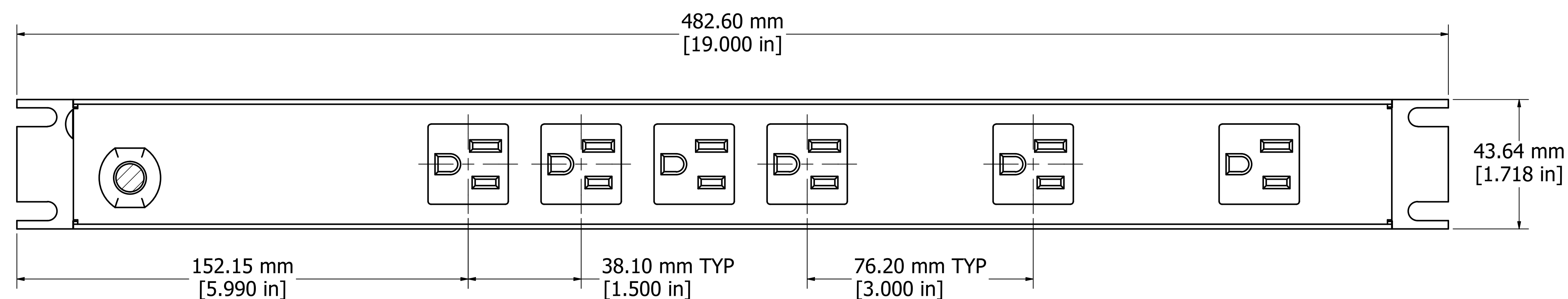

SECTION A-A

1583H6B1S
Finish - Front - ASA 61 Grey Painted Steel
Back - ASA 61 Grey Painted Steel
Rated - 125 VAC, 60 Hz, 15 Amps
Approvals - cURus Recognized to: UL1449 & C22.2 No. 269.3-17
Surge Specs - 1080 Joules, 75000 Amps Transient Current
- 500V Voltage Protection Rating (VPR)

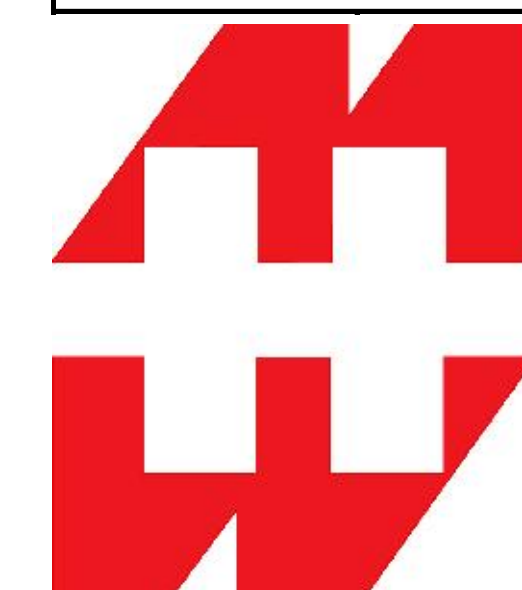

HAMMOND
MANUFACTURING™

1583H6B1S

www.hammondmfg.com