




SECTION A-A  
(VIEW FROM FRONT)

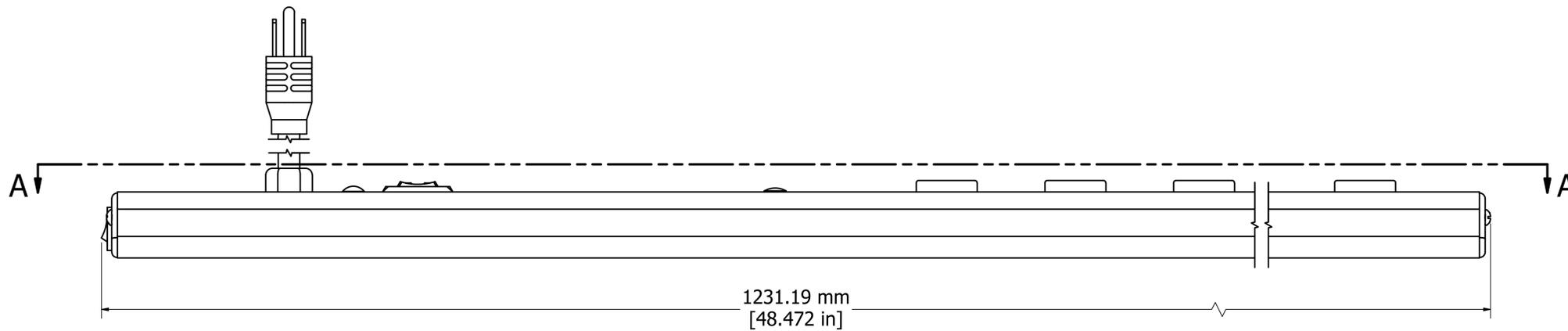

ASSEMBLY - VIEW FROM SIDE

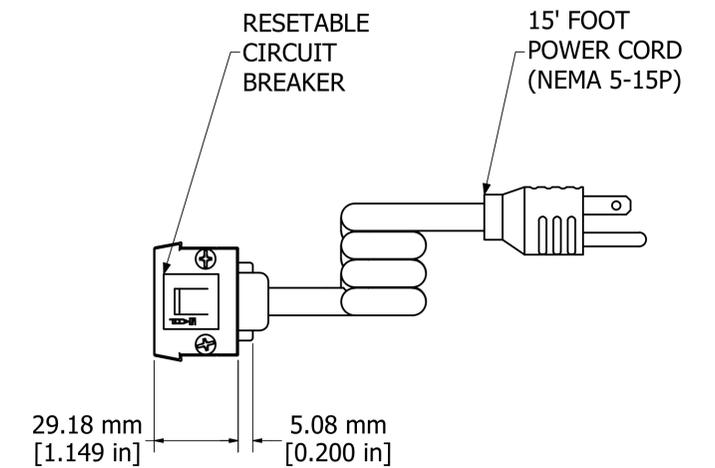


ASSEMBLY - VIEW FROM END

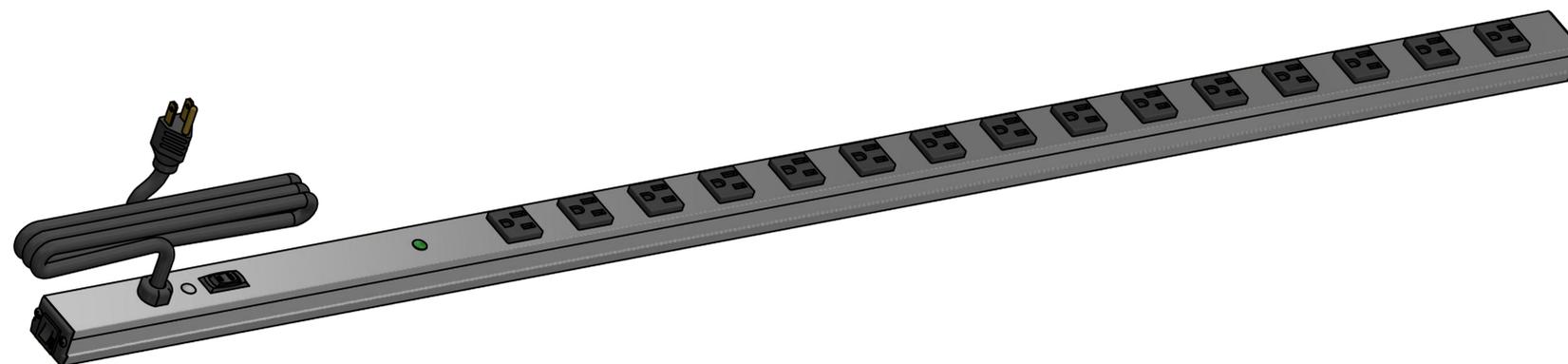

ISOMETRIC VIEW

<b>1585H15B1S</b>
Finish - Case - Anodized Aluminum Extrusion
Ends - ABS Plastic
Rated - 125 VAC, 60 Hz, 15 Amps
Approvals - cULus Listed to: UL1449 & C22.2 No. 269.3-17
Surge Specs - 1080 Joules, 75000 Amps Transient Current - 500V Voltage Protection Rating (VPR)
<b>Accessories Included</b>
Mounting Bracket Kit with Hardware

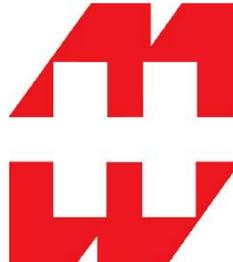

**HAMMOND  
MANUFACTURING™**  
**1585H15B1S**  
www.hammondmfg.com