


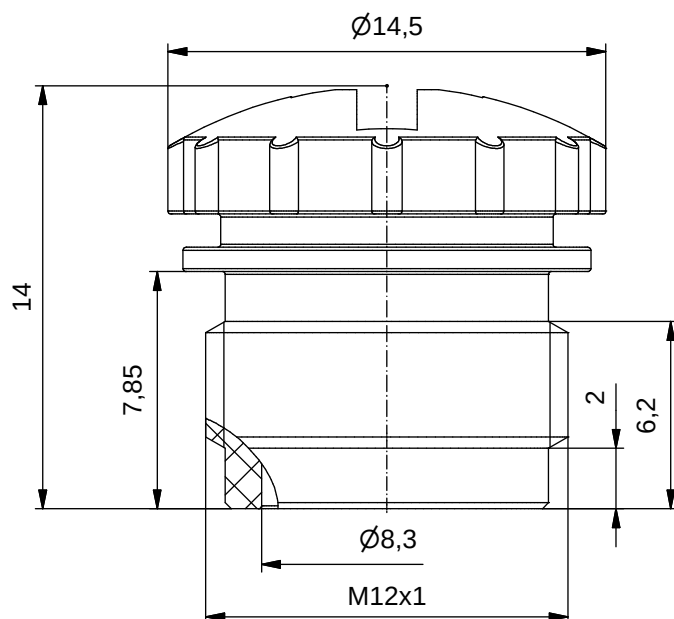

Technical specification:

Degree of protection: IP 67, in mated condition
IEC 60529

Temperature range: -30°C ... +120°C


Materials:

Protecting cap: PA GF

 
Loop: TPU-V

Installation specification:

Recommended torque: 0,6 Nm

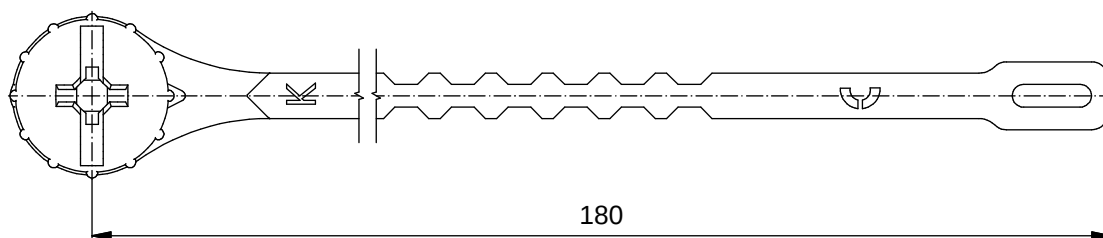

Part no:	Description:	Colour:
43-16212	Protecting cap M12x1 female socket with loop	black

DO NOT ALTER CAD DRAWING BY HAND Directive 2011/65/EU RoHS compliant	Index: b 11.11.13 Brū Ä4989 Data sheet revised, material changed			 dim. in mm		title: Protecting cap M12x1 with loop, female socket	
		date	name				
	tolerance of cable:			drawn	18.01.13	Kniesburgers	dwg no:
				appd.	18.01.13	Mankopf	
	general tolerance: 0 ± 0,50mm 0,0 ± 0,25mm 0,00 ± 0,10mm					43K1A1802	
	THIS DRAWING MAY NOT BE COPIED OR REPRODUCED IN ANY WAY, AND MAY NOT BE PASSED ON TO A THIRD PARTY WITHOUT WRITTEN PERMISSION. OWNERSHIP AND COPYRIGHT OF CONEC GmbH					part no: see table	