


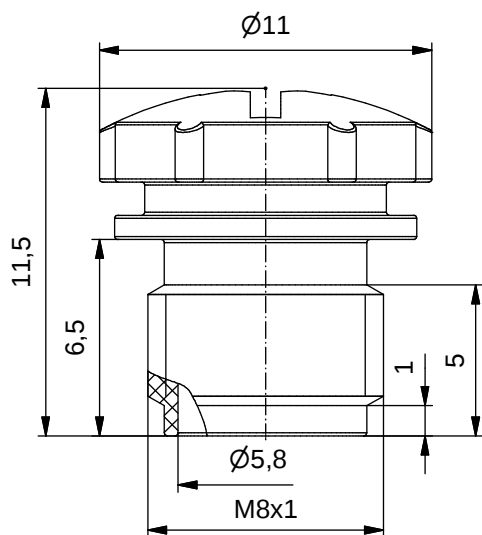

Technical specification:

Degree of protection: IP 67, in mated condition
IEC 60529

Temperature range: -30°C ... +120°C


Materials:

Protecting cap: PA GF

 
Loop: TPU-V

Installation specification:

Recommended torque: 0,4 Nm

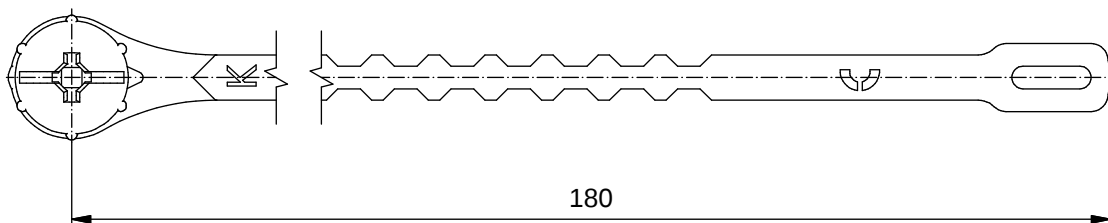

Part no:	Description:	Colour:
42-11773	Protecting cap M8x1 female socket with loop	black

DO NOT ALTER CAD DRAWING BY HAND Directive 2002/95/EC RoHS compliant	Index: b 11.11.13 Brū Ä4989 Data sheet revised, material changed			 dim. in mm		title: Protection cap M8x1 with loop, female socket	
			date	name			
				drawn	18.01.13	Gitinow	dwg no:
				appd.	21.01.13	Kniesburgers	
	general tolerance: 0 ± 0,50mm 0,0 ± 0,25mm 0,00 ± 0,10mm					42K1A427	
	THIS DRAWING MAY NOT BE COPIED OR REPRODUCED IN ANY WAY, AND MAY NOT BE PASSED ON TO A THIRD PARTY WITHOUT WRITTEN PERMISSION. OWNERSHIP AND COPYRIGHT OF CONEC GmbH					part no: see table	

general tolerance: 0 ± 0,50mm
0,0 ± 0,25mm
0,00 ± 0,10mm

THIS DRAWING MAY NOT BE COPIED OR REPRODUCED IN ANY WAY, AND MAY NOT BE PASSED ON TO A THIRD PARTY WITHOUT WRITTEN PERMISSION. OWNERSHIP AND COPYRIGHT OF CONEC GmbH

CONEC®