
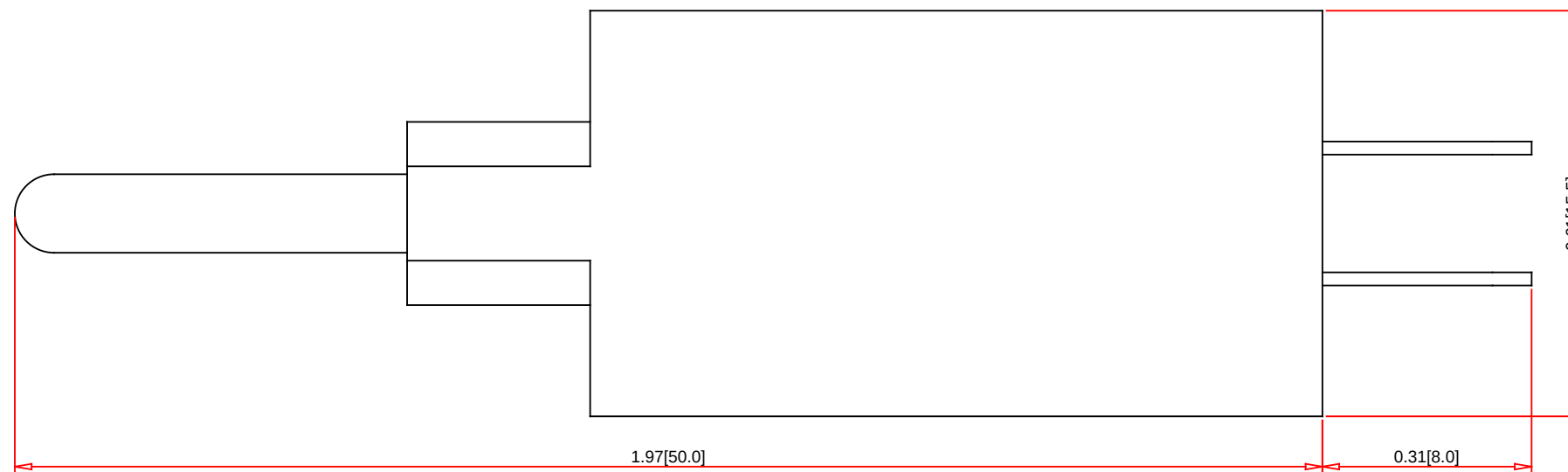


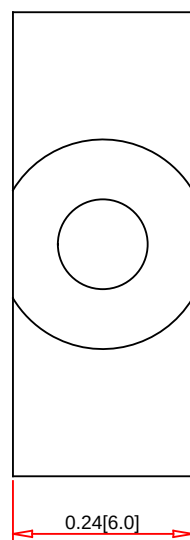

Note: - Drawings Not To Scale - Drawings Subject to Change Without Notice - Dimensions are inches next to [Millimeters]		Part No.: ZB6EG4B		Schneider Electric Schneider Electric United States North American Division Boston One Campus 800 Federal Street Andover, MA 01810, USA Phone: +1 8773425173 Email: CCC@us.schneider-electric.com	
Technical Information: UL File: E164353 CCN NKCR CSA File: LR44087 Class 321103 CE Marked: Yes RoHS: Yes NEMA / IP Rating: NEMA 1/2/3/4/4X/12, IP65 Terminal Type: Quick Connect/Solder Tabs			Description: Head Type: not applicable Style: Protected LED 48/120Vac Bezel Material: Color: Red Operator Action: n/a Operator Type: Illuminated Specification:		