

Euromas ABS / PC / F05 | Threaded inserts for mounting bosses



DODGE M3x6,5

Order no.: 59002810

ND = 4.0 x 6.5

* = Available on request.

Characteristics

Colour of enclosure group

--

Enclosure Material

ABS, PC (UV stabilised) and selected sizes in PC UL 94 V0 (additional UL 94 V0 versions on request)

The highest flammability rating of UL 94 5V is achieved even with slightly reduced outdoor suitability (f2 listing acc. to UL 746).

Seal: CR

V215: Vestamid, CR seal

For details see Technical Information

Scope of delivery


1 piece

Note

Put the threaded insert into the boss until it touches the base. Then hammer down the stretcher plate using a pin.

Product drawing

Enclosure concept

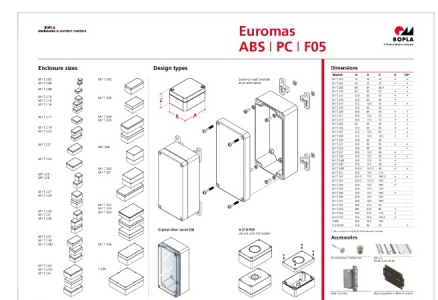

Important!

To compensate for pressure when temperatures change and cause moisture in the enclosure, we recommend that you use a [pressure compensation](#) element.

In order to ensure that you can determine **the correct quantity of elements for your application**, we are providing you here with a DAE calculator.

[» Additional information](#)

Technical documentation / Downloads

Technical drawings

3D product data in STEP format:

59002810 Dodge-M3-x-65-gespreizt.stp
(3.9 MB)

3D product data in STEP format:

59002810 Dodge-M3-x-65-ungespreizt.stp
(4.7 MB)

Works test certificates

670 WPZ-Euromas-PC DE.pdf

(197.3 KB)

670 WPZ-Euromas-PC EN.pdf

(191.1 KB)

Product information

euromas-abs-pc-f05 en.pdf

(1.1 MB)