




INSULATION DISPLACEMENT CABLE:
0.025" PITCH, 30 AWG, STRANDED EXTRUDED FEP

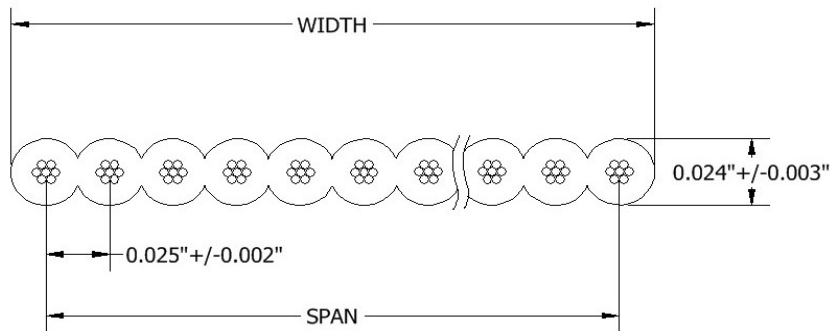

Cond. No.	Part Number	Span	Width
4	1000570287	0.075" $\pm$ 0.005"	0.100" $\pm$ 0.005"
6	1000570291	0.125" $\pm$ 0.005"	0.150" $\pm$ 0.005"
8	1000570296	0.175" $\pm$ 0.005"	0.200" $\pm$ 0.007"
9	1000570297	0.200" $\pm$ 0.005"	0.225" $\pm$ 0.007"
10	1000570272	0.225" $\pm$ 0.005"	0.250" $\pm$ 0.007"
12	1000570273	0.275" $\pm$ 0.005"	0.300" $\pm$ 0.007"
14	1000570277	0.325" $\pm$ 0.005"	0.350" $\pm$ 0.007"
15	1000570275	0.350" $\pm$ 0.005"	0.375" $\pm$ 0.007"
16	1000570276	0.375" $\pm$ 0.005"	0.400" $\pm$ 0.007"
20	1000570021	0.475" $\pm$ 0.005"	0.500" $\pm$ 0.007"
24	1000570279	0.575" $\pm$ 0.005"	0.600" $\pm$ 0.007"
26	1000570022	0.625" $\pm$ 0.005"	0.650" $\pm$ 0.007"
30	1000570023	0.725" $\pm$ 0.005"	0.750" $\pm$ 0.007"
32	1000570084	0.775" $\pm$ 0.005"	0.800" $\pm$ 0.007"
34	1000570283	0.825" $\pm$ 0.005"	0.850" $\pm$ 0.007"
36	1000570284	0.875" $\pm$ 0.005"	0.900" $\pm$ 0.007"
40	1000570024	0.975" $\pm$ 0.006"	1.000" $\pm$ 0.007"
50	1000570025	1.225" $\pm$ 0.006"	1.250" $\pm$ 0.010"
60	1000570026	1.475" $\pm$ 0.006"	1.500" $\pm$ 0.010"
64	1000570292	1.575" $\pm$ 0.006"	1.600" $\pm$ 0.010"
68	1000570027	1.675" $\pm$ 0.006"	1.700" $\pm$ 0.010"
72	1000570507	1.775" $\pm$ 0.006"	1.800" $\pm$ 0.010"
80	1000570028	1.975" $\pm$ 0.006"	2.000" $\pm$ 0.010"
100	1000570029	2.475" $\pm$ 0.006"	2.500" $\pm$ 0.010"

CHARACTERISTICS		
Conductor	30 AWG, 7/38, Silver Plated Copper	
Insulation	FEP	
Color	Natural with Blue Polarity Stripe	
Impedance (ohms)	85 Unbalanced	120 Balanced
Capacitance (pF/ft)	16.8 Unbalanced	10.8 Balanced
Inductance (uH/ft)	0.11 Unbalanced	0.16 Balanced
Insulation Resistance (Mohm)	>500	
Voltage Rating	150V	
Temperature Rating	-55°C to 150°C	

STANDARD PACKAGING
100 ft./spool, 10 Ft. minimum length

UL STYLE 20726