
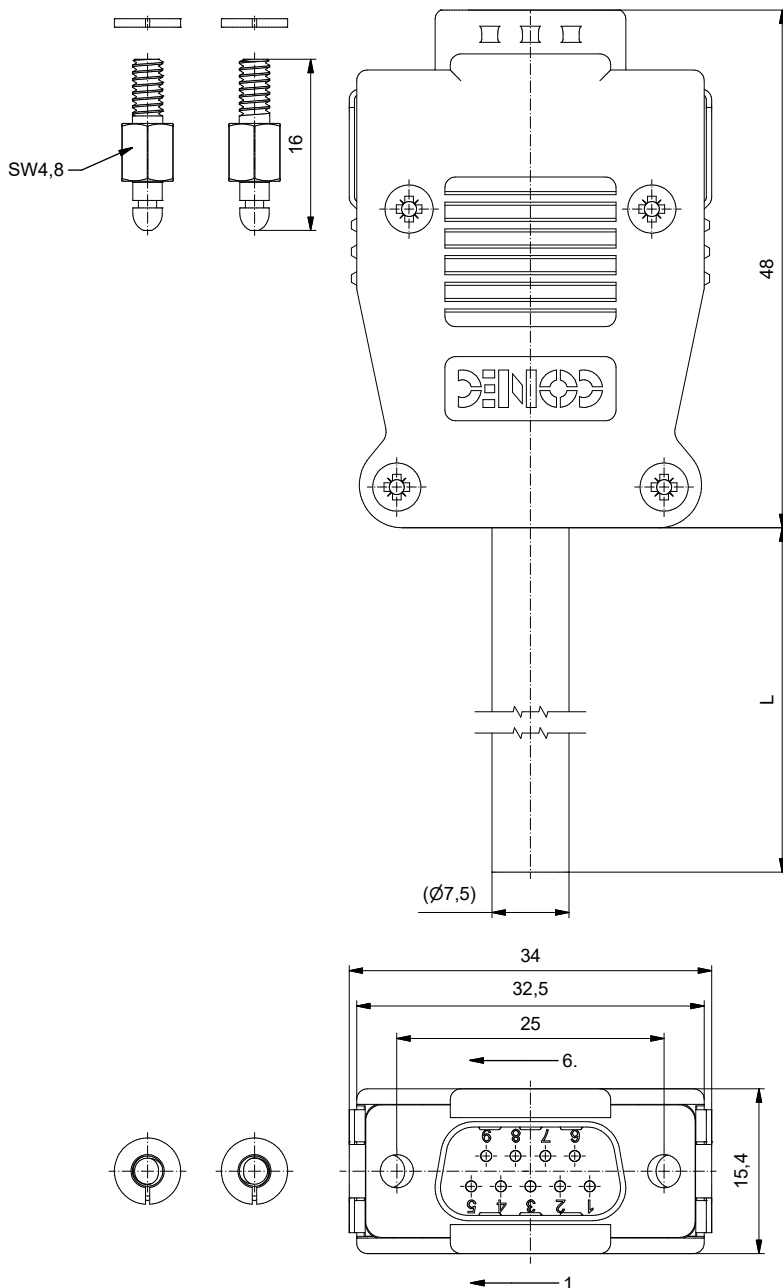


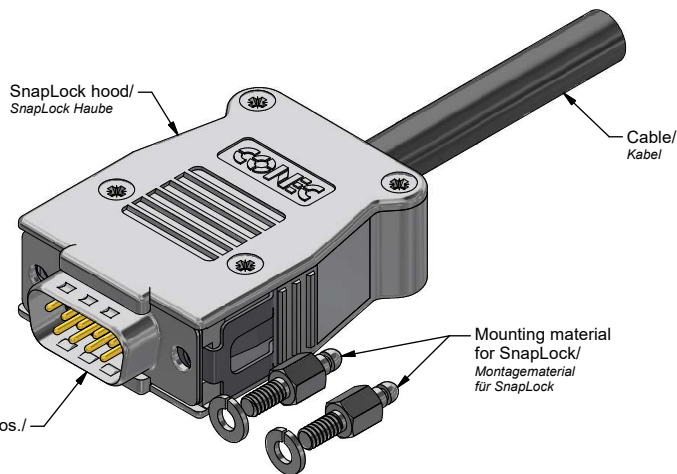

Materials SnapLock hood/ Werkstoffe SnapLock Haube:

Hood/ Haube:	ABS UL 94 V-0, Ni
Blanking plug/ Blindstopfen:	ABS UL 94 V-0, Ni
Cable strain relief/ Zugentlastung:	Steel, Ni
Clip/ Clip:	Stainless Steel/ Edelstahl
Countersunk-head screw/ Linsenkopfschraube:	Steel, Ni
Mounting material/ Montagematerial:	Steel, Ni

Materials D-SUB Male 9pos./ Werkstoffe D-SUB Stift 9pol.:

Insulator/ Isolierkörper:	PA 66 GF UL 94 V-0
Shell/ Gehäuse:	Steel, Sn over Ni
Crimp contact/ Crimpkontakt:	Copper alloy, Au over Ni

Contact assignment/ Kontaktbelegung:

D-Sub

1	black/schwarz
2	brown/braun
3	red/rot
4	pink/rosa
5	yellow/gelb
6	green/grün
7	blue/blau
8	violet/violett
9	grey/grau
	white/weiss

Shielding
cable strain relief/
Schirmauflage
Zugentlastung

Part no/ Art.-Nr.:	Length L/ Länge L:	Cable/ Kabel:
16-512330	1,8 m	PVC, grey/grau, 10x0,25 mm², LiY-CY Cable/Kabel: 781-GN211000
16-512340	3 m	
16-512350	5 m	

				dim. in mm		D-Sub Male 9pol. in SnapLock hood with cable and mounting material		
		Date/Datum		Name				
		drawn/ gez. appd./ gepr.		25.11.2024 Lehmenkühler				
				29.11.2024 Koch				
Index: a Original		scale/maßstab: 2:1				dwg no / Z.-nr.: 16K1A4393		DIN- A3
ROHS compliant, exemption 6c ROHS konform, Ausnahme 6c						Customer specific product		1 / 1