


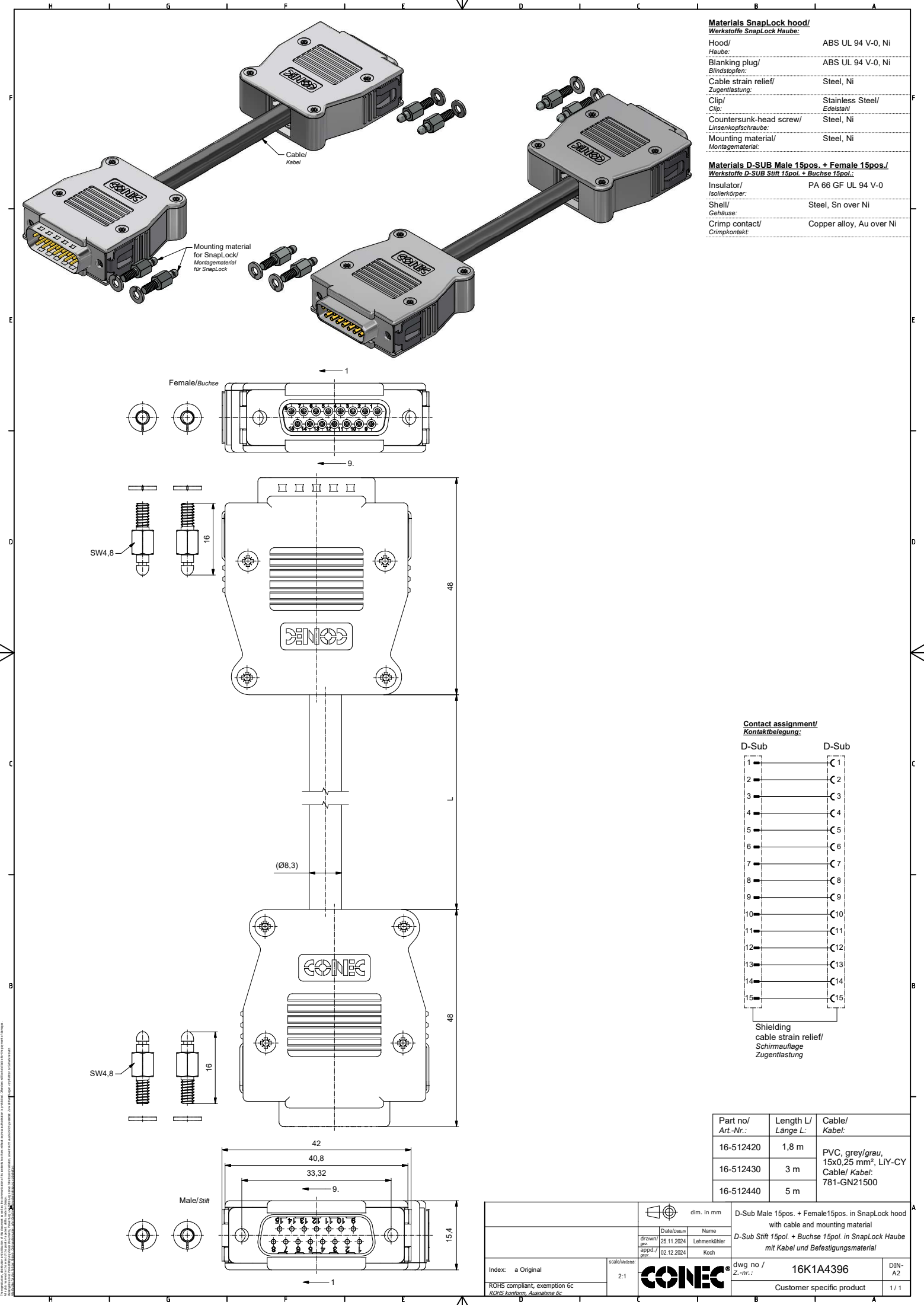

**Materials SnapLock hood/
Werkstoffe SnapLock Haube:**

Hood/ Haube:	ABS UL 94 V-0, Ni
Blanking plug/ Blindstopfen:	ABS UL 94 V-0, Ni
Cable strain relief/ Zugentlastung:	Steel, Ni
Clip/ Clip:	Stainless Steel/ Edelstahl
Countersunk-head screw/ Linsenkopfschraube:	Steel, Ni
Mounting material/ Montagematerial:	Steel, Ni

**Materials D-SUB Male 15pos. + Female 15pos./
Werkstoffe D-SUB Stift 15pol. + Buchse 15pol.:**

Insulator/ Isolierkörper:	PA 66 GF UL 94 V-0
Shell/ Gehäuse:	Steel, Sn over Ni
Crimp contact/ Crimpkontakt:	Copper alloy, Au over Ni

**Contact assignment/
Kontaktbelegung:**

D-Sub	D-Sub
1	C1
2	C2
3	C3
4	C4
5	C5
6	C6
7	C7
8	C8
9	C9
10	C10
11	C11
12	C12
13	C13
14	C14
15	C15

Shielding
cable strain relief/
Schirmauflage
Zugentlastung

Part no/ Art.-Nr.:	Length L/ Länge L:	Cable/ Kabel:
16-512420	1,8 m	PVC, grey/gray, 15x0,25 mm², LiY-CY
16-512430	3 m	Cable/ Kabel: 781-GN21500
16-512440	5 m	

Index: a Original		scale/Vergr.: 2:1		dim. in mm	
ROHS compliant, exemption 6c ROHS konform, Ausnahme 6c		drawn/ gezt. 25.11.2024		Date/ Datum Name Lehmenkühler	
		approved/ gepr. 02.12.2024		Koch	
		dwg no / Z.-nr.:		16K1A4396	
		Customer specific product		DIN-A2	

