


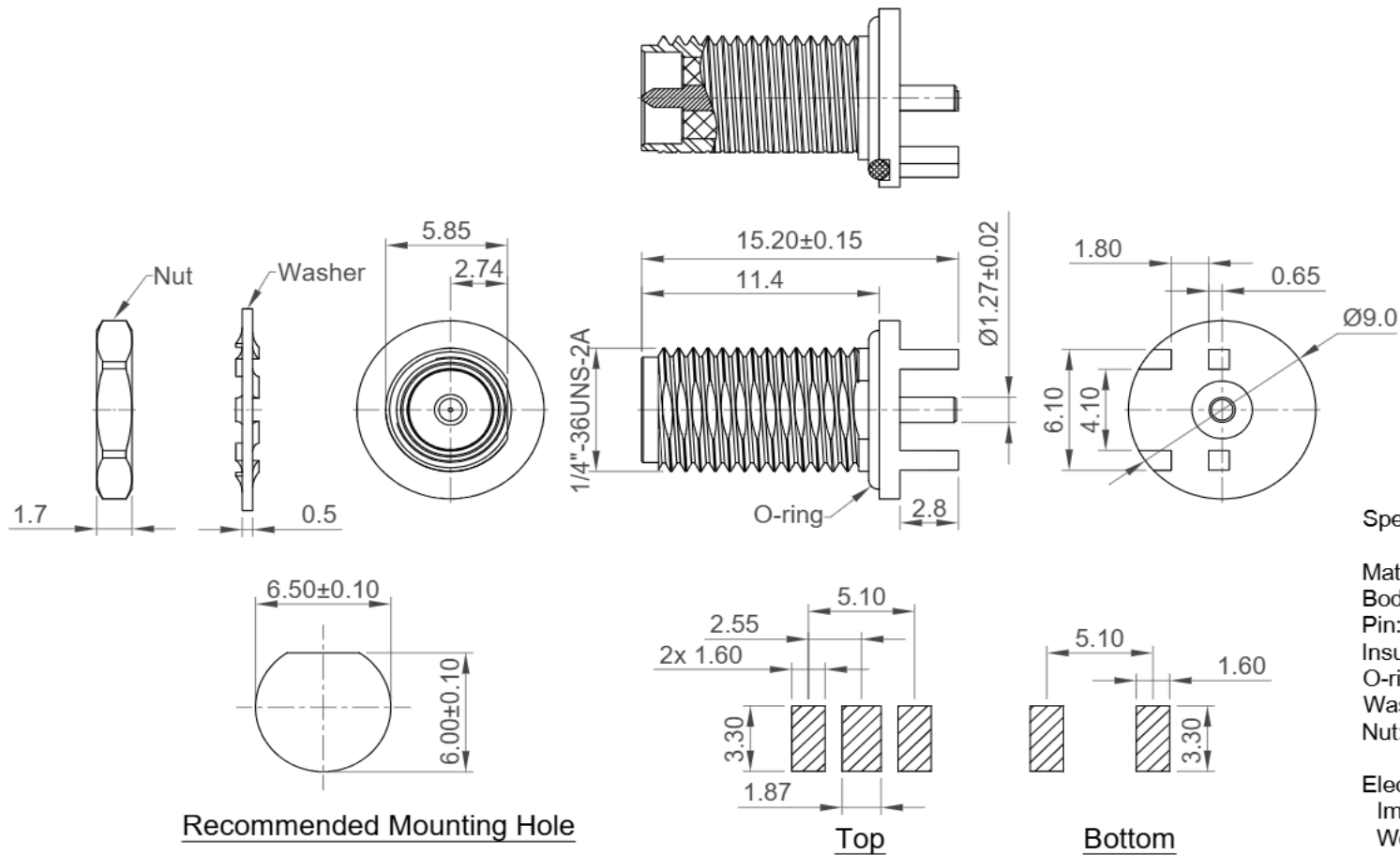

Recommended Mounting Hole

Recommended Foot Print

Tolerance: ± 0.05

Ordering Grid

RFPC-SMA40-FN-180-X

Request Samples and Quotation

Washer and nut options:
A = All Assembled with Connector (Standard)
 Blank = Separately Packed

Specifications

Material
 Body: Brass, Gold Plated.
 Pin: Brass, Gold Plated.
 Insulator: PTFE, White.
 O-ring: Silicone Rubber, Red.
 Washer: Brass, Gold Plated.
 Nut: Brass, Gold Plated.

Electrical

Impedance: 50 Ohm
 Working Frequency Range: DC - 18GHz

Mechanical & Environmental

Operating Temperature: $-55^{\circ}\text{C} \sim +125^{\circ}\text{C}$
 Ingress Protection Rating: IP67
 IP6x - Dust tight - no particle ingress.
 IPx7 Waterproof for 30 minutes up to 1m underwater.
(mated with plug, the plug has inner gasket)
 Recommended PCB Thickness: 1.60mm.
 Other PCB thickness available on request

Part Number		Product Description	
RFPC-SMA40-FN		RP SMA Bulkhead Jack With O-ring, Edge Mount,	
Drawing Date		IP67, 18GHz	
18th February 2025			
By	CC	Tolerances (Except as Noted)	Units:
Detail	Drawing Release	Length	Metric (mm)
Revision	A	Angle	3rd Angle Projection
Date	18/02/25	X.X ± 0.20	
		X.XX ± 0.10	
		$\pm 1^{\circ}$	
		RoHS COMPLIANT 2011/65/EU Deca-BDE	
		This drawing is confidential and copyright of Global Connector Technology, Ltd (GCT). This drawing must not be copied or disclosed without written consent. E & OE	
		Not to Scale Drawn By CC Sheet No. 1/1	

GCT
 www.gct.co