

Wire to Board Connectors

Economy Power (EP) Connectors

Crimp Type Receptacles

Crimp snap-in type receptacle contacts

Wire size range : AWG#22~18
(0.3~0.89 mm²)
Insulation Diameter : 1.7~3.0mm

Part Number : 1123721-1
(Strip form)

Part Number : 1318912-1
(Lose piece)


Material and Finish : Phosphor
bronze, pre-tin plated

Part Number : 1123721-2
(Strip form)

Material and Finish : Brass,
pre-tin plated



Hand Tool

Part Number : 1366402-1


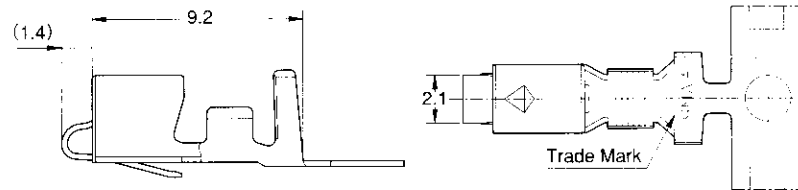


Plug Housing

Material and Finish : 66 Nylon,
UL94V-0 rated, natural, yellow,
blue, red, black and green

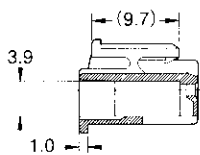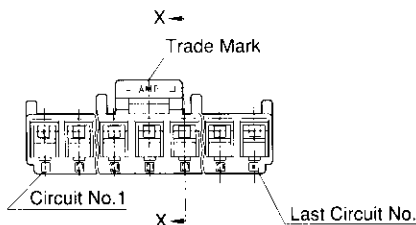

Section X-X

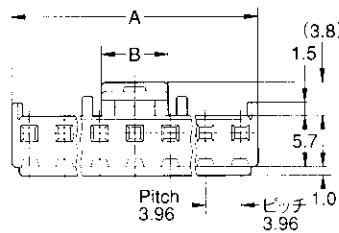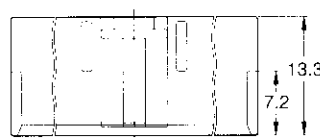

| No. of Pos | Dimension | | Part No. Plug Housing | | | | | |
|------------|-----------|------|-----------------------|-------------|-------------|-------------|-------------|-------------|
| | A | B | natural | yellow | blue | red | black | green |
| 2 | 7.86 | 3.60 | 1-1123722-2 | 2-1123722-2 | 3-1123722-2 | 4-1123722-2 | 5-1123722-2 | 6-1123722-2 |
| 3 | 11.82 | 7.50 | 1-1123722-3 | 2-1123722-3 | 3-1123722-3 | 4-1123722-3 | 5-1123722-3 | 6-1123722-3 |
| 4 | 15.78 | 7.50 | 1-1123722-4 | 2-1123722-4 | 3-1123722-4 | 4-1123722-4 | 5-1123722-4 | 6-1123722-4 |
| 5 | 19.74 | 7.50 | 1-1123722-5 | 2-1123722-5 | 3-1123722-5 | 4-1123722-5 | 5-1123722-5 | 6-1123722-5 |
| 6 | 23.70 | 7.50 | 1-1123722-6 | 2-1123722-6 | 3-1123722-6 | 4-1123722-6 | 5-1123722-6 | 6-1123722-6 |
| 7 | 27.66 | 7.50 | 1-1123722-7 | 2-1123722-7 | 3-1123722-7 | 4-1123722-7 | 5-1123722-7 | 6-1123722-7 |
| 8 | 31.62 | 7.50 | 1-1123722-8 | 2-1123722-8 | 3-1123722-8 | 4-1123722-8 | 5-1123722-8 | 6-1123722-8 |
| 9 | 35.58 | 7.50 | 1-1123722-9 | 2-1123722-9 | 3-1123722-9 | 4-1123722-9 | 5-1123722-9 | 6-1123722-9 |
| 10 | 39.54 | 7.50 | 1-1123722-0 | 2-1123722-0 | 3-1123722-0 | 4-1123722-0 | 5-1123722-0 | 6-1123722-0 |
| 11 | 43.50 | 7.50 | 1-1123722-1 | 2-1123722-1 | 3-1123722-1 | 4-1123722-1 | 5-1123722-1 | 6-1123722-1 |