

A standard in-line 4mm banana plug with a stainless steel contact spring.
 The large rear diameter of this plug will accept cables with a conductor of up 5,5mm (10 awg). The lead wire can be held either by soldering in a large solder bucket, or by a set screw. When the cable is held by the set screw, the solder bucket can also be crimped for added strength, (suitable crimping tool - Daniels Manufacturing D36 Hydraulic Crimper).


The product is also supplied with a large diameter insulating cover that accepts cables with a maximum outside diameter of 7,1mm.

MATERIAL
CONTACT SPRING : Stainless Steel, BS 302
PLUG BODY : Brass, TR1 CZ 131 nickel plated
SCREW : Brass, BS 2874
PLUG HOUSING : Acetal, C 27021 R

RATING : 10 Amps

VOLTAGE : 50 Volts max

Dimensions

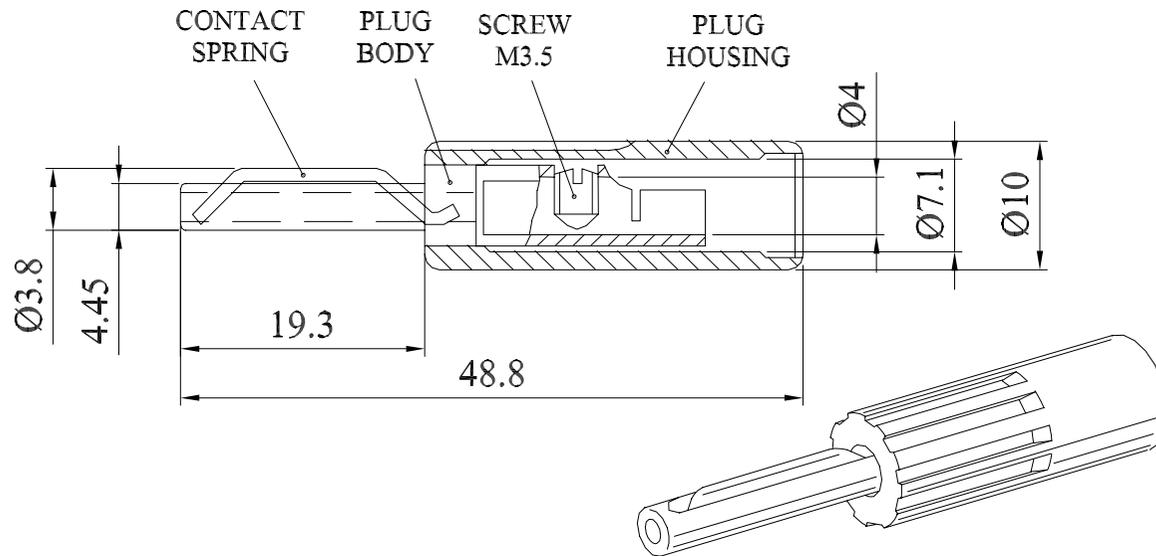

Part No.	Description	
583-0100	BLACK	(NICKEL PLATED)
583-0500	RED	(NICKEL PLATED)

CONVERTED FROM PS0335 ISS5 (02.12.97) IN JAN 2003

DrgNo 583 SERIES TITLE STANDARD 4mm PLUG ALL DIMENSIONS IN MM ANGLES IN DECIMAL DEGREES

DELTRON Components	ISSUE 5	GENERAL SPECIFICATION FOR 583 SERIES	CUSTOMER		FILTER REF	
			Aprvd Date 10/02/03	Aprvd By MC	Drwn by BFS	Scale: NTS