


NEW PTH EXTENDER CARDS FOR DIN 41494 EURO FRAMES.

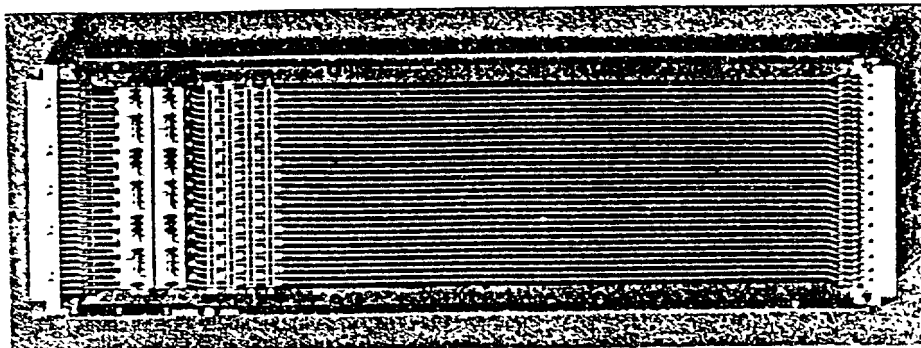

BOARD FEATURES :

- \* Plated Through Holes.
- \* 64-64 Type B and 64-96 Type C DIN 41612 Applications.
- \* High reliability DIL switches on lines 2-31 to provide fast and simple track interruption.
- \* Suitable for 160 mm and 220 mm applications.
- \* Expandable heights in multiples of 3U by adding divider kits.
- \* Wide power tracks - rows 1 and 32.
- \* 100% tested for line continuity.
- \* Test point and DIL switch positions clearly indentified by silk screen.
- \* 20 terminal assemblies supplied with each Extender Card.
- \* Soldering resist coated to prevent solder bridging and finger stains.
- \* Reverse DIN applications by request.

ORDERING INFORMATION :

DESCRIPTION:	PART NO:
64-64 Type B PTH Extender	EC 02D 0211-B
64-64 Type B Reverse	EC 02D 0211-RB
64-96 Type C PTH Extender	EC 02D 0211-C
64-96 Type C Reverse	EC 02D 0211-RC
Extender Multiple converter	EC 01D 0201

< 148-213

< 148-214